
 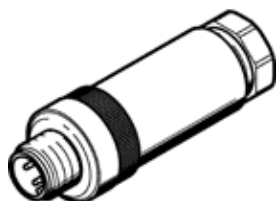


Utikač NECU-S-M12G4-P2-IS

Broj artikla: 570954

FESTO



Tehnički podaci

| Svojstvo | Vrednost |
|--|---|
| Zasnovano na normi | EN 61076-2-101 EN 61984 |
| Frekvencija priključivanja | 50 |
| Položaj ugradnje | proizvoljno |
| Težina proizvoda | 18 g |
| Electrical connection 1, function | Field device side |
| Electrical connection 1, design | okruglo |
| Electrical connection 1, connection type | Utikači |
| Electrical connection 1, cable outlet | Ravno |
| Electrical connection 1, connection technology | M12x1, A-coded in accordance with EN 61076-2-101 |
| Electrical connection 1, number of pins/wires | 4 |
| Electrical connection 1, type of mounting | Screw-type lock with hex A/F 18 mm and longitudinal knurl |
| Electrical connection 2, connection type | Kabl |
| Electrical connection 2, connection technology | Vijčana stezaljka |
| Područje pogonskog napona DC | 0 ... 30 V |
| Strujna opteretivost kod 40°C | 4 A |
| Čvrstoća na udarno naprezanje | 2,5 kV |
| Navojni spoj kabla | Pg9 |
| Dozvoljeni prečnik kabla | 6 ... 8 mm |
| Presek priključka | 0,75 mm ² |
| Mehanička zaštita | IP65 IP67 |
| Temperatura okoline | -25 ... 85 °C |
| PWIS conformity | VDMA24364-B2-L |
| Materijal - napomena | RoHS komformnost |
| Stepen zagađenja | 3 |
| Material housing | PA |
| Material of union nut | PA |
| Material electrical contact | Mesing Bela obložena bronza |