 



# Utikač NECU-S-M12G4-P1-Q6-IS

Broj artikla: 570955

FESTO

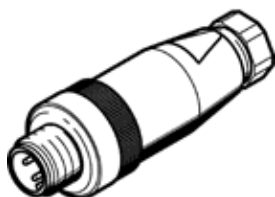

## Tehnički podaci

Svojstvo	Vrednost
Zasnovano na normi	EN 61076-2-101 EN 61984
Frekvencija priključivanja	50
Položaj ugradnje	proizvoljno
Težina proizvoda	18 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	okruglo
Electrical connection 1, connection type	Utikači
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 1, number of pins/wires	4
Electrical connection 1, type of mounting	Screw-type lock with hex A/F 18 mm and longitudinal knurl
Electrical connection 2, connection type	Kabl
Electrical connection 2, connection technology	Vijčana stezaljka
Područje pogonskog napona DC	0 ... 30 V
Strujna opteretivost kod 40°C	4 A
Čvrstoća na udarno naprezanje	2,5 kV
Navojni spoj kabla	Pg7
Dozvoljeni prečnik kabla	2,5 ... 2,9 mm
Presek priključka	0,14 ... 0,5 mm <sup>2</sup>
Mehanička zaštita	IP65 IP67
Temperatura okoline	-25 ... 85 °C
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komfornost
Stepen zagađenja	3
Material housing	PA
Material of union nut	PA
Material electrical contact	Mesing Bela obložena bronza