


# Bus interface CDPX-F-CO

Broj artikla: 575301

FESTO

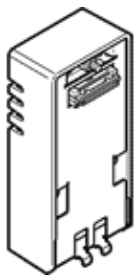

## Tehnički podaci

Svojstvo	Vrednost
Dubina ugradnje	24 mm
Visina	91 mm
Dužina	41 mm
Dozvola	C-Tick c UL us - Listed (OL)
CE znak (vidi izjavu o usklađenosti)	prema EU-EMV-smernici in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
Temperatura ležaja	-20 ... 70 °C
Relativna vlažnost vazduha	5 - 85 % ne kondenzira se
Mehanička zaštita	IP20
Temperatura okoline	0 ... 50 °C
Težina proizvoda	150 g
Materijal - napomena	RoHS komfornost
Fieldbus interface	CANopen
Fieldbus interface, tehnika priključka	Utikači Sub-D 9-polno
Fieldbus interface, prenosni odnos	9,6 kbit/s bis 1 Mbit/s