
 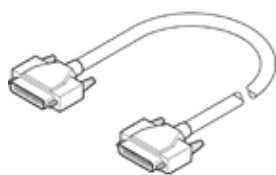


Spojni vod NEBC-S1G25-K-5.0-N-S1G25

Broj artikla: 8001376

FESTO



Tehnički podaci

Svojstvo	Vrednost
Cable identification	Without inscription label holder
Električni priključak	25-polno Utikač ravni Sub-D / Sub-D
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utikači
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	25
Electrical connection 1, occupied pins/wires	25
Electrical connection 1, type of mounting	2 screws 4-40 UNC
Electrical connection 2, function	Controller side
Electrical connection 2, design	ugaono
Electrical connection 2, connection type	Utičnica
Electrical connection 2, cable outlet	Ravno
Electrical connection 2, connection technology	Sub-D
Electrical connection 2, number of pins/wires	25
Electrical connection 2, occupied pins/wires	25
Electrical connection 2, type of mounting	2 screws 4-40 UNC
Nazivni pogonski napon DC	24 V
Strujna opteretivost kod 40°C	1 A
Dužina kabla	5 m
Svojstvo kabla	Standard
Prečnik kabla	7 mm
Struktura kabla	zaslonjeno
Mehanička zaštita	IP40
Note on degree of protection	u montiranom stanju
Temperatura okoline	0 ... 70 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
Materijal - napomena	RoHS komfornost
Klasa korozione otpornosti KBK	0 - No corrosion stress
Material cable sheath	PVC
Boja izolacije	sivo
Boja kućišta	sivo