


 
Spojni vod NEBC-U7G10-KS-5-N-S-U5G9

Broj artikla: 8072582

Komponenta koja će prestati da se proizvodi

Komponenta se više ne proizvodi. Isporučuje se do 2025. Vidi Support Portal za alternativni proizvod.

FESTO

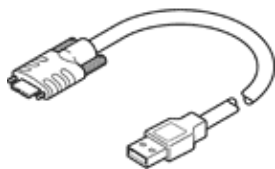

Tehnički podaci

Svojstvo	Vrednost
Cable identification	Without inscription label holder
Težina proizvoda	422 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utikači
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	USB 3.0 type B micro
Electrical connection 1, number of pins/wires	10
Electrical connection 1, occupied pins/wires	9
Electrical connection 1, type of mounting	2x screws M2x0.4
Electrical connection 2, function	Controller side
Electrical connection 2, design	ugaono
Electrical connection 2, connection type	Utikači
Electrical connection 2, cable outlet	Ravno
Electrical connection 2, connection technology	USB 3.0 type A
Electrical connection 2, number of pins/wires	9
Electrical connection 2, occupied pins/wires	9
Područje pogonskog napona DC	0 ... 30 V
Strujna opteretivost kod 40°C	1,8 A
Čvrstoća na udarno naprezanje	0,3 kV
Dužina kabla	5 m
Svojstvo kabla	Standard
Uslovi ispitivanja kabla	Uslovi ispitivanja na zahtev
Bending radius, fixed cable installation	≥ 125 mm
Bending radius, flexible cable installation	≥ 125 mm
Prečnik kabla	6,2 mm
Struktura kabla	2 x AWG22 + 2 x (2 x AWG26)C + 1 x (2 x AWG28) zaslonjeno
Nazivni presek provodnika	0,08 mm ² 0,128 mm ² 0,324 mm ²
Mehanička zaštita	IP20
Note on degree of protection	u montiranom stanju
Temperatura okoline	-20 ... 80 °C
Temperatura okoline kod pokretnog postepenja kablova	-20 ... 80 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komformnost Bez halogena
Stepen zagađenja	1
Klasa korozione otpornosti KBK	0 - No corrosion stress
Material cable sheath	PVC
Boja izolacije	crno