 



# Motorski vod

## NEBM-F1W31-XC-0.5-F1N-DF1W31

Broj artikla: 8079819

FESTO

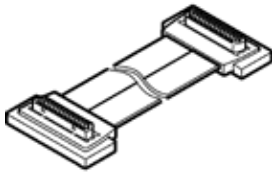

## Tehnički podaci

Svojstvo	Vrednost
Cable identification	Without inscription label holder
Frekvencija priključivanja	30
Težina proizvoda	27 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Angled
Electrical connection 1, note about the cable outlet	90°
Electrical connection 1, connection technology	Connection pattern F1
Electrical connection 1, number of pins/wires	31
Electrical connection 1, occupied pins/wires	31
Electrical connection 1, type of mounting	Snap-in locking
Electrical connection 2, function	Controller side
Electrical connection 2, design	ugaono
Electrical connection 2, connection type	Utičnica
Electrical connection 2, cable outlet	Angled
Electrical connection 2, note on cable outlet	90°
Electrical connection 2, connection technology	Connection pattern F1
Electrical connection 2, number of pins/wires	31
Electrical connection 2, occupied pins/wires	31
Electrical connection 2, type of mounting	Snap-in locking
Područje pogonskog napona DC	0 ... 50 V
Nazivni pogonski napon DC	24 V
Strujna opteretivost kod 40°C	0,5 A
Čvrstoća na udarno naprezanje	0,25 kV
Dužina kabela	0,5 m
Svojstvo kabela	for dynamic applications
Uslovi ispitivanja kabela	Uslovi ispitivanja na zahtev
Bending radius, fixed cable installation	0 mm
Information on bending radius, fixed cable installation	Can be bent once
Bending radius, flexible cable installation	≥ 25 mm
Struktura kabela	31 wires, distance 0.5 mm
Nazivni presek provodnika	0,0105 mm <sup>2</sup>
Mehanička zaštita	IP20
Note on degree of protection	u montiranom stanju
Temperatura okoline	-20 ... 75 °C
Temperatura okoline kod pokretnog postepenja kablova	-5 ... 70 °C
Temperatura ležaja	-25 ... 55 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
Materijal - napomena	RoHS komformnost
Stepen zagađenja	1
Klasa korozione otpornosti KBK	1 - Low corrosion stress
Material cable sheath	PET
Boja izolacije	sivo
Material housing	PA
Boja kućišta	crno
Material electrical contact	Legura bakra, kalajisana