


Mrežni filter CAMF-C6-F-C8-3A

Broj artikla: 8088928

★ Kernprogramm

FESTO

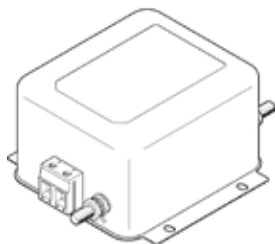

Tehnički podaci

Svojstvo	Vrednost
Otpornost na kratak spoj	ne
Strujna opteretivost kod 40°C	8 A
Područje pogonskog napona AC	0 ... 250 V
Mrežna frekvencija	0 ... 400 Hz
Napon izolacije	1.100 V
Dozvola	ENEC UL - Recognized (OL) c UL - Recognized (OL)
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
PWIS conformity	VDMA24364 zone III
Temperatura ležaja	-25 ... 100 °C
Mehanička zaštita	IP20
Temperatura okoline	-25 ... 100 °C
Težina proizvoda	700 g
Vrsta pričvršćenja	Montažna ploča, navojno pritegnuta
Materijal - napomena	RoHS komformnost
Položaj ugradnje	vodoravno
Electrical connection 1, function	Power supply
Electrical connection 1, connection type	Terminal strip
Electrical connection 1, connection technology	Vijčana stezaljka
Electrical connection 1, number of pins/wires	2
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, conductor cross section	4 ... 6 mm ²
Electrical connection 2, function	Power supply
Electrical connection 2, connection type	Terminal strip
Electrical connection 2, connection technology	Vijčana stezaljka
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
Electrical connection 2, conductor cross section	4 ... 6 mm ²