

Spojni vod

NEBC-U7W10-KS-0.5-N-SB-U7G10


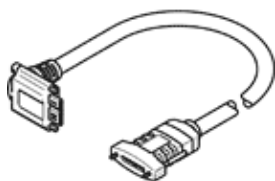
Broj artikla: 8093270

Komponenta koja će prestati da se proizvodi

[Komponenta se više ne proizvodi. Isporučuje se do 2025. Vidi Support Portal za alternativni proizvod.](#)

FESTO

10 9 8 7 6 5 4 3 2 1

Tehnički podaci

Svojstvo	Vrednost
Cable identification	Without inscription label holder
Težina proizvoda	35 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utikači
Electrical connection 1, cable outlet	Angled
Electrical connection 1, connection technology	USB 3.0 type B micro
Electrical connection 1, number of pins/wires	10
Electrical connection 1, occupied pins/wires	9
Electrical connection 1, type of mounting	2x screws M2x0.4
Electrical connection 2, function	Controller side
Electrical connection 2, design	ugaono
Electrical connection 2, connection type	Utičnica
Electrical connection 2, cable outlet	Ravno
Electrical connection 2, connection technology	USB 3.0 type B micro
Electrical connection 2, number of pins/wires	10
Electrical connection 2, occupied pins/wires	9
Electrical connection 2, type of mounting	2x threaded bush M2x0.4
Područje pogonskog napona DC	0 ... 30 V
Područje pogonskog napona AC	0 ... 30 V
Strujna opteretivost kod 40°C	1,4 A
Čvrstoća na udarno naprezanje	1 kV
Shielding	Da
Svojstva prenošenja	as per system communication AP
Dužina kabla	0,45 m
Svojstvo kabla	Standard
Uslovi ispitivanja kabla	Uslovi ispitivanja na zahtev
Bending radius, fixed cable installation	≥ 62 mm
Bending radius, flexible cable installation	≥ 62 mm
Prečnik kabla	6,2 mm
Struktura kabla	2 x AWG22 + 2 x (2 x AWG26)C + 1 x (2 x AWG28)
Nazivni presek provodnika	0,32 mm ²
Mehanička zaštita	IP20
Note on degree of protection	u montiranom stanju
Temperatura okoline	-10 ... 80 °C
Temperatura okoline kod pokretnog postepenja kablova	-10 ... 80 °C
Temperatura ležaja	-10 ... 80 °C
PWIS conformity	VDMA24364 zone III
Materijal - napomena	RoHS komformnost
Stepen zagađenja	1
Klasa korozione otpornosti KBK	0 - No corrosion stress
Material cable sheath	PVC
Boja izolacije	crno
Material housing	PVC
Boja kućišta	crno
Material insulation	PVC