


Line choke CAMF-C6-FD-C6-11A

Broj artikla: 8096867

FESTO

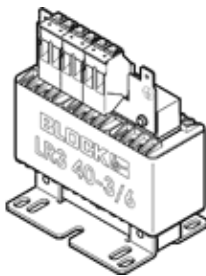

Tehnički podaci

Svojstvo	Vrednost
Otpornost na kratak spoj	ne
Strujna opteretivost kod 40°C	6 A
Područje pogonskog napona AC	0 ... 600 V
Nominal inductance	3,7 mH
Nominal inductance tolerance	10 %
Mrežna frekvencija	50 ... 60 Hz
Napon izolacije	4.000 V
Dimenzije Š x D x V	60 mm x 80 mm x 116 mm
Dozvola	ENEC c UL - Recognized (OL)
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
PWIS conformity	VDMA24364 zone III
Temperatura ležaja	-10 ... 40 °C
Mehanička zaštita	IP00
Temperatura okoline	-10 ... 40 °C
Težina proizvoda	940 g
Vrsta pričvršćenja	Montažna ploča, navojno pritegnuta
Materijal - napomena	RoHS komfornost
Položaj ugradnje	vodoravno
Electrical connection 1, function	Power supply
Electrical connection 1, connection type	Terminal strip
Electrical connection 1, connection technology	Vijčana stezaljka
Electrical connection 1, number of pins/wires	6
Electrical connection 1, occupied pins/wires	6
Electrical connection 1, conductor cross section	4 mm ²