


Mrežni filter CAMF-C6-F-C42-11A

Broj artikla: 8096894

FESTO

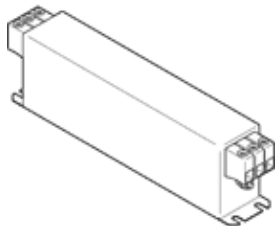

Tehnički podaci

Svojstvo	Vrednost
Otpornost na kratak spoj	ne
Strujna opteretivost kod 40°C	42 A
Područje pogonskog napona AC	0 ... 520 V
Mrežna frekvencija	0 ... 60 Hz
Napon izolacije	2.650 V
Dimenzije Š x D x V	50 mm x 295 mm x 85 mm
Dozvola	ENEC UL - Recognized (OL) c UL - Recognized (OL)
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
PWIS conformity	VDMA24364 zone III
Temperatura ležaja	-25 ... 100 °C
Mehanička zaštita	IP20
Temperatura okoline	-25 ... 100 °C
Težina proizvoda	1.400 g
Vrsta pričvršćenja	Montažna ploča, navojno pritegnuta
Materijal - napomena	RoHS komfornost
Položaj ugradnje	vodoravno
Electrical connection 1, function	Power supply
Electrical connection 1, connection type	Terminal strip
Electrical connection 1, connection technology	Vijčana stezaljka
Electrical connection 1, number of pins/wires	3
Electrical connection 1, occupied pins/wires	3
Electrical connection 1, conductor cross section	10 ... 16 mm ²
Electrical connection 2, function	Power supply
Electrical connection 2, connection type	Terminal strip
Electrical connection 2, connection technology	Vijčana stezaljka
Electrical connection 2, number of pins/wires	3
Electrical connection 2, occupied pins/wires	3
Electrical connection 2, conductor cross section	10 ... 16 mm ²