 



Adapter

NEFM-S1G9-K-0,5-R3G8

Broj artikla: 8106112

FESTO

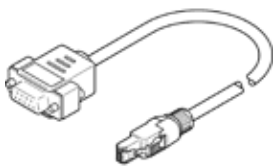

Tehnički podaci

Svojstvo	Vrednost
Cable identification	Without inscription label holder
Težina proizvoda	100 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	9
Electrical connection 1, occupied pins/wires	8
Electrical connection 2, function	Controller side
Electrical connection 2, design	ugaono
Electrical connection 2, connection type	Utikači
Electrical connection 2, cable outlet	Ravno
Electrical connection 2, connection technology	RJ45
Electrical connection 2, number of pins/wires	8
Electrical connection 2, occupied pins/wires	8
Područje pogonskog napona DC	0 ... 24 V
Nazivni pogonski napon DC	24 V
Strujna opteretivost kod 40°C	0,9 A
Čvrstoća na udarno naprezanje	2 kV
Shielding	Da
Dužina kabla	0,5 m
Svojstvo kabla	Standard
Bending radius, fixed cable installation	68 mm
Prečnik kabla	6,8 mm
Struktura kabla	5x(2x0,08)
Nazivni presek provodnika	0,08 mm ²
Nominal conductor cross section (AWG)	AWG28
Mehanička zaštita	IP20
Note on degree of protection	u montiranom stanju
Temperatura okoline	-20 ... 80 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komfornost
Stepen zagađenja	2
Material cable sheath	PVC
Boja izolacije	crno
Material housing	PVC
Boja kućišta	crno
Material insulation	PVC