


Elektronski modul VAVE-P17-TP-5YL1-P

Broj artikla: 8109876

FESTO

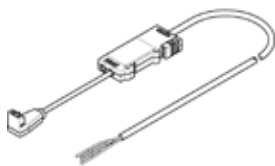

Tehnički podaci

Svojstvo	Vrednost
Zaštita od zamene polova	za pogonski napon
Dodatne funkcije	Zaštitni krug
Područje pogonskog napona DC	12 ... 24 V
Ulazni otpor, ulaz zadate vrednosti	10 kOhm
podesivi izlazni napon	0 ... 310 V
Primljena snaga kod 24 V DC	1,2 W
Maks. izlazna struja	5 mA
Nazivni pogonski napon DC	12 ... 24 V
Napon eksternog ulaza zadate vrednosti	0 ... 10 V
Dozvola	RCM Mark
KC mark	KC-EMV
CE znak (vidi izjavu o usklađenosti)	prema EU-EMV-smernici
UKCA marking (see declaration of conformity)	To UK instructions for EMC
Klasa korozione otpornosti KBK	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
Mehanička zaštita	IP40
Temperatura okoline	-10 ... 60 °C
Temperatura ležaja	-40 ... 80 °C
Položaj ugradnje	proizvoljno
Maks. pritezni moment	52,5 Ncm
Bending radius, fixed cable installation	13,5 mm
Bending radius, flexible cable installation	45 mm
Težina proizvoda	35 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, connection technology	Festo-specific coding
Electrical connection 1, number of pins/wires	3
Electrical connection 1, occupied pins/wires	3
Electrical connection 1, type of mounting	Plug-in
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabl
Electrical connection 2, cable outlet	Ravno
Electrical connection 2, number of pins/wires	4
Electrical connection 2, occupied pins/wires	4
Struktura kabla	4x0,25
Prečnik kabla	4,5 mm
Dužina kabla	0,5 m
Krajevi žica	Završetak žice
Priključak uzemljenja	ne postoji
Vrsta pričvršćenja	Direct mounting via through-holes sa H - profilom
Boja kućišta	crno
Materijal - napomena	RoHS komfornost
Material cover	PA
Material housing	PA
Material cable sheath	PVC