 



Ventil

VOFC-LT-M32C-M-FN14-FN

Broj artikla: 8122932

FESTO

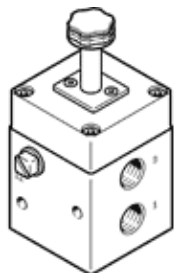

Tehnički podaci

Svojstvo	Vrednost
Normalni nazivni protok	601 l/min
Operating pressure MPa	0 ... 0,8 MPa
Pogonski pritisak	0 ... 8 bar
Mehanička zaštita	IP65
Mesto izdavanja sertifikata	TÜV 968/V 1251.00/21
Sigurnosna funkcija	Safe venting
Safety Integrity Level (SIL)	Product can be used in SRP/CS up to SIL 3 (high demand) do SIL 3 načina niskih zahteva
Napomena za pogonski pritisak	0 - 0.8 MPa with external pilot air
Klasa korozione otpornosti KBK	4 - Very high corrosion stress
PWIS conformity	VDMA24364 zone III
Materijal - napomena	RoHS komformnost