


Mrežna priključna utičnica NECL-L12W5-C2-Q10

Broj artikla: 8166794

FESTO

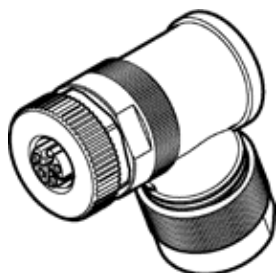

Tehnički podaci

Svojstvo	Vrednost
Zasnovano na normi	EN 61076-2-111
Dozvola	c UL us - Recognized (OL)
Mesto izdavanja sertifikata	UL E474609
Vrsta pričvršćenja	Threaded
Cable outlet	Angled
Note on cable outlet	Can be rotated 72°
Težina proizvoda	53,58 g
Electrical connection 1, function	Power supply
Electrical connection 1, design	okruglo
Electrical connection 1, connection type	Utičnica
Electrical connection 1, connection technology	M12x1, L-coded to EN 61076-2-111
Electrical connection 1, number of pins/wires	5
Electrical connection 2, connection technology	Vijčana stezaljka
Područje pogonskog napona DC	0 ... 63 V
Nazivni pogonski napon DC	63 V
Strujna opteretivost kod 40°C	16 A
Čvrstoća na udarno naprezanje	1,5 kV
Dozvoljeni prečnik kabla	8 - 13 mm for electrical connection 1
Nazivni presek provodnika	≤ 2,5 mm ²
Nominal conductor cross section (AWG)	AWG14
Napomena za presek priključka	Max. 1.5 mm ² /AWG16 when using wire end sleeves
Mehanička zaštita	IP65 IP67
Temperatura okoline	-40 ... 105 °C
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komformnost
Stepen zagađenja	3
Klasa korozione otpornosti KBK	1 - Low corrosion stress
Material housing	PA
Material screw-type lock	Nickel-plated die-cast zinc
Material electrical contact	Gold-plated copper alloy