


L-Verschraubung
Typ LJK-...
mit Innengewinde und 2 Dichtringen

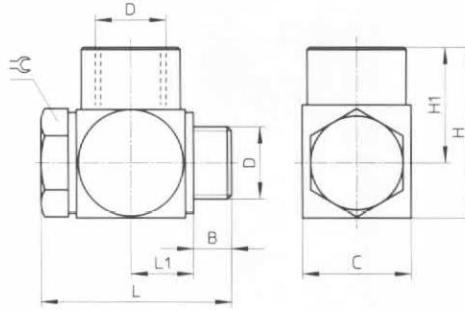


Bestellbezeichnung		Anschluß D	Nennweite mm	Werkstoff	Gewicht kg	Abmessungen						
Teile-Nr.	Typ					B	C	L	L ₁	L ₂	L ₃	⌀
4945	LJK-1/8	G 1/8	4	GD-Zn	0,015	5,3	16	27,5	23,5	9,1	15,5	13
4946	LJK-1/4	G 1/4	6		0,027	6,8	20	35	31	11,6	21	17
4947	LJK-3/8	G 3/8	8		0,050	9,3	25	43,5	36,5	14,1	24	22
4948	LJK-1/2	G 1/2	12		0,092	11,6	30	50	44	16,7	29	27

T-Verschraubung
Typ TJK-...
mit Innengewinde und 2 Dichtringen

Typ TJK-M3



Typ TJK-...

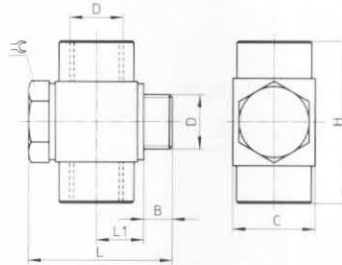

Bestellbezeichnung		Anschluß D	Nennweite mm	Werkstoff	Gewicht kg	Abmessungen						
Teile-Nr.	Typ					B	C	L	L ₁	L ₂	L ₃	⌀
15874	TJK-M3	-	1	CuZn 39 Pb 2	0,002	-	-	-	-	-	-	-
4949	TJK-1/8	G 1/8	4	GD-Zn	0,016	5,3	16	27,5	28	9,1	13	
4950	TJK-1/4	G 1/4	6		0,030	6,8	20	35	39	11,6	17	
4951	TJK-3/8	G 3/8	8		0,053	9,3	25	43,5	43	14,1	22	
4952	TJK-1/2	G 1/2	12		0,096	11,6	30	50	52	16,7	27	