


Sub-base
 Type FLP-7-PK-3
 For 3 mm tubing


Type FLP-7-PK-3

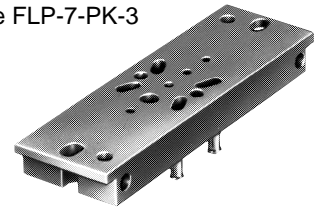

For frame mounting, see page 685.

Accessories:
 Mounting brackets
 11571 NRW-9/1.5-B
 Socket head capscrews
 M4 x 12

Type FLP-7-PK-3

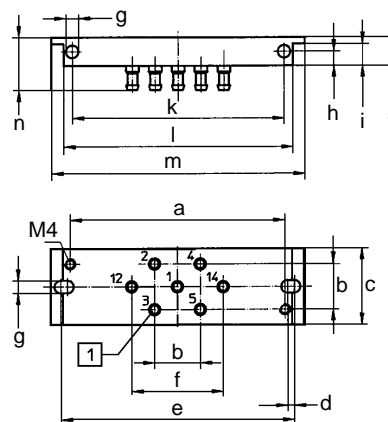

- 1 (P) = Supply
- 4, 2 (A, B) = Outlet
- 5, 3 (R, S) = Exhaust
- 12, 10 (Y, Z) = Pilot

① Barbed fitting for 3 mm tubing

Dimensions

- a 2.95 in / 75 mm
- b 0.63 in / 16 mm
- c 1.06 in / 27 mm
- d 0.09 in / 2.3 mm
- e 3.19 in / 81 mm
- f 1.26 in / 32 mm
- g 0.17 in / 4.4 mm
- h 0.20 in / 5 mm
- i 0.30 in / 7.7 mm
- j 0.39 in / 10 mm
- k 2.91 in / 74 mm
- l 3.15 in / 80 mm
- m 3.48 in / 88.5 mm
- n 0.73 in / 18.5 mm

Order Number	Part No./ Type	102104 FLP-7-PK-3	7868 ADB-PK-4
Mounting		Through-holes or manifold mounting	Manifold mounting
Connection	Working Ports	For 3 mm tubing	
	Control Ports	For 3 mm tubing	
Flow Rate		5.0 SCFM / 140 l/min	
Materials		Diecast Al, brass	Plastic
Weight		0.110 lb / 0.050 kg	