

Manifold

Type FR-12-...-B

For 2n-width Mounting Racks



This is a rack-mounted manifold or accumulator, and can provide additional volume for timing devices.

Accessories:

Mounting racks, see page 685.

Cap for sealing barbed fittings. Order No. 6213 CV-PK-3-B

Pipe plug for G 1/4 ISO
Order No. 3569 B-1/4

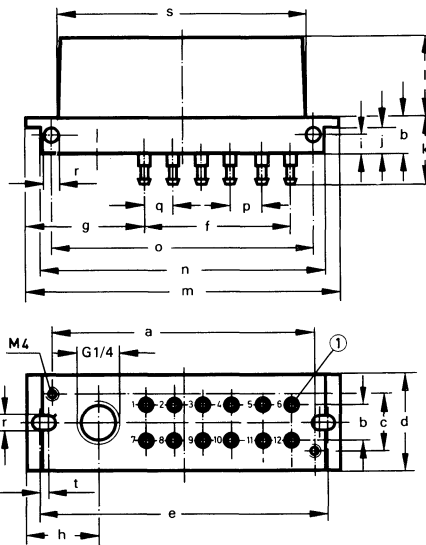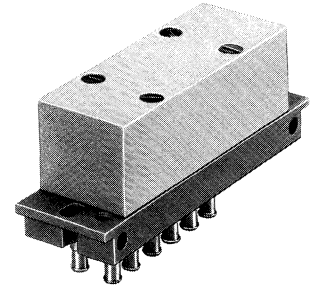

① Barbed fitting for
3 mm or 4 mm tubing

Dimensions

a	2.95 in / 75 mm	h	0.81 in / 20.5 mm	o	2.91 in / 74 mm
b	0.39 in / 10 mm	i	0.20 in / 5 mm	p	0.35 in / 9 mm
c	0.63 in / 16 mm	j	0.30 in / 7.7 mm	q	0.31 in / 8 mm
d	1.06 in / 27 mm	k	0.73 in / 18.5 mm	r	0.17 in / 4.4 mm
e	3.19 in / 81 mm	l	0.89 in / 22.5 mm	s	2.76 in / 70 mm
f	1.61 in / 41 mm	m	3.48 in / 88.5 mm	t	0.09 in / 2.3 mm
g	1.32 in / 33.5 mm	n	3.18 in / 80.8 mm		

Order Number	Part No./Type	8761 FR-12-PK-3-B	8762 FR-12-PK-4-B
Medium		Compressed air (filtered, lubricated, or unlubricated)	
Mounting		Holes through housing or rack mount	
Connection	Supply	One G 1/4 ISO connection	
	Outlet	12 barbed fittings for 3 mm tubing	12 barbed fittings for 4 mm tubing
Pressure Range*		0 to 120 psi / 0 to 8 bar	
Materials		Al, brass	
Weight		0.14 lb / 0.065 kg	0.15 lb / 0.070 kg
Volume		1.464 cu in / 22 cm ³	

* 14 to 140°F / -10 to +60°C