
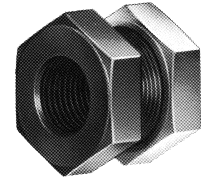


Fittings and Accessories

Swivel Pipe Fittings

Threaded Female Bulkhead Connector Type SCM-...

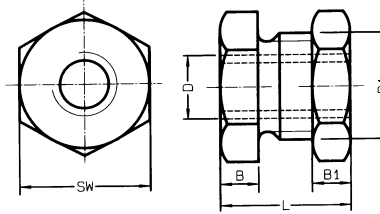


SW = wrench size (mm)

Order Number		Thread D	Material	Weight lb / kg	Dimensions					
Part No.	Type				B in / mm	B1 in / mm	D1	L in / mm	SW mm	
9969	SCM-M 5	M5	Al, blue anodized	0.001 / 0.005	0.16 / 4	0.14 / 3.5	M 10 x 1	0.61 / 15.5	13	
9970	SCM-1/8	G 1/8 ISO		0.022 / 0.010	0.20 / 5	0.20 / 5	M 14 x 1.5	0.79 / 20	17	
9971	SCM-1/4	G 1/4 ISO		0.062 / 0.028	0.20 / 5	0.28 / 7	M 20 x 1.5	0.89 / 22	24	
9972	SCM-3/8	G 3/8 ISO		0.075 / 0.034	0.31 / 8	0.33 / 8.5	M 24 x 1.5	1.04 / 26.5	27	
9973	SCM-1/2	G 1/2 ISO		0.172 / 0.078	0.31 / 8	0.41 / 10.5	M 30 x 1.5	1.12 / 28.5	36	

Swivel Elbow Type LJK-...

With Female Thread and 2 sealing rings

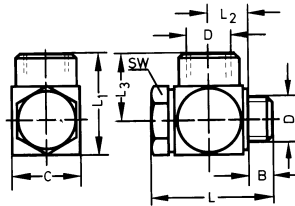


SW = wrench size (mm)

Order Number		Thread D	Orifice Size in / mm	Material	Weight lb / kg	Dimensions						
Part No.	Type					B in / mm	C in / mm	L in / mm	L1 in / mm	L2 in / mm	L3 in / mm	SW mm
4945	LJK-1/8	G 1/8 ISO	0.16 / 4	Diecast Zinc	0.033 / 0.015	0.21 / 5.3	0.63 / 16	1.08 / 27.5	0.93 / 23.5	0.36 / 9.1	0.61 / 15.5	13
4946	LJK-1/4	G 1/4 ISO	0.24 / 6		0.059 / 0.027	0.27 / 6.8	0.79 / 20	1.38 / 35	1.22 / 31	0.46 / 11.6	0.83 / 21	17
4947	LJK-3/8	G 3/8 ISO	0.31 / 8		0.110 / 0.050	0.37 / 9.3	0.98 / 25	1.71 / 43.5	1.44 / 36.5	0.56 / 14.1	0.94 / 24	22
4948	LJK-1/2	G 1/2 ISO	0.47 / 12		0.202 / 0.092	0.46 / 11.6	1.18 / 30	1.97 / 50	1.73 / 44	0.66 / 16.7	1.14 / 29	27

Swivel T Type TJK-...


With Female Thread and 2 sealing rings

Type TJK-M3

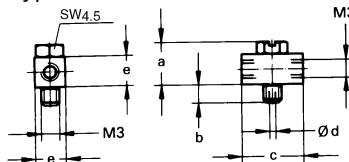


Dimensions Type TJK-M3

- a 0.28 in / 7 mm
- b 0.12 in / 3 mm
- c 0.39 in / 10 mm
- d 0.04 in / 1 mm
- e 0.20 in / 5 mm

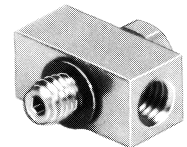

Type TJK-...

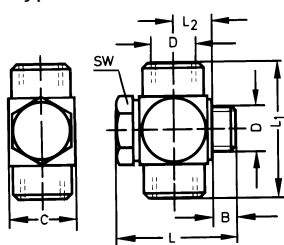

SW = wrench size (mm)

Order Number		Thread D	Orifice Size in / mm	Material	Weight lb / kg	Dimensions					
Part No.	Type					B in / mm	C in / mm	L in / mm	L1 in / mm	L2 in / mm	SW mm
15874	TJK-M 3	M3	0.04 / 1	CuZn39Pb2	0.004 / 0.002	—	—	—	—	—	—
4949	TJK-1/8	G 1/8 ISO	0.16 / 4	Diecast Zinc	0.035 / 0.016	0.21 / 5.3	0.63 / 16	1.08 / 27.5	1.10 / 28	0.36 / 9.1	13
4950	TJK-1/4	G 1/4 ISO	0.24 / 6		0.066 / 0.030	0.27 / 6.8	0.79 / 20	1.38 / 35	1.54 / 39	0.46 / 11.6	17
4951	TJK-3/8	G 3/8 ISO	0.31 / 8		0.117 / 0.053	0.37 / 9.3	0.98 / 25	1.71 / 43.5	1.69 / 43	0.56 / 14.1	22
4952	TJK-1/2	G 1/2 ISO	0.47 / 12		0.211 / 0.096	0.46 / 11.6	1.18 / 30	1.97 / 50	2.05 / 52	0.66 / 16.7	27

Multiple Distributor, with female thread Type VT-.../LK-.../TK-... see page 541.