 


Pneumatic Indicators and Gauges


Binary Signal Indicators

Visual Indicator

Type OH-10




The indicator pin extends when a pressure of more than 21 psi / 1.4 bar is present. The indicator pin extends to a length of 0.12 in / 3 mm.

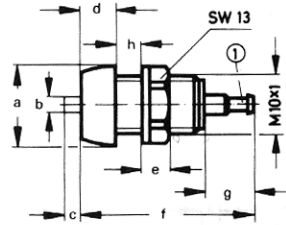

① Barbed fitting for 3 mm tubing
SW = wrench size, mm

Dimensions

- a diameter 0.55 in / 14 mm
- b diameter 0.11 in / 2.8 mm
- c 0.2 in / 3 mm
- d 0.24 in / 6 mm
- e 0.20 in / 5 mm
- f 1.16 in / 29.5 mm
- g 0.33 in / 8.5 mm
- h max. 0.35 in / 9 mm

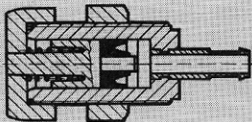

Order Number	9791 OH-10
Medium	Compressed air (filtered, lubricated, or unlubricated)
Design	Indicator pin with spring return
Mounting	Front panel mounting (dia. 7/16 in / 10.5 mm)
Connection	Barbed fitting for 3 mm plastic tubing
Pressure Range	21 to 120 psi / 1.4 to 8 bar
Color of Indicator	Red
Temperature Range	-50°F to +176°F / -10°C to +80°C
Materials	Housing: Plastic. Seals: Buna N
Weight	0.009 lb / 0.004 kg