 



### Visual Display

- Type OH-22 Green
- OH-22 Red
- OH-22 Yellow
- OH-22 Blue




This indicator responds when pressure in a line exceeds 22 psi / 1.5 bar. It is suitable for monitoring and indicating operating conditions. When actuated, a colored sleeve extends into the transparent cap and is easily seen from any angle.

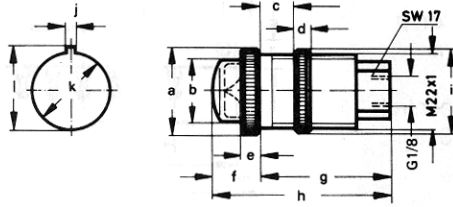

### Dimensions

- a 1.02 in / 26 mm
- b 0.75 in / 19 mm
- c 0.08 min - 0.95 max in / 2 min - 24 max mm
- d 0.16 in / 4 mm
- e 0.20 in / 5 mm
- f 0.53 in / 13.5 mm
- g 1.54 in / 39 mm
- h 2.07 in / 52.5 mm
- i 0.98 in / 25 mm
- j 0.09 in / 2.2 mm
- k 0.89 in / 22.5 mm
- l 0.94 in / 24 mm

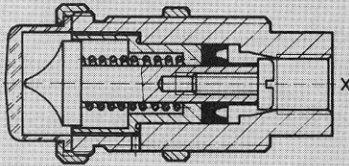

Order Number	4600 OH-22 Blue	4601 OH-22 Yellow	4237 OH-22 Green	4131 OH-22 Red
Medium	Compressed air (filtered, lubricated or unlubricated)			
Mounting	Front panel mount (mounting hole diameter 7/8 in / 22.5 mm)			
Connection	G1/8 ISO			
Pressure Range*	22 to 120 psi / 1.5 to 8 bar			
Display Color	Blue	Yellow	Green	Red
Visibility Angle, min	180°			
Max. Display Frequency	25 Hz (briefly due to heating)			
Design	Spring return			
Material	Housing: Polyamide. Seals: Buna N.			
Weight	0.055 lb / 0.025 kg			

\*113°F / 45°C Max.