 




Visual Indicator

Type OH-8

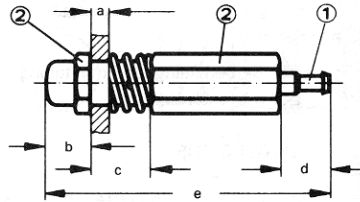

This indicator is actuated when a pressure of more than 18 psi / 1.2 bar is present. When the indicator is actuated, a colored sleeve extends into the transparent cap and can be seen from all sides.

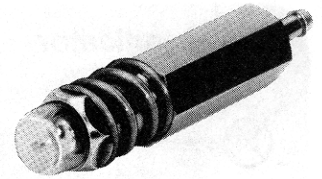

- ① Barbed fitting for 3 mm tubing
- ② 9 mm hex for tightening

Dimensions

- a 0.18 in / 4.5 mm (max)
- b 0.31 in / 7.8 mm
- c 0.41 in / 10.5 mm
- d 0.31 in / 8 mm
- e 1.94 in / 49.3 mm



Order Number	10088 OH-8 red	10089 OH-8 green	10090 OH-8 blue	10091 OH-8 yellow
Medium	Compressed air (filtered, lubricated, or unlubricated)			
Mounting	Front panel mount (mounting hole diameter 5/16 in / 8.2 mm)			
Connection	Barbed fitting for 3 mm plastic tubing			
Pressure Range*	18 to 120 psi / 1.2 to 8 bar			
Display Color	Red	Green	Blue	Yellow
Visibility Angle, min	180°			
Design	Spring return			
Material	Housing: Chrome plated brass, plastic			
Weight	0.022 lb / 0.010 kg			

*14 to +140°F / -10 to +60°C