

Air guns

FESTO



Air guns LBP

Technical data

FESTO

- Sturdy aluminium design
- Interchangeable nozzles


 Operating pressure
0 ... 10 bar



General technical data	
Exhaust function	Non-metered blowing
Pneumatic connection	Female thread G $\frac{1}{4}$
Operating pressure [bar]	0 ... 10
Standard nominal flow rate [l/min]	120 at 6 bar
Noise level [dB (A)]	90 at 6 bar
Material	Aluminium
Ambient temperature [°C]	-10 ... +50
Weights [g]	240

- | - Note: This product conforms with the ISO 1179-1 standard and the ISO 228-1 standard.

Dimensions

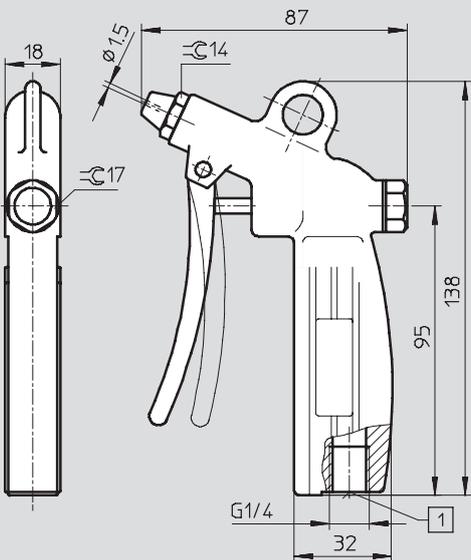

1 Sealing surface

- | - Note
This air gun has no pressure regulating valve.

- | - Note
Compressed air guns must not be pointed at people.

- | - Note: This product conforms with the ISO 1179-1 standard and the ISO 228-1 standard.

Ordering data		
Pneumatic connection	Part No.	Type
G $\frac{1}{4}$	35528	LBP- $\frac{1}{4}$

Low consumption air guns LSP

Technical data

- Fine, infinitely variable, lever operated flow metering
- Interchangeable nozzles

 - Operating pressure
0 ... 10 bar



General technical data	
Exhaust function	Metered blowing
Pneumatic connection	Female thread G $\frac{1}{4}$
Operating pressure [bar]	0 ... 10
Standard nominal flow rate [l/min]	120 at 6 bar
Noise level [dB (A)]	90 at 6 bar
Material	Polyamide
Ambient temperature [°C]	-10 ... +50
Weights [g]	125

-||- Note: This product conforms with the ISO 1179-1 standard and the ISO 228-1 standard.

Dimensions

Note
This air gun has no pressure regulating valve.

Note
Compressed air guns must not be pointed at people.

1 Sealing surface

-||- Note: This product conforms with the ISO 1179-1 standard and the ISO 228-1 standard.

Ordering data	
Pneumatic connection	Part No. Type
G $\frac{1}{4}$	184318 LSP- $\frac{1}{4}$ -C

