

Electrical connection technology, for inputs/outputs

Technical data – KM8

- Plug socket with cable for connecting inputs/outputs
- Pre-assembled at both ends
- Cable lengths 1 m, 2.5 m or 5 m
- Socket/plug, 3-pin or 4-pin



General technical data		
Type	KM8-...	
Type of mounting	Union nut/threaded connector	
Mounting position	Any	
Operating voltage range	[V AC]	60 AC
	[V DC]	75 DC
Current-carrying capacity	[A]	4
Protection class to EN 60 529		IP65 (assembled)
Material of housing		Polyurethane
Material of contacts		Nickel-plated/gold-plated bronze
Material of union nut		Nickel-plated brass
Material of cable sheath		Polyurethane
Material note		RoHS compliant
Ambient temperature	[°C]	-25 ... +85
Ambient temperature of flexible cable installation	[°C]	+20 ... +80


Ordering data							
	Electrical connection	Constructional design [mm ²]	Cable diameter [mm]	Product weight [g]	Cable length [m]	Type	Part No.
	Straight plug, 3-pin, M8	3x0.25	4.5	26	0.5	KM8-M8-GSGD-0,5	175 488
	Straight socket, 3-pin, M8						
	Straight plug, 3-pin, M8	3x0.25	4.5	40	1	KM8-M8-GSGD-1	175 489
	Straight socket, 3-pin, M8						
	Straight plug, 3-pin, M8	3x0.25	4.5	78.8	2.5	KM8-M8-GSGD-2,5	165 610
	Straight socket, 3-pin, M8						
	Straight plug, 3-pin, M8	3x0.25	4.5	140	5	KM8-M8-GSGD-5	165 611
	Straight socket, 3-pin, M8						

Electrical connection technology, for inputs/outputs

Technical data – KM8

Dimensions Download CAD data → www.festo.com


KM8-M8-...

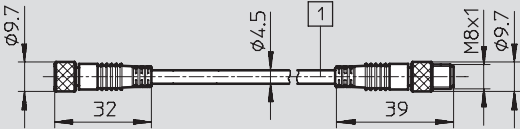


L1 Length according to type
(2.5 m or 5 m)

Wiring allocation (socket/plug view)

KM8-M8-...

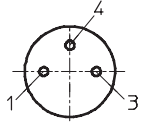Socket	Pin	Core colour	Pin	Plug
	1	Brown	1	
	2	Blue	2	
	3	Black	3	

-  - Note

Additional variants can be configured and ordered via modular products NEBU
 → internet.nebu.