


 

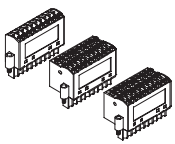
 
# Electrical connection technology, for power supply

Technical data – PS1-SAC-...

- Connector for power supply, 10-pin or 30-pin
- Individually or as a set
- Simple cable connection using clamping technology

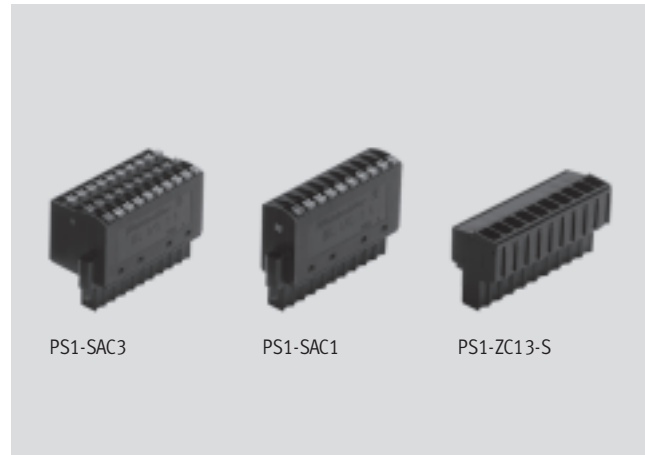

General technical data	
Type	PS1-SAC-.../SEA-KL-...
Type of mounting	2 M2x7 screws
Max. wire cross section	[mm <sup>2</sup> ] 0.08 ... 0.75
Operating voltage range	[V] 50 AC
Material of housing	Polybuteneterephthalate
Ambient temperature	[°C] -20 ... +100

Ordering data					
	Electrical connection	Current-carrying capacity	Product weight	Type	Part No.
		[A]	[g]		
	Socket, 10-pin, terminal strip, 10-pin	4	14	PS1-SAC10-10POL	197 159
	Socket, 10-pin, terminal strip, 10-pin	4	40	PS1-SAC11-10POL+LED	197 160
	Socket, 10-pin, terminal strip, 30-pin	0.5	25	PS1-SAC30-30POL	197 161
	Socket, 10-pin, terminal strip, 30-pin	0.5	25	PS1-SAC31-30POL+LED	197 162
	Socket, 10-pin, terminal strip, 10/30-pin	0.5/4	71	SEA-KL-SAC10/30	526 256
	Screw terminal socket, 10-pin	4	37	PS1-ZC13-10POL-SCHRAUBKL	160 800


# Electrical connection technology, for power supply

Technical data – PS1-SAC-...

## Dimensions

Download CAD data → [www.festo.com](http://www.festo.com)

PS1-SAC10-10POL

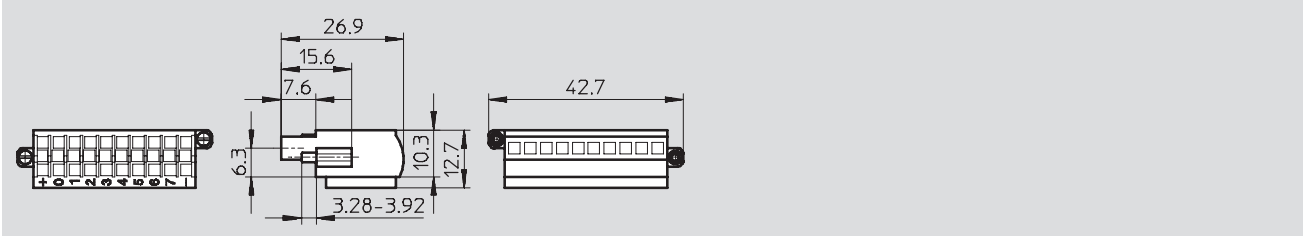

PS1-SAC30-30POL

