


# Electrical connection technology, for individual connection

Technical data – KMH

- Plug socket with cable for the horizontal connection of individual valves (type CPA-SC1)
- Pre-assembled
- Cable lengths 0.5 m, 1 m, 2.5 m or 5 m
- 3-pin plug socket
- Not suitable for chain link trunking
- KMH-D for 2 coils

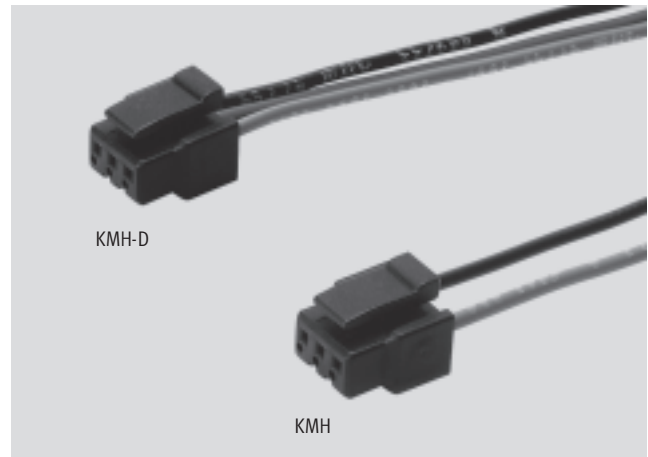

General technical data	
Type	KMH...
Electrical connection	3-pin plug socket
Type of mounting	Clip
Mounting position	Any
Operating voltage [V]	60 DC
Current-carrying capacity [A]	3
Cable diameter [mm]	1.3
Protection class to EN 60 529	IP40
Material of housing	Polyacetal
Material of contacts	Tin-plated bronze
Material of cable sheath	Polyvinyl chloride
Ambient temperature [°C]	-40 ... +105

Ordering data					
	Constructional design [mm <sup>2</sup> ]	Product weight [g]	Cable length (L1) [m]	Type	Part No.
	2x0.14	4	0.5	KMH-0,5	197 263
	2x0.14	7	1	KMH-1	197 264
	2x0.14	17	2.5	KMH-2,5	527 400
	2x0.14	31	5	KMH-5	527 401
	3x0.14	6	0.5	KMH-D-0,5	527 396
	3x0.14	11	1	KMH-D-1	527 397
	3x0.14	24	2.5	KMH-D-2,5	527 398
	3x0.14	46	5	KMH-D-5	527 399

# Electrical connection technology, for individual connection



FESTO

Technical data – KMH

## Dimensions

Download CAD data → [www.festo.com](http://www.festo.com)

Type KMH-...

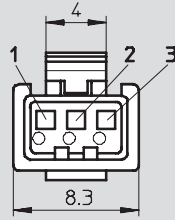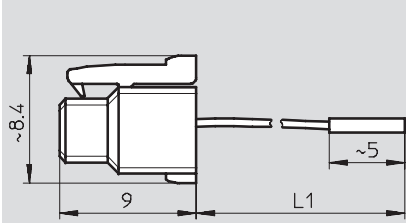

- 1 Pin 1, core colour black
- 2 Pin 2, core colour blue
- 3 Pin 3, core colour red
- L1 Length according to type  
(0.5 m, 1 m, 2.5 m or 5 m)