

Connecting cables NEBV, for valves

Technical data

Plug socket with cable KME

- Plug socket with cable for valves with E solenoid coils
- Pre-assembled
- Cable lengths 2.5 to 10 m



General technical data	
Electrical connection	Angled socket, 3-pin, type C, to EN 175301-803
Switching position display	LED
Nominal operating voltage [V DC]	24
Cable composition [mm ²]	2x0.75
Cable diameter [mm]	5.2
Protective earth connection	No
Type of mounting	On solenoid valve via M3 central screw
Mounting position	Any
Protection class to EN 60529	IP67 (assembled)


Materials	
Housing	PA
Pin contact	Bronze
Cable sheath	PVC

Operating and environmental conditions	
Ambient temperature [°C]	-20 ... +80

Connecting cables NEBV, for valves

Technical data

Dimensions Download CAD data → www.festo.com

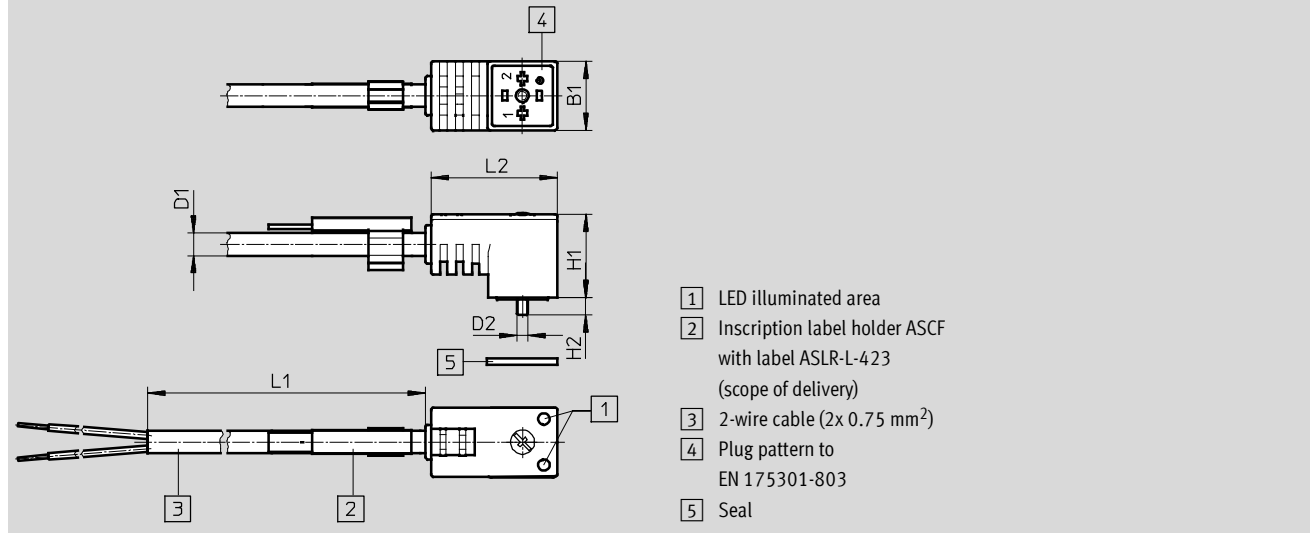

Type	B1	D1	D2	H1	H2	L1	L2
KME-1-24DC-2,5-LED	16	5.2	3	19.3	4	2,500	29.1
KME-1-24DC-5-LED						5,000	
KME-1-24-10-LED						10,000	

Ordering data		Product weight	Length	Part No.	Type
Electrical connection		[g]	[m]		
Angled socket, 3-pin, type C, to EN 175301-803	135	2.5	30943	KME-1-24DC-2,5-LED	
	280	5	30945	KME-1-24DC-5-LED	
	570	10	193455	KME-1-24-10-LED	