

Connecting cables NEBV, for valves

Technical data

Plug socket with cable KMYZ-9

- Plug socket with cable for valves with ZC solenoid coils (CPE10/CPE14)
- Pre-assembled
- Cable lengths 0.2 to 10 m



General technical data				
Type	KMYZ-9-24-...-PUR-B	KMYZ-9-24-M8-...-LED-B	KMYZ-9-24-AD-0,2-LED-B	KMYZ-9-24-AD-0,2-B
Electrical connection	Angled socket, 2-pin, square design			
	Open cable end, 2-wire	Straight plug, 3-pin, M8x1	Angled plug, 2-pin, square design	Angled plug, 2-pin, square design
Switching position display	LED	LED	LED	–
Additional functions	Reduction of retaining current	Reduction of retaining current	Reduction of retaining current	–
Nominal operating voltage [V DC]	24			
Cable composition [mm ²]	2x0.25			
Cable diameter [mm]	3.4			
Protective earth connection	No			
Type of mounting	On solenoid valve via M2 central screw			
Tightening torque [Nm]	0.25			
Mounting position	Any			
Protection class to EN 60529	IP65 (assembled)			

Materials	
Housing	Polyamide
Pin contact	Bronze
Cable sheath	TPE-U(PUR)
Note on materials	RoHS-compliant

Operating and environmental conditions	
Ambient temperature [°C]	–10 ... +50
CE marking (see declaration of conformity)	To EU EMC Directive

Connecting cables NEBV, for valves

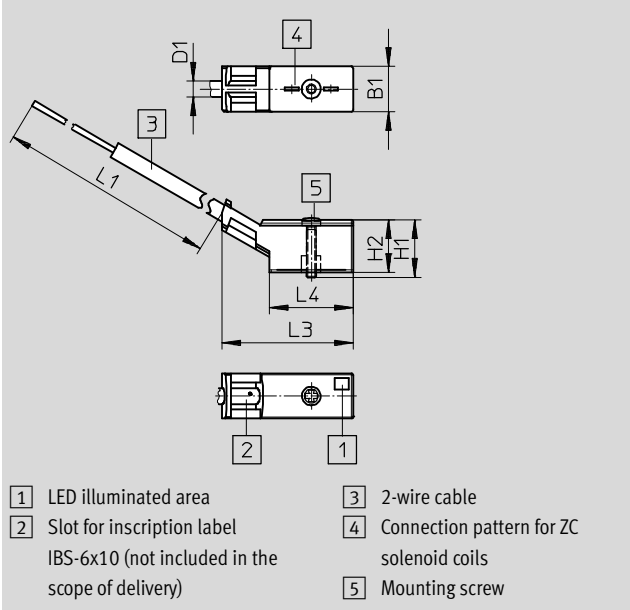
Technical data

FESTO


Dimensions

Download CAD data → www.festo.com


KMYZ-9-24



KMYZ-9-24-M8

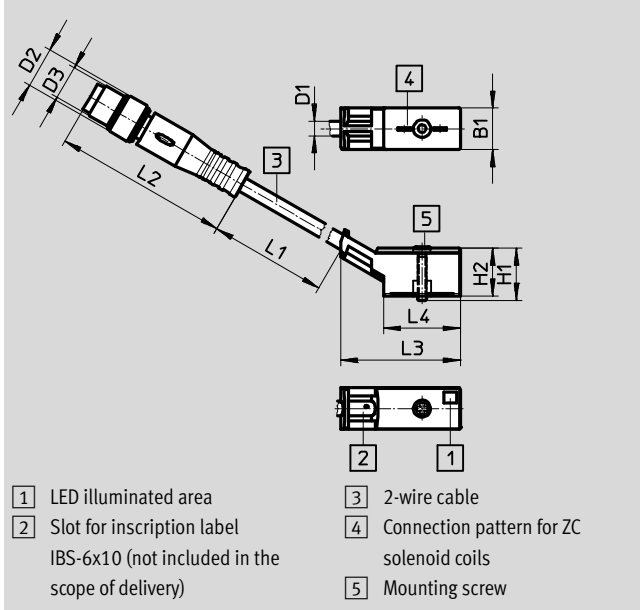




KMYZ-9-24-AD

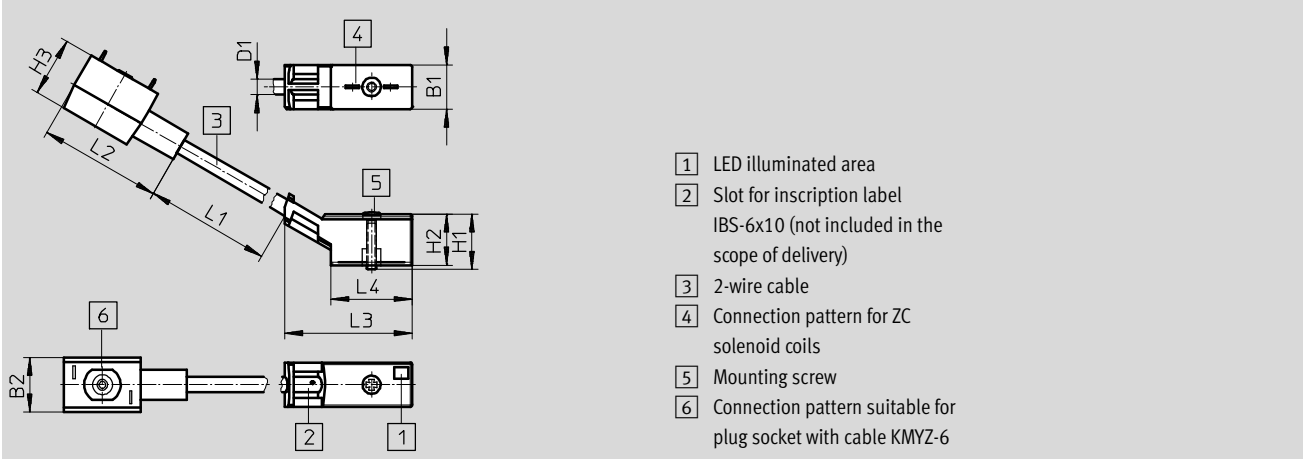


Type	B1	B2	D1 - Ø -	D2 - Ø -	D3 - Ø -	H1	H2	H3	L1	L2	L3	L4
KMYZ-9-24-2,5-LED-PUR-B	9.7	-	3.4	-	-	12.25	12.15	-	2,500	-	28.1	18
KMYZ-9-24-5-LED-PUR-B									5,000			
KMYZ-9-24-10-LED-PUR-B									10,000			
KMYZ-9-24-M8-0,5-LED-PUR	9.7	-	3.4	9.7	M8X1	12.25	12.15	-	500	41.1	28.1	18
KMYZ-9-24-M8-2,5-LED-PUR									2,500			
KMYZ-9-24-AD	9.7	12	3.4	-	-	12.25	12.15	13	200	27	28.1	18

Connecting cables NEBV, for valves

   Technical data

Ordering data						
	Electrical connection	Switching position display	Weight	Cable length	Part No.	Type
	Open cable end, 2-wire	LED	50 g	2.5 m	193687	KMYZ-9-24-2,5-LED-PUR-B
		LED	90 g	5 m	193689	KMYZ-9-24-5-LED-PUR-B
		LED	170 g	10 m	196063	KMYZ-9-24-10-LED-PUR-B
	Straight plug, M8x1, 3-pin	LED	18 g	0.5 m	196064	KMYZ-9-24-M8-0,5-LED-B
		LED	54 g	2.5 m	196065	KMYZ-9-24-M8-2,5-LED-B
	Angled plug, square design, 2-pin	LED	18 g	0.2 m	530942	KMYZ-9-24-AD-0,2-LED-B
		–	18 g	0.2 m	547449	KMYZ-9-24-AD-0,2-B

 Ordering data – Accessories			
	Description	Part No.	Type
	Inscription labels 6x10 mm, 64 pieces, in frames	18576	IBS-6x10