


Power supply units SVG



 
Power supply units SVG

Type codes

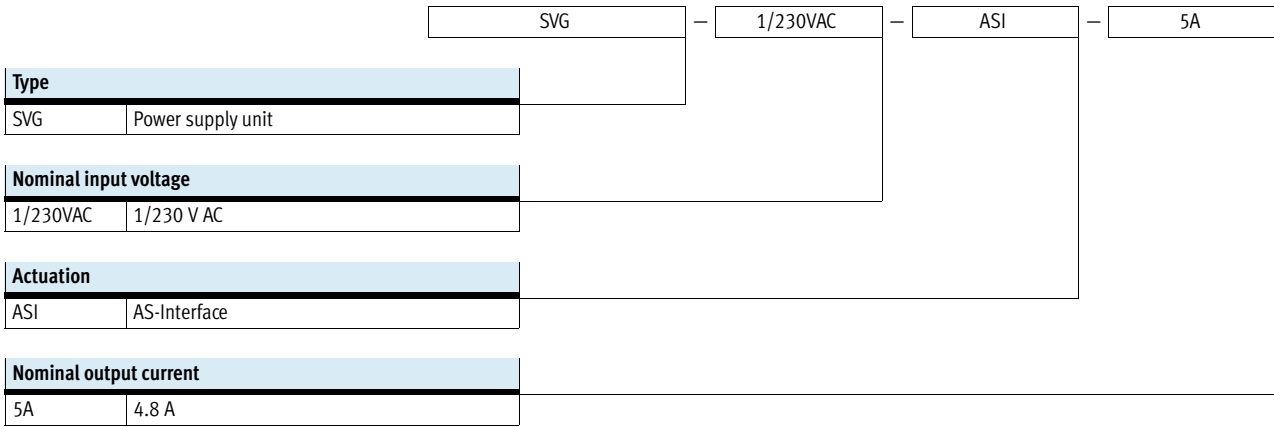

Power supply units SVG

Technical data

-  - Voltage
24 ... 48 V DC

Power supply units for AS-interface systems



General technical data		
Electrical		
Input voltage range	[V AC]	100 ... 240
Input current	[A]	2.1 ... 1.0
Nominal output voltage	[V DC]	30.1
Nominal output current	[A]	4.8
Mains voltage frequency	[Hz]	45 ... 65
Power failure buffering	[ms]	20
Primary supply		Single-phase
Mechanical		
Type of mounting		Via H-rail
Installation position		Free convection
Product weight	[g]	900


Operating and environmental conditions		
Ambient temperature	[°C]	-25 ... +70
Storage temperature	[°C]	-40 ... +85
Protection class		IP20
Relative air humidity	[%]	95
CE symbol (see declaration of conformity)		In accordance with EU EMC Directive
		In accordance with EU Low Voltage Directive
Certification		c UL us - Listed (OL)
		C-Tick

Power supply units SVG

Technical data


Dimensions

Download CAD data → www.festo.com

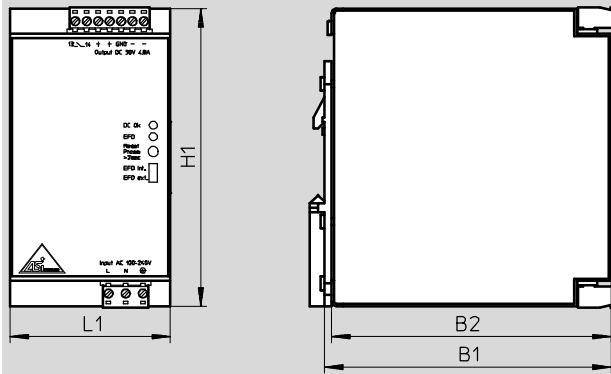

Type	B1	B2	H1	L1
SVG-1/230VAC-ASI-5A	125	122	130	70

Ordering data

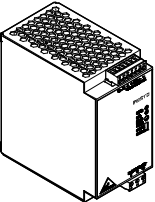	Application	Part No.	Type
	For AS-interface systems	547869	SVG-1/230VAC-ASI-5A