

Inscription label holders ASCF

Technical data

Inscription label holder IBT, VMPA1, CPX, CPVSC1-ST, CPV
Identification clip MN2H, MVH

Inscription label holders enable inscription labels to be attached to components without pre-assembled carriers, or with special carriers for holders of this type.

If display components are concealed by the inscription label holder, the carrier is either semi-transparent or completely transparent.



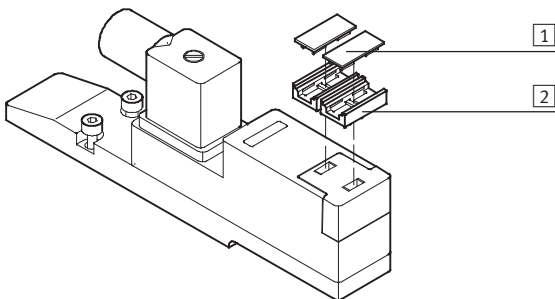
Note

Microsoft Word templates for inscription label holders/identification strips can be found at:
 → www.festo.com/us/engineering

Materials								
Type	MN2H	MVH	IBT	VMPA1-ST-1	VMPA1-ST-2	CPX	CPVSC1-ST	CPV
Inscription label holder	PA	PA	PC	PP	POM	PP	PVC	PVC

Examples illustrating the attachment of inscription label holders


MVH-BZ (similar to MN2H-BZT-...)



- 1 Inscription labels IBS-9x17
- 2 Inscription label holder MVH-BZ

- The inscription label holder is snapped into recesses on the valve
- The inscription is created using inscription labels

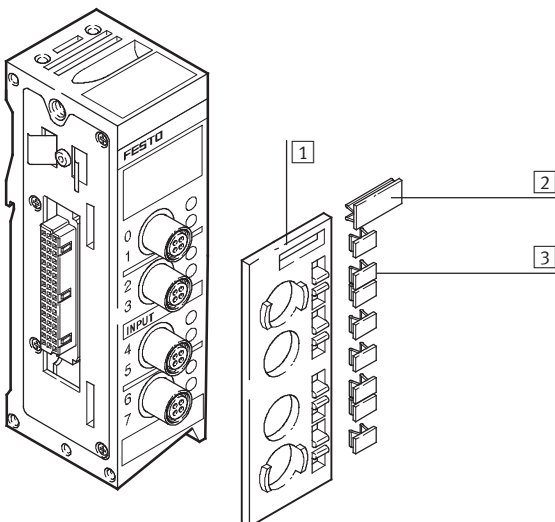IBT-...



- 1 Inscription label holder IBT-03...
- 2 Inscription label IBS-9x20
- 3 Inscription labels IBS-6x20


- The inscription label holder is pushed in
- The inscription is created using inscription labels

Inscription label holders ASCF

Technical data

Examples illustrating the attachment of inscription label holders

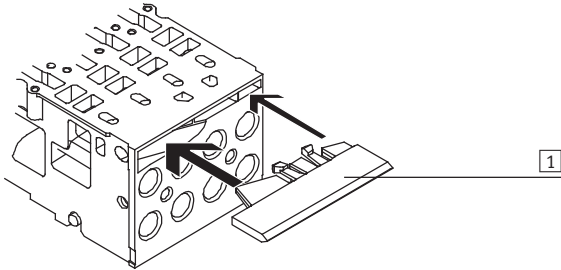
VMPA1-ST-...



1 Inscription label holder VMPA1-ST...

- The inscription label holder is snapped into recesses on the valve terminal
- The inscription is created by inserting identification strips

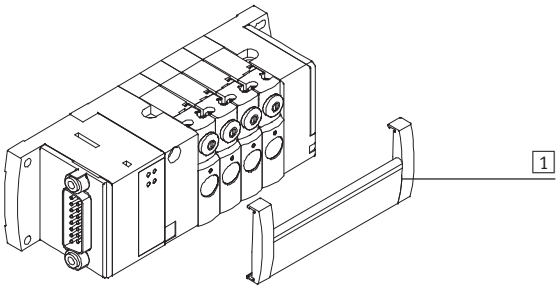
CPVSC1-ST-...



1 Inscription label holder CPVSC1-ST...

- The inscription label holder is clipped onto the valve terminal
- The inscription is created by inserting identification strips

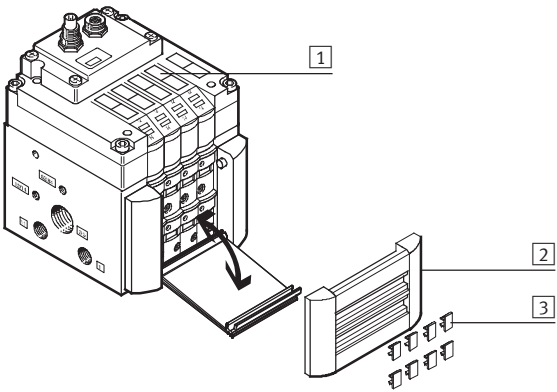CPV10-VI-...



1 Inscription labels IBS-9x20
2 Inscription label holder CPV10-VI-BZT...
3 Inscription labels IBS-6x10

- The inscription label holder is snapped into recesses on the valve terminal
- The inscription is created using inscription labels or by inserting identification strips

Note

 
 
 
 
 
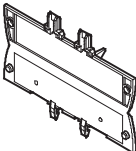
 
The inscription label holder cannot be used together with relay slices.

- 1 - Type discontinued
Available up until 2017

FESTO



Inscription label holders ASCF


Technical data

Ordering data						
	Carriers for inscription labels	Use	For modules with the following number of valves	Weight	Part No.	Type
				[g]		
	IBS-9x17 (1 piece)	Valve terminal type 14	-	7	161936	MN2H-BZT-10X
	IBS-9x17 (1 piece)	-	-	19	18575	MVH-BZ
	IBS-9x20 (3 pieces)	Valve terminal type 02	-	47	158968	IBT-02-E/A
	IBS-9x20 (1 piece) IBS-6x10 (8 pieces)	Modular electrical peripherals for valve terminal type 03/04	-	38	18183	IBT-03-E/A - 1
	Insertable label or paper/cardboard strips	Valve terminal type 32 MPA	-	6	533362	VMPA1-ST-1-4
	IBS-6x10 (4 pieces)	Valve terminal type 32 MPA	-	8	544384	VMPA1-ST-2-4
	Insertable label or paper/cardboard strips	Modular electrical terminal CPX	-	5	536593	CPX-ST-1
	Insertable label or paper/cardboard strips	Valve terminal type 80 CPV-SC	2	5	547395	CPVSC1-ST-2
			3	6	547396	CPVSC1-ST-3
			4	7	527631	CPVSC1-ST-4
			5	7	547397	CPVSC1-ST-5
			6	8	547398	CPVSC1-ST-6
			7	8	547399	CPVSC1-ST-7
			8	9	527633	CPVSC1-ST-8
			9	10	547400	CPVSC1-ST-9
			10	12	547401	CPVSC1-ST-10
			11	13	547402	CPVSC1-ST-11
			12	15	527635	CPVSC1-ST-12
			13	16	547403	CPVSC1-ST-13
			14	17	547404	CPVSC1-ST-14
15	18	547405	CPVSC1-ST-15			
16	20	527637	CPVSC1-ST-16			

Inscription label holders ASCF

  Technical data

Ordering data						
	Carriers for inscription labels	Use	For modules with the following number of valves	Weight	Part No.	Type
				[g]		
	IBS-6x10 (4 pieces)	Valve terminal type 10 CPV in size 10	2	9	162560	CPV10-VI-BZ-T-2
	IBS-6x10 (6 pieces)		3	10	162561	CPV10-VI-BZ-T-3
	IBS-6x10 (8 pieces)		4	11	162562	CPV10-VI-BZ-T-4
	IBS-6x10 (10 pieces)		5	15	162563	CPV10-VI-BZ-T-5
	IBS-6x10 (12 pieces)		6	14	162564	CPV10-VI-BZ-T-6
	IBS-6x10 (14 pieces)		7	15	162565	CPV10-VI-BZ-T-7
	IBS-6x10 (16 pieces)		8	16	162566	CPV10-VI-BZ-T-8
	IBS-6x10 (4 pieces)		Valve terminal type 10 CPV in size 14	2	10	162567
	IBS-6x10 (6 pieces)	3		11	162568	CPV14-VI-BZ-T-3
	IBS-6x10 (8 pieces)	4		13	162569	CPV14-VI-BZ-T-4
	IBS-6x10 (10 pieces)	5		15	162570	CPV14-VI-BZ-T-5
	IBS-6x10 (12 pieces)	6		16	162571	CPV14-VI-BZ-T-6
	IBS-6x10 (14 pieces)	7		19	162572	CPV14-VI-BZ-T-7
	IBS-6x10 (16 pieces)	8		21	162573	CPV14-VI-BZ-T-8
	IBS-6x10 (4 pieces)	Valve terminal type 10 CPV in size 18		2	11	163293
	IBS-6x10 (6 pieces)		3	12	163294	CPV18-VI-BZ-T-3
	IBS-6x10 (8 pieces)		4	17	163295	CPV18-VI-BZ-T-4
	IBS-6x10 (10 pieces)		5	18	163296	CPV18-VI-BZ-T-5
	IBS-6x10 (12 pieces)		6	20	163297	CPV18-VI-BZ-T-6
	IBS-6x10 (14 pieces)		7	23	163298	CPV18-VI-BZ-T-7
IBS-6x10 (16 pieces)	8		29	163299	CPV18-VI-BZ-T-8	
	Insertable label or paper/cardboard strips		Valve terminal type 10 CPV in size 10	2	8	194066
		3		10	194067	CPV10-VI-ST-3
		4		11	194068	CPV10-VI-ST-4
		5		13	194069	CPV10-VI-ST-5
		6		14	194070	CPV10-VI-ST-6
		7		15	194071	CPV10-VI-ST-7
		8		16	194072	CPV10-VI-ST-8
		Valve terminal type 10 CPV in size 14		2	10	194073
	3		11	194074	CPV14-VI-ST-3	
	4		14	194075	CPV14-VI-ST-4	
	5		15	194076	CPV14-VI-ST-5	
	6		20	194077	CPV14-VI-ST-6	
	7		19	194078	CPV14-VI-ST-7	
	8		22	194079	CPV14-VI-ST-8	
	Valve terminal type 10 CPV in size 18		2	11	194080	CPV18-VI-ST-2
		3	13	194081	CPV18-VI-ST-3	
		4	15	194082	CPV18-VI-ST-4	
		5	18	194083	CPV18-VI-ST-5	
		6	21	194084	CPV18-VI-ST-6	
		7	23	194085	CPV18-VI-ST-7	
8		28	194086	CPV18-VI-ST-8		

 Ordering data – Accessories			
	Description	Part No.	Type
	Inscription labels 6x10 mm, 64 pieces, in frames	18576	IBS-6x10
	Inscription labels 9x17 mm, 24 pieces, in frames	161937	IBS-9x17
	Inscription labels 9x20 mm, 20 pieces, in frames	18182	IBS-9x20

Product Range and Company Overview

A Complete Suite of Automation Services

Our experienced engineers provide complete support at every stage of your development process, including: conceptualization, analysis, engineering, design, assembly, documentation, validation, and production.



Custom Automation Components
Complete custom engineered solutions



Custom Control Cabinets
Comprehensive engineering support and on-site services



Complete Systems
Shipment, stocking and storage services

The Broadest Range of Automation Components

With a comprehensive line of more than 30,000 automation components, Festo is capable of solving the most complex automation requirements.



Electromechanical
Electromechanical actuators, motors, controllers & drives



Pneumatics
Pneumatic linear and rotary actuators, valves, and air supply



PLCs and I/O Devices
PLC's, operator interfaces, sensors and I/O devices

Supporting Advanced Automation... As No One Else Can!

Festo is a leading global manufacturer of pneumatic and electromechanical systems, components and controls for industrial automation, with more than 12,000 employees in 56 national headquarters serving more than 180 countries. For more than 80 years, Festo has continuously elevated the state of manufacturing with innovations and optimized motion control solutions that deliver higher performing, more profitable automated manufacturing and processing equipment. Our dedication to the advancement of automation extends beyond technology to the education and development of current and future automation and robotics designers with simulation tools, teaching programs, and on-site services.

Quality Assurance, ISO 9001 and ISO 14001 Certifications

Festo Corporation is committed to supply all Festo products and services that will meet or exceed our customers' requirements in product quality, delivery, customer service and satisfaction.

To meet this commitment, we strive to ensure a consistent, integrated, and systematic approach to management that will meet or exceed the requirements of the ISO 9001 standard for Quality Management and the ISO 14001 standard for Environmental Management.



© Copyright 2008, Festo Corporation. While every effort is made to ensure that all dimensions and specifications are correct, Festo cannot guarantee that publications are completely free of any error, in particular typing or printing errors. Accordingly, Festo cannot be held responsible for the same. For Liability and Warranty conditions, refer to our "Terms and Conditions of Sale", available from your local Festo office. All rights reserved. No part of this publication may be reproduced, distributed, or transmitted in any form or by any means, electronic, mechanical, photocopying or otherwise, without the prior written permission of Festo. All technical data subject to change according to technical update.



Printed on recycled paper at New Horizon Graphic, Inc., FSC certified as an environmentally friendly printing plant.

Festo North America

Festo Regional Contact Center

5300 Explorer Drive
Mississauga, Ontario L4W 5G4
Canada

USA Customers:

For ordering assistance,

Call: 1.800.99.FESTO (1.800.993.3786)

Fax: 1.800.96.FESTO (1.800.963.3786)

Email: customer.service@us.festo.com

For technical support,

Call: 1.866.GO.FESTO (1.866.463.3786)

Fax: 1.800.96.FESTO (1.800.963.3786)

Email: product.support@us.festo.com

Canadian Customers:

Call: 1.877.GO.FESTO (1.877.463.3786)

Fax: 1.877.FX.FESTO (1.877.393.3786)

Email: festo.canada@ca.festo.com

USA Headquarters

Festo Corporation
395 Moreland Road
P.O. Box 18023
Hauppauge, NY 11788, USA
www.festo.com/us

USA Sales Offices

Appleton

North 922 Tower View Drive, Suite N
Greenville, WI 54942, USA

Boston

120 Presidential Way, Suite 330
Woburn, MA 01801, USA

Chicago

1441 East Business Center Drive
Mt. Prospect, IL 60056, USA

Dallas

1825 Lakeway Drive, Suite 600
Lewisville, TX 75057, USA

Detroit – Automotive Engineering Center

2601 Cambridge Court, Suite 320
Auburn Hills, MI 48326, USA

New York

395 Moreland Road
Hauppauge, NY 11788, USA

Silicon Valley

4935 Southfront Road, Suite F
Livermore, CA 94550, USA

United States



USA Headquarters, East: Festo Corp., 395 Moreland Road, Hauppauge, NY 11788

Phone: 1.631.435.0800; Fax: 1.631.435.8026;

Email: info@festo-usa.com

www.festo.com/us

Canada



Headquarters: Festo Inc., 5300 Explorer Drive, Mississauga, Ontario L4W 5G4

Phone: 1.905.624.9000; Fax: 1.905.624.9001;

Email: festo.canada@ca.festo.com

www.festo.ca

Mexico



Headquarters: Festo Pneumatic, S.A., Av. Ceylán 3, Col. Tequesquahuac,
54020 Tlalneantla, Edo. de México

Phone: 011 52 [55] 53 21 66 00; Fax: 011 52 [55] 53 21 66 65;

Email: festo.mexico@mx.festo.com

www.festo.com/mx

Central USA

Festo Corporation
1441 East Business
Center Drive
Mt. Prospect, IL 60056, USA
Phone: 1.847.759.2600
Fax: 1.847.768.9480



Western USA

Festo Corporation
4935 Southfront Road,
Suite F
Livermore, CA 94550, USA
Phone: 1.925.371.1099
Fax: 1.925.245.1286



Festo Worldwide

Argentina Australia Austria Belarus Belgium Brazil Bulgaria Canada Chile China Colombia Croatia Czech Republic Denmark
Estonia Finland France Germany Great Britain Greece Hong Kong Hungary India Indonesia Iran Ireland Israel Italy Japan Latvia
Lithuania Malaysia Mexico Netherlands New Zealand Norway Peru Philippines Poland Romania Russia Serbia Singapore
Slovakia Slovenia South Africa South Korea Spain Sweden Switzerland Taiwan Thailand Turkey Ukraine United States Venezuela

www.festo.com