

Connecting cables NEBV, for valves

Technical data

Connecting cable KMYZ-9

- Connecting cable for valves with ZC solenoid coils (CPE10/CPE14)
- Pre-assembled
- Cable lengths 0.2 to 10 m



General technical data				
Type	KMYZ-9-24-...-PUR-B	KMYZ-9-24-M8-...-LED-B	KMYZ-9-24-AD-0,2-LED-B	KMYZ-9-24-AD-0,2-B
Electrical connection	Angled socket, 2-pin, square design			
	Open cable end, 2-wire	Straight plug, 3-pin, M8x1	Angled plug, 2-pin, square design	Angled plug, 2-pin, square design
Switching position display	LED	LED	LED	-
Additional functions	Reduction of retaining current	Reduction of retaining current	Reduction of retaining current	-
Nominal operating voltage [V DC]	24			
Cable composition [mm ²]	2x0.25			
Cable diameter [mm]	3.4			
Protective earth connection	No			
Type of mounting	On solenoid valve via M2 central screw			
Tightening torque [Nm]	0.25			
Mounting position	Any			
Protection class to EN 60529	IP65 (assembled)			

Materials	
Housing	Polyamide
Pin contact	Bronze
Cable sheath	TPE-U(PUR)
Note on materials	RoHS-compliant

Operating and environmental conditions	
Ambient temperature [°C]	-10 ... +50
CE marking (see declaration of conformity)	To EU EMC Directive

Connecting cables NEBV, for valves


Technical data




Dimensions

Download CAD data → www.festo.com


KMYZ-9-24

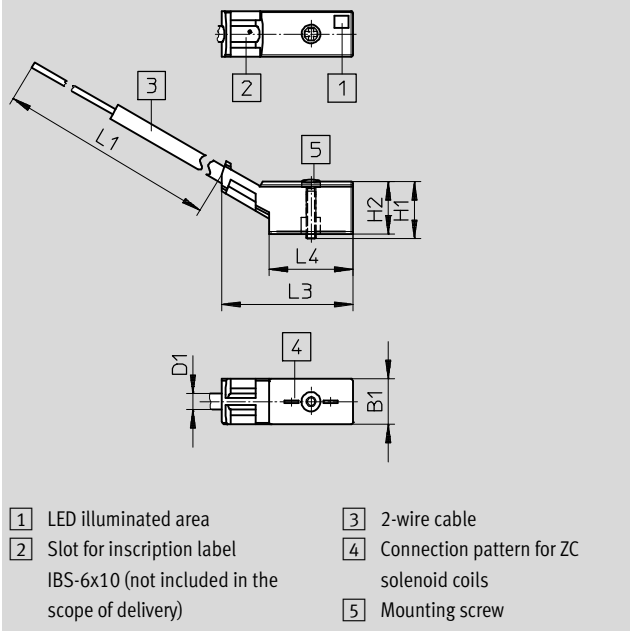

KMYZ-9-24-M8

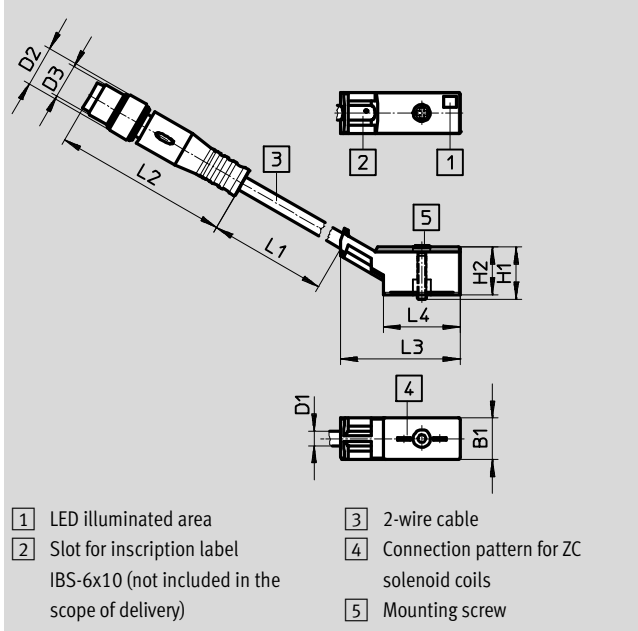




KMYZ-9-24-AD

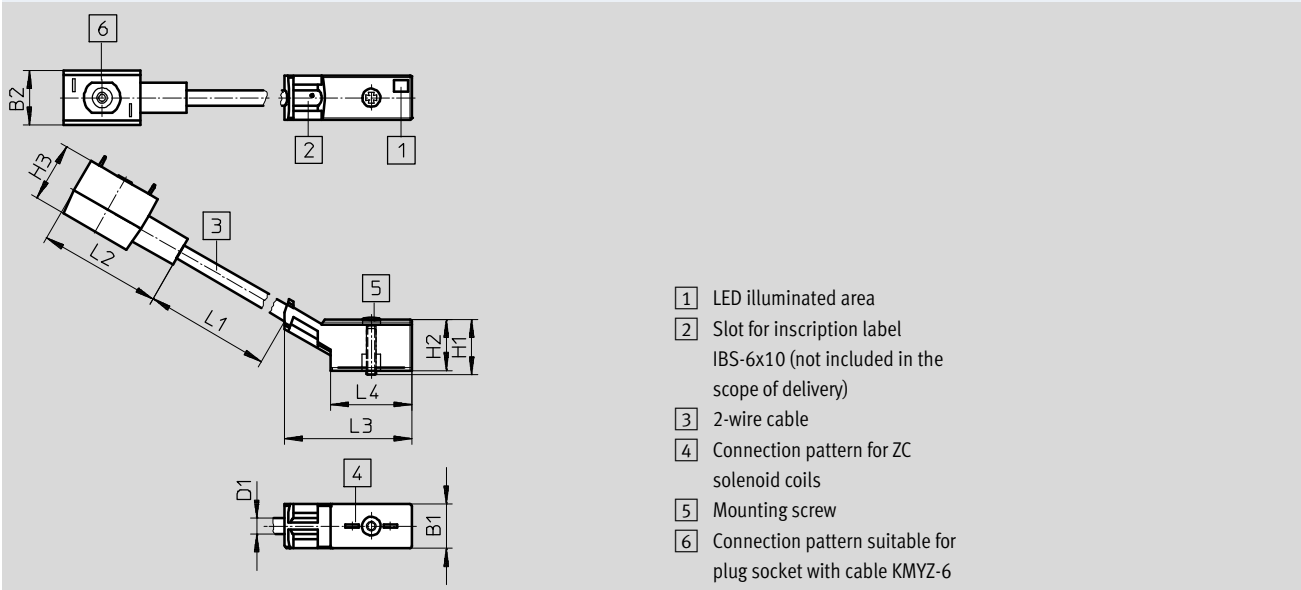


Type	B1	B2	D1	D2	D3	H1	H2	H3	L1	L2	L3	L4
KMYZ-9-24-2,5-LED-PUR-B	9.7	-	3.4	-	-	12.25	12.15	-	2,500	-	28.1	18
KMYZ-9-24-5-LED-PUR-B									5,000			
KMYZ-9-24-10-LED-PUR-B									10,000			
KMYZ-9-24-M8-0,5-LED-PUR	9.7	-	3.4	9.7	M8X1	12.25	12.15	-	500	41.1	28.1	18
KMYZ-9-24-M8-2,5-LED-PUR									2,500			
KMYZ-9-24-AD	9.7	12	3.4	-	-	12.25	12.15	13	200	27	28.1	18

Connecting cables NEBV, for valves

   Technical data


Ordering data						
	Electrical connection	Switching position display	Weight	Cable length	Part No.	Type
	Open cable end, 2-wire	LED	50 g	2.5 m	193687	KMYZ-9-24-2,5-LED-PUR-B
		LED	90 g	5 m	193689	KMYZ-9-24-5-LED-PUR-B
		LED	170 g	10 m	196063	KMYZ-9-24-10-LED-PUR-B
	Straight plug, M8x1, 3-pin	LED	18 g	0.5 m	196064	KMYZ-9-24-M8-0,5-LED-B
		LED	54 g	2.5 m	196065	KMYZ-9-24-M8-2,5-LED-B
	Angled plug, square design, 2-pin	LED	18 g	0.2 m	530942	KMYZ-9-24-AD-0,2-LED-B
		-	18 g	0.2 m	547449	KMYZ-9-24-AD-0,2-B

 Ordering data – Accessories			
	Description	Part No.	Type
	Inscription labels 6x10 mm, 64 pieces, in frames	18576	IBS-6x10

Product Range and Company Overview

A Complete Suite and Company Overview


Our experienced engineers provide complete support at every stage of your development process, including: conceptualization, analysis, engineering, design, assembly, documentation, validation, and production.

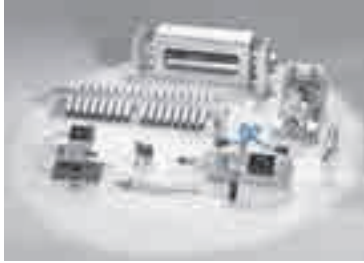

Custom Automation Components
Complete custom engineered solutions



Custom Control Cabinets
Comprehensive engineering support and on-site services

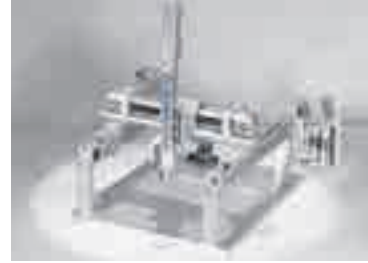

Complete Systems
Shipment, stocking and storage services

The Broadest Range of Automation Components

With a comprehensive line of more than 30,000 automation components, Festo is capable of solving the most complex automation requirements.



Electromechanical
Electromechanical actuators, motors, controllers & drivers



Pneumatics
Pneumatic linear and rotary actuators, valves, and air supply



PLCs and I/O Devices
PLC's, operator interfaces, sensors and I/O devices

Supporting Advanced Automation... As No One Else Can!

Festo is a leading global manufacturer of pneumatic and electromechanical systems, components and controls for industrial automation, with more than 16,000 employees in 60 national headquarters serving more than 180 countries. For more than 80 years, Festo has continuously elevated the state of manufacturing with innovations and optimized motion control solutions that deliver higher performing, more profitable automated manufacturing and processing equipment. Our dedication to the advancement of automation extends beyond technology to the education and development of current and future automation and robotics designers with simulation tools, teaching programs, and on-site services.

Quality Assurance, ISO 9001 and ISO 14001 Certifications

Festo Corporation is committed to supply all Festo products and services that will meet or exceed our customers' requirements in product quality, delivery, customer service and satisfaction.

To meet this commitment, we strive to ensure a consistent, integrated, and systematic approach to management that will meet or exceed the requirements of the ISO 9001 standard for Quality Management and the ISO 14001 standard for Environmental Management.




© Copyright 2013, Festo Corporation. While every effort is made to ensure that all dimensions and specifications are correct, Festo cannot guarantee that publications are completely free of any error, in particular typing or printing errors. Accordingly, Festo cannot be held responsible for the same. For Liability and Warranty conditions, refer to our "Terms and Conditions of Sale", available from your local Festo office. All rights reserved. No part of this publication may be reproduced, distributed, or transmitted in any form or by any means, electronic, mechanical, photocopying or otherwise, without the prior written permission of Festo. All technical data subject to change according to technical update.



Printed on recycled paper at New Horizon Graphic, Inc., FSC certified as an environmental friendly printing plant.

Festo North America

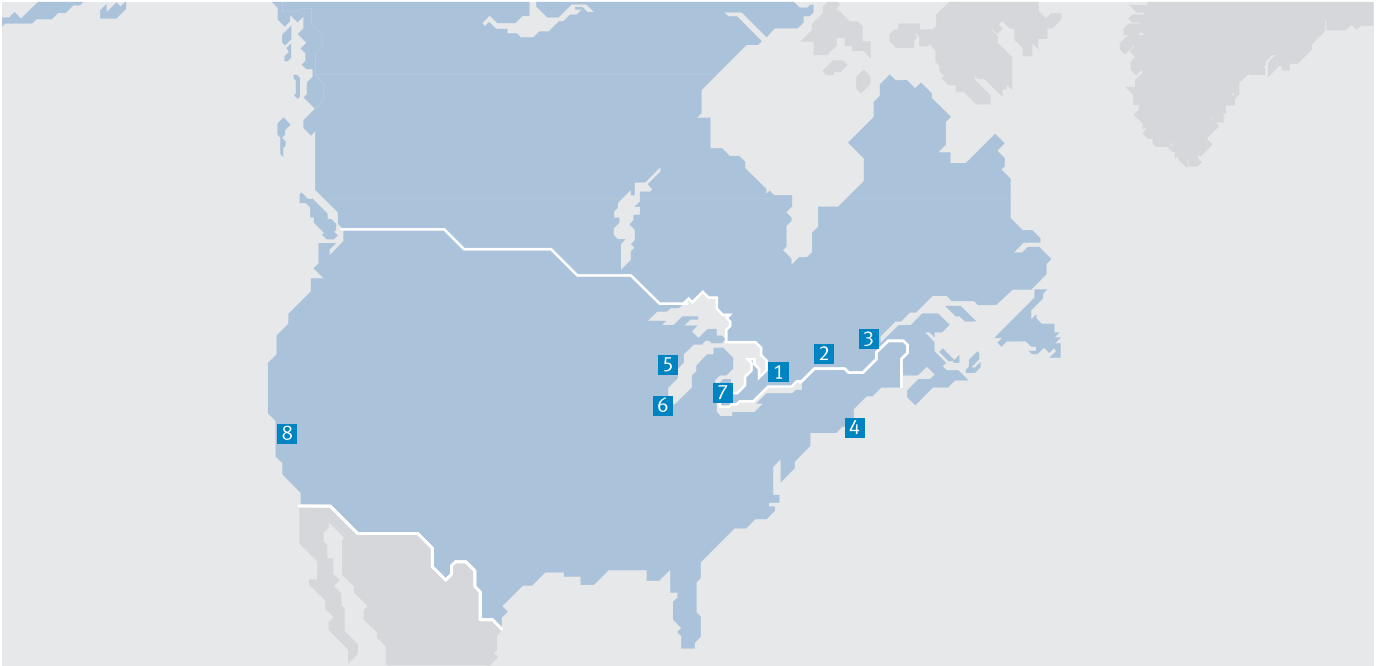

**1 Festo Canada
Headquarters
Festo Inc.**
5300 Explorer Drive
Mississauga, ON
L4W 5G4

2 Montréal
5600, Trans-Canada
Pointe-Claire, QC
H9R 1B6

3 Québec City
2930, rue Watt#117
Québec, QC
G1X 4G3



**4 Festo United States
Headquarters
Festo Corporation**
395 Moreland Road
Hauppauge, NY
11788

5 Appleton
North 922 Tower View Drive, Suite N
Greenville, WI
54942

7 Detroit
1441 West Long Lake Road
Troy, MI
48098

6 Chicago
85 W Algonquin - Suite 340
Arlington Heights, IL
60005

8 Silicon Valley
4935 Southfront Road, Suite F
Livermore, CA
94550

Festo Regional Contact Center

Canadian Customers

Commercial Support:
Tel: 1 877 GO FESTO (1 877 463 3786)
Fax: 1 877 FX FESTO (1 877 393 3786)
Email: festo.canada@ca.festo.com

Technical Support:
Tel: 1 866 GO FESTO (1 866 463 3786)
Fax: 1 877 FX FESTO (1 877 393 3786)
Email: technical.support@ca.festo.com

USA Customers

Commercial Support:
Tel: 1 800 99 FESTO (1 800 993 3786)
Fax: 1 800 96 FESTO (1 800 963 3786)
Email: customer.service@us.festo.com

Technical Support:
Tel: 1 866 GO FESTO (1 866 463 3786)
Fax: 1 800 96 FESTO (1 800 963 3786)
Email: product.support@us.festo.com