

Check Valves, Ball Valves, and Shutoff Valves – Inch Series

Quick Star Flow/Pressure Controls

Check Valve
Housing: Black Anodized
Aluminum, Nickel-plated Brass



Ordering Data		
Part No.	Type	For Tubing O.D. D1 [inch]
190841	H-QSM-5/32-U	5/32
190842	H-QSM-3/16-U	3/16
190843	H-QS-1/4-U	1/4
190844	H-QS-5/16-U	5/16
190845	H-QS-3/8-U	3/8
190846	H-QS-1/2-U	1/2

These check valves block air flow when tubing is removed.

Check Valve, UNF/NPT, Flow
Towards Push-in Connector
Housing: Nickel-plated Brass



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190847	HA-10-32-UNF-QSM-5/32-U	10-32	5/16	5/16
190848	HA-1/8-QSM-5/32-U	1/8	5/32	7/16
190849	HA-1/8-QSM-3/16-U	1/8	3/16	7/16
190850	HA-1/8-QS-1/4-U	1/8	1/4	9/16
190851	HA-18-QS-5/16-U	1/8	5/16	9/16
190852	HA-1/4-QSM-3/16-U	1/4	3/16	9/16
190853	HA-1/4-QS-1/4-U	1/4	1/4	9/16
190854	HA-1/4-QS-5/16-U	1/4	5/16	9/16
190855	HA-3/8-QS-3/8-U	3/8	3/8	1
190856	HA-1/2-QS-3/8-U	1/2	3/8	1 1/8

Check Valve, UNF/NPT, Flow
Towards Threaded Connection
Housing: Nickel-plated Brass



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190857	HB-10-32-UNF-QSM-5/32-U	10-32	5/32	5/16
190858	HB-1/8-QSM-5/32-U	1/8	5/32	7/16
190859	HB-1/8-QSM-3/16-U	1/8	3/16	7/16
190860	HB-1/8-QS-1/4-U	1/8	1/4	9/16
190861	HB-1/8-QS-5/16-U	1/8	5/16	9/16
190862	HB-1/4-QSM-3/16-U	1/4	3/16	9/16
190863	HB-1/4-QS-1/4-U	1/4	1/4	9/16
190864	HB-1/4-QS-5/16-U	1/4	5/16	9/16
190865	HB-3/8-QS-3/8-U	3/8	3/8	1
190866	HB-1/2-QS-3/8-U	1/2	3/8	1 1/8

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
 Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Check Valves, Ball Valves, and Shutoff Valves – Inch Series

Quick Star Flow/Pressure Controls

Ball Valve with Hand Lever and Two Connectors
Housing: Polymer



Ordering Data		
Part No.	Type	For Tubing O.D. D1 [inch]
190880	QH-QS-1/8-U	1/8
190881	QH-QS-5/32-U	5/32
190882	QH-QS-3/16-U	3/16
	Butterfly Lever (not shown)	
190883	QH-QS-1/4-U	1/4

Ball Valve, NPT, with Hand Lever, Connector, and Fitting
Housing: Polymer



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190886	QH-QS-1/8-1/8-NPT-U	1/8	1/8	13/32
190887	QH-QS-5/32-1/8-NPT-U	1/8	5/32	13/32
190888	QH-QS-5/32-1/4-NPT-U	1/4	5/32	9/16
190889	QH-QS-3/16-1/4-NPT-U	1/4	3/16	9/16

Bulkhead Ball Valve, with Hand/Butterfly Lever, and Two Connectors
Housing: Polymer



Ordering Data				
Part No.	Type	For Tubing O.D. D1 [inch]	Wrench Size [inch]	
			WS1	WS2
	Hand Lever			
190884	QHS-QS-1/8-U	1/8	9/16	9/16
	Butterfly Lever (not shown)			
190885	QHS-QS-1/4-U	1/4	3/4	11/16

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Check Valves, Ball Valves, and Shutoff Valves – Inch Series


Quick Star Flow/Pressure Controls

Shutoff Valve 2/2-way, with Two Connectors
Housing: Polymer



Ordering Data		
Part No.	Type	For Tubing O.D. D1 [inch]
153980	HE-2-QS-3/16-U	3/16
153981	HE-2-QS-1/4-U	1/4
153982	HE-2-QS-5/16-U	5/16
153983	HE-2-QS-3/8-U	3/8
153984	HE-2-QS-1/2-U	1/2

Shutoff Valve 2/2-way, NPT, with Connector and Fitting
Housing: Polymer

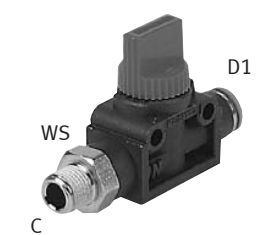

Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153989	HE-2-1/8-QS-3/16-U	1/8	3/16	9/16
153990	HE-2-1/4-QS-1/4-U	1/4	1/4	9/16
190867	HE-2-1/4-QS-5/16-U	1/4	5/16	9/16
190868	HE-2-3/8-QS-5/16-U	3/8	5/16	11/16
153991	HE-2-3/8-QS-3/8-U	3/8	3/8	7/8
153992	HE-2-1/2-QS-1/2-U	1/2	1/2	1

Shutoff Valve 3/2-way, with Two Connectors
Housing: Polymer



Ordering Data		
Part No.	Type	For Tubing O.D. D1 [inch]
153975	HE-3-QS-3/16-U	3/16
153976	HE-3-QS-1/4-U	1/4
153977	HE-3-QS-5/16-U	5/16
153978	HE-3-QS-3/8-U	3/8
143979	HE-3-QS-1/2-U	1/2


HE-3 Shutoff Valves exhaust to atmosphere.

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Check Valves, Ball Valves, and Shutoff Valves – Inch Series

Quick Star Flow/Pressure Controls


**Shutoff Valve 3/2-way, NPT,
Flow Towards Push-in
Connector Housing: Polymer**

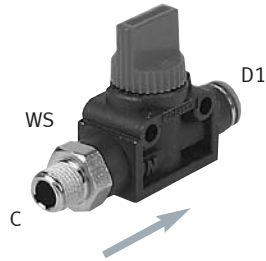

Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153985	HE-3-1/8-QS-3/16-U	1/8	3/16	9/16
153986	HE-3-1/4-QS-1/4-U	1/4	1/4	9/16
190869	HE-3-1/4-QS-5/16-U	1/4	5/16	9/16
190870	HE-3-3/8-QS-5/16-U	3/8	5/16	11/16
153987	HE-3-3/8-QS-3/8-U	3/8	3/8	7/8
153988	HE-3-1/2-QS-1/2-U	1/2	1/2	1

HE-3 Shutoff Valves exhaust to atmosphere.

**Shutoff Valve 3/2-way, NPT,
Flow Towards Threaded
Connection
Housing: Polymer**

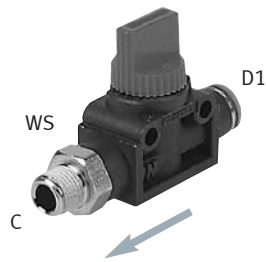

Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190871	HE-3A-1/8-QS-3/16-U	1/8	3/16	9/16
190872	HE-3A-1/4-QS-1/4-U	1/4	1/4	9/16
190873	HE-3A-1/4-QS-5/16-U	1/4	5/16	9/16
190874	HE-3A-3/8-QS-5/16-U	3/8	5/16	11/16
190875	HE-3A-3/8-QS-3/8-U	3/8	3/8	11/16
190876	HE-3A-1/2-QS-1/2-U	1/2	1/2	7/8

HE-3 Shutoff Valves exhaust to atmosphere.

**Shutoff Valve 3/2-way, NPT,
with Two Fittings
Housing: Polymer**



Ordering Data			
Part No.	Type	Thread C	Wrench Size [inch]
190877	HE-3-1/8-1/8-NPT-U	1/8	9/16
190878	HE-3-1/4-1/4-NPT-U	1/4	11/16
190879	HE-3-3/8-3/8-NPT-U	3/8	11/16

HE-3 Shutoff Valves exhaust to atmosphere.

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Product Range and Company Overview

A Complete Suite of Automation Services

Our experienced engineers provide complete support at every stage of your development process, including: conceptualization, analysis, engineering, design, assembly, documentation, validation, and production.



Custom Automation Components
Complete custom engineered solutions



Custom Control Cabinets
Comprehensive engineering support and on-site services



Complete Systems
Shipment, stocking and storage services

The Broadest Range of Automation Components

With a comprehensive line of more than 30,000 automation components, Festo is capable of solving the most complex automation requirements.



Electromechanical
Electromechanical actuators, motors, controllers & drives



Pneumatics
Pneumatic linear and rotary actuators, valves, and air supply



PLCs and I/O Devices
PLC's, operator interfaces, sensors and I/O devices

Supporting Advanced Automation... As No One Else Can!

Festo is a leading global manufacturer of pneumatic and electromechanical systems, components and controls for industrial automation, with more than 12,000 employees in 56 national headquarters serving more than 180 countries. For more than 80 years, Festo has continuously elevated the state of manufacturing with innovations and optimized motion control solutions that deliver higher performing, more profitable automated manufacturing and processing equipment. Our dedication to the advancement of automation extends beyond technology to the education and development of current and future automation and robotics designers with simulation tools, teaching programs, and on-site services.

Quality Assurance, ISO 9001 and ISO 14001 Certifications

Festo Corporation is committed to supply all Festo products and services that will meet or exceed our customers' requirements in product quality, delivery, customer service and satisfaction.

To meet this commitment, we strive to ensure a consistent, integrated, and systematic approach to management that will meet or exceed the requirements of the ISO 9001 standard for Quality Management and the ISO 14001 standard for Environmental Management.



© Copyright 2008, Festo Corporation. While every effort is made to ensure that all dimensions and specifications are correct, Festo cannot guarantee that publications are completely free of any error, in particular typing or printing errors. Accordingly, Festo cannot be held responsible for the same. For Liability and Warranty conditions, refer to our "Terms and Conditions of Sale", available from your local Festo office. All rights reserved. No part of this publication may be reproduced, distributed, or transmitted in any form or by any means, electronic, mechanical, photocopying or otherwise, without the prior written permission of Festo. All technical data subject to change according to technical update.



Printed on recycled paper at New Horizon Graphic, Inc., FSC certified as an environmentally friendly printing plant.

Festo North America

United States

Customer Resource Center
502 Earth City Expy., Suite 125
Earth City, MO 63045

For ordering assistance, or to find
your nearest Festo Distributor,

Call: 1.800.99.FESTO

Fax: 1.800.96.FESTO

Email: customer.service@us.festo.com

For technical support,

Call: 1.866.GO.FESTO

Fax: 1.800.96.FESTO

Email: product.support@us.festo.com

Headquarters

Festo Corporation
395 Moreland Road
P.O. Box 18023
Hauppauge, NY 11788
www.festo.com/us

Sales Offices

Appleton

N. 922 Tower View Drive, Suite N
Greenville, WI 54942

Boston

120 Presidential Way, Suite 330
Woburn, MA 01801

Chicago

1441 East Business Center Drive
Mt. Prospect, IL 60056

Dallas

1825 Lakeway Drive, Suite 600
Lewisville, TX 75057

Detroit - Automotive Engineering Center

2601 Cambridge Court, Suite 320
Auburn Hills, MI 48326

New York

395 Moreland Road
Hauppauge, NY 11788

Silicon Valley

4935 Southfront Road, Suite F
Livermore, CA 94550

Design and Manufacturing Operations



East: 395 Moreland Road, Hauppauge, NY 11788



Central: 1441 East Business Center Drive, Mt. Prospect, IL 60056



West: 4935 Southfront Road, Suite F, Livermore, CA 94550

Mexico

Headquarters

Festo Pneumatic, S.A.
Av. Ceylán 3, Col. Tequesquahuac
54020 Tlalnepantla, Edo. de México
Call: 011 52 [55] 53 21 66 00
Fax: 011 52 [55] 53 21 66 65
Email: festo.mexico@mx.festo.com
www.festo.com/mx



Canada

Headquarters

Festo Inc.
5300 Explorer Drive
Mississauga, Ontario L4W 5G4
Call: 1.905.624.9000
Fax: 1.905.624.9001
Email: info.ca@ca.festo.com
www.festo.com/ca



Festo Worldwide

Argentina Australia Austria Belarus Belgium Brazil Bulgaria Canada Chile China Colombia Croatia Czech Republic Denmark
Estonia Finland France Germany Great Britain Greece Hong Kong Hungary India Indonesia Iran Ireland Israel Italy Japan
Latvia Lithuania Malaysia Mexico Netherlands New Zealand Norway Peru Philippines Poland Romania Russia Serbia Singapore
Slovakia Slovenia South Africa South Korea Spain Sweden Switzerland Taiwan Thailand Turkey Ukraine United States Venezuela

www.festo.com