

Quick Star Push-in Fittings – Inch Series



QSM Mini Series:
Thread Sizes: 10-32 UNF and
from 1/16 NPT to 1/4 NPT

QS Standard Series:
Thread Sizes: 10-32 UNF and
from 1/16 NPT to 1/2 NPT

QS Rotary with Ball Bearings:
Thread Sizes: 5/32 NPT
to 1/2 NPT

For complete dimensional
and technical information,
visit: www.festo.com/us
and view our online catalog,
or contact your Product
Support team via:
Phone: 1.800.99.FESTO
(1.800.993.3786)
Email: product.support@us.festo.com

Quick Star Push-in Fittings – Inch Series

1

1.1

Push-in Straight Fitting, UNF



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153901*	QSM-10-32-UNF-1/8-U	10-32	1/8	5/16
164852*	QSM-10-32-UNF-5/32-U	10-32	5/32	5/16
164851	QS-10-32-UNF-3/16-U	10-32	3/16	1/2
164850	QS-10-32-UNF-1/4-U	10-32	1/4	1/2

Push-in Straight Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153902*	QSM-1/16-1/8-U	1/16	1/8	5/16
190676*	QSM-1/6-5/32-U	1/16	5/32	7/16
153930*	QSM-1/8-1/8-U	1/8	1/8	7/16
190677*	QSM-1/8-5/32-U	1/8	5/32	7/16
190680*	QSM-1/4-1/8-U	1/4	1/8	9/16
192802*	QS-1/16-5/32-U	1/16	5/32	7/16
192803*	QS-1/16-3/16-U	1/16	3/16	1/2
190678*	QS-1/16-1/4-U	1/16	1/4	1/2
153601*	QS-1/8-5/32-U	1/8	5/32	7/16
153603*	QS-1/8-3/16-U	1/8	3/16	1/2
153605*	QS-1/8-1/4-U	1/8	1/4	1/2
153608*	QS-1/8-5/16-U	1/8	5/16	9/16
190679*	QS-1/8-3/8-U	1/8	3/8	11/16
153602*	QS-1/4-5/32-U	1/4	5/32	9/16
153604*	QS-1/4-3/16-U	1/4	3/16	9/16
153606*	QS-1/4-1/4-U	1/4	1/4	9/16
153609*	QS-1/4-5/16-U	1/4	5/16	9/16
153611*	QS-1/4-3/8-U	1/4	3/8	11/16
190681*	QS-1/4-1/2-U	1/4	1/2	7/8
153607*	QS-3/8-1/4-U	3/8	1/4	11/16
153610*	QS-3/8-5/16-U	3/8	5/16	11/16
153612*	QS-3/8-3/8-U	3/8	3/8	11/16
153614	QS-3/8-1/2-U	3/8	1/2	7/8
153613*	QS-1/2-3/8-U	1/2	3/8	7/8
153615	QS-1/2-1/2-U	1/2	1/2	7/8
190682*	QS-1/2-5/8-U	1/2	5/8	1

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series

Push-in Straight Fitting, UNF, with Female Thread



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153904*	QSMF-10-32-UNF-1/8-U	10-32	1/8	5/16
190699*	QSMF-10-32-UNF-5/32-U	10-32	5/32	5/16
190700*	QSF-10-32-UNF-3/16-U	10-32	3/16	1/2
190701*	QSF-10-32-UNF-1/4-U	10-32	1/4	1/2

Push-in Straight Fitting, NPT, with Female Thread



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153616*	QSF-1/8-5/32-U	1/8	5/32	9/16
153618*	QSF-1/8-3/16-U	1/8	3/16	9/16
153620*	QSF-1/8-1/4-U	1/8	1/4	9/16
153622*	QSF-1/8-5/16-U	1/8	5/16	9/16
190702*	QSF-1/8-3/8-U	1/8	3/8	11/16
153617*	QSF-1/4-5/32-U	1/4	5/32	11/16
153619*	QSF-1/4-3/16-U	1/4	3/16	11/16
153621*	QSF-1/4-1/4-U	1/4	1/4	11/16
153623*	QSF-1/4-5/16-U	1/4	5/16	11/16
153625*	QSF-1/4-3/8-U	1/4	3/8	11/16
153624*	QSF-3/8-5/16-U	3/8	5/16	7/8
153626*	QSF-3/8-3/8-U	3/8	3/8	7/8
153627	QSF-3/8-1/2-U	3/8	1/2	7/8

Push-in Straight Fitting, UNF, with Internal Hex



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190683*	QSM-10-32-UNF-1/8-I-U	10-32	1/8	5/64
190684*	QSM-10-32-UNF-5/32-I-U	10-32	5/32	3/32
190686*	QSM-10-32-UNF-3/16-I-U	10-32	3/16	3/32
190687*	QS-10-32-UNF-1/4-I-U	10-32	1/4	3/32

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series

1

1.1

Push-in Straight Fitting, NPT, with Internal Hex



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190685*	QSM-1/8-5/32-I-U	1/8	5/32	3/32
190689*	QSM-1/8-3/16-I-U	1/8	3/16	1/8
190688*	QS-1/8-5/32-I-U	1/8	5/32	3/32
190690*	QS-1/8-1/4-I-U	1/8	1/4	5/32
190691*	QS-1/8-5/16-I-U	1/8	5/16	3/16
190692*	QS-1/4-1/4-I-U	1/4	1/4	5/32
190693*	QS-1/4-5/16-I-U	1/4	5/16	7/32
190694*	QS-1/4-3/8-U	1/4	3/8	7/32
190695*	QS-3/8-5/16-I-U	3/8	5/16	7/32
190696*	QS-3/8-3/8-I-U	3/8	3/8	7/32
190697*	QS-3/8-1/2-I-U	3/8	1/2	5/16
190698*	QS-1/2-1/2-I-U	1/2	1/2	5/16

Push-in Straight Fitting, UNF, with Internal Shut-off



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190703	QSMK-10-32-UNF-1/8-U	10-32	1/8	3/8
190704	QSMK-10-32-UNF-5/32-U	10-32	5/32	3/8
190706	QSMK-10-32-UNF-3/16-U	10-32	3/16	7/16
190707	QSK-10-32-UNF-1/4-U	10-32	1/4	1/2

Push-in Straight Fitting, NPT, with Internal Shut-off



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
192804	QSMK-1/16-1/8-U	1/16	1/8	3/8
192805	QSMK-1/16-5/32-U	1/16	5/32	3/8
192806	QSMK-1/16-3/16-U	1/16	3/16	7/16
192705	QSMK-1/8-5/32-U	1/8	5/32	7/16
190709	QSMK-1/8-3/16-U	1/8	3/16	7/16
192807	QSK-1/16-1/4-U	1/16	1/4	1/2
190710	QSK-1/8-1/4-U	1/8	1/4	1/2
190711	QSK-1/8-5/16-U	1/8	5/16	9/16
190712	QSK-1/4-1/4-U	1/4	1/4	9/16
190713	QSK-1/4-5/16-U	1/4	5/16	9/16
190714	QSK-1/4-3/8-U	1/4	3/8	11/16
190715	QSK-3/8-5/16-U	3/8	5/16	11/16
190716	QSK-3/8-3/8-U	3/8	3/8	11/16
190717	QSK-3/8-1/2-U	3/8	1/2	7/8
190718	QSK-1/2-1/2-U	1/2	1/2	7/8

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series

Push-in Elbow Fitting, UNF



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153907*	QSML-10-32-UNF-1/8-U	10-32	1/8	5/16
164849*	QSML-10-32-UNF-5/32-U	10-32	5/32	5/16
164848*	QSL-10-32-UNF-3/16-U	10-32	3/16	1/2
164847*	QSL-10-32-UNF-1/4-U	10-32	1/4	1/2

Push-in Elbow Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153908*	QSML-1/16-1/8-U	1/16	1/8	7/16
190721*	QSML-1/16-5/32-U	1/16	5/32	7/16
192811*	QSML-1/16-3/16-U	1/16	3/16	7/16
153909*	QSML-1/8-1/8-U	1/8	1/8	7/16
190723*	QSML-1/4-1/8-U	1/4	1/8	9/16
192812*	QSL-1/16-1/4-U	1/16	1/4	1/2
153639*	QSL-1/8-5/32-U	1/8	5/32	7/16
153641*	QSL-1/8-3/16-U	1/8	3/16	1/2
153643*	QSL-1/8-1/4-U	1/8	1/4	1/2
153646*	QSL-1/8-5/16-U	1/8	5/16	9/16
190722*	QSL-1/8-3/8-U	1/8	3/8	11/16
153640*	QSL-1/4-5/32-U	1/4	5/32	9/16
153642*	QSL-1/4-3/16-U	1/4	3/16	9/16
153644*	QSL-1/4-1/4-U	1/4	1/4	9/16
153647*	QSL-1/4-5/16-U	1/4	5/16	9/16
153649*	QSL-1/4-3/8-U	1/4	3/8	11/16
190724*	QSL-1/4-1/2-U	1/4	1/2	7/8
153645*	QSL-3/8-1/4-U	3/8	1/4	11/16
153648*	QSL-3/8-5/16-U	3/8	5/16	11/16
153650*	QSL-3/8-3/8-U	3/8	3/8	11/16
153652*	QSL-3/8-1/2-U	3/8	1/2	7/8
153651*	QSL-1/2-3/8-U	1/2	3/8	7/8
153653	QSL-1/2-1/2-U	1/2	1/2	7/8
190725*	QSL-1/2-5/8-U	1/2	5/8	1

Push-in Elbow Fitting, UNF, Long



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153910*	QSMLL-10-32-UNF-1/8-U	10-32	1/8	5/16

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series

1

1.1

Push-in Elbow Fitting, NPT, Long



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153911*	QSMML-1/16-1/8-U	1/16	1/8	7/16
153912*	QSMML-1/8-1/8-U	1/8	1/8	7/16
190734*	QSMML-1/4-1/8-U	1/4	1/8	9/16
153668*	QSL-1/8-5/32-U	1/8	5/32	7/16
153669*	QSL-1/8-3/16-U	1/8	3/16	1/2
153671*	QSL-1/8-1/4-U	1/8	1/4	1/2
153674*	QSL-1/8-5/16-U	1/8	5/16	9/16
190735*	QSL-1/4-5/32-U	1/4	5/32	9/16
153670*	QSL-1/4-3/16-U	1/4	3/16	9/16
153672*	QSL-1/4-1/4-U	1/4	1/4	9/16
153675*	QSL-1/4-5/16-U	1/4	5/16	9/16
153677*	QSL-1/4-3/8-U	1/4	3/8	11/16
190736*	QSL-1/4-1/2-U	1/4	1/2	7/8
153673*	QSL-3/8-1/4-U	3/8	1/4	11/16
153676*	QSL-3/8-5/16-U	3/8	5/16	11/16
153678*	QSL-3/8-3/8-U	3/8	3/8	11/16
153680*	QSL-3/8-1/2-U	3/8	1/2	7/8
153679*	QSL-1/2-3/8-U	1/2	3/8	7/8
153681*	QSL-1/2-1/2-U	1/2	1/2	7/8

Push-in Elbow Fitting, NPT, with Female Thread



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190726*	QSLF-1/8-5/32-U	1/8	5/32	9/16
190727*	QSLF-1/8-3/16-U	1/8	3/16	9/16
190728*	QSLF-1/8-1/4-U	1/8	1/4	9/16
190729*	QSLF-1/8-5/16-U	1/8	5/16	9/16
190730*	QSLF-1/4-1/4-U	1/4	1/4	11/16
190731*	QSLF-1/4-5/16-U	1/4	5/16	11/16
164846*	QSLF-1/4-3/8-U	1/4	3/8	3/4
190732*	QSLF-3/8-5/16-U	3/8	5/16	7/8
190733*	QSLF-3/8-3/8-U	3/8	3/8	7/8

Push-in Elbow Fitting, UNF, with Internal Shut-off



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190737	QSMKL-10-32-UNF-1/8-U	10-32	1/8	1
190738	QSMKL-10-32-UNF-5/32-U	10-32	5/32	1
190739	QSMKL-10-32-UNF-3/16-U	10-32	3/16	1/2
190740	QSKL-10-32-UNF-1/4-U	10-32	1/4	1/2

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.


Quick Star Push-in Fittings – Inch Series

Push-in Elbow Fitting, NPT, with Internal Shut-off



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
192813	QSMKL-1/16-1/8-U	1/16	1/8	7/16
192814	QSMKL-1/16-5/32-U	1/16	5/32	7/16
192815	QSMKL-1/16-3/16-U	1/16	3/16	1/2
190741	QSMKL-1/8-5/32-U	1/8	5/32	7/16
190742	QSMKL-1/8-3/16-U	1/8	3/16	1/2
192816	QSKL-1/16-1/4-U	1/16	1/4	1/2
190743	QSKL-1/8-1/4-U	1/8	1/4	1/2
190744	QSKL-1/8-5/16-U	1/8	5/16	9/16
190745	QSKL-1/4-1/4-U	1/4	1/4	9/16
190746	QSKL-1/4-5/16-U	1/4	5/16	9/16
190747	QSKL-1/4-3/8-U	1/4	3/8	11/16
190748	QSKL-3/8-5/16-U	3/8	5/16	11/16
190749	QSKL-3/8-3/8-U	3/8	3/8	11/16
190750	QSKL-3/8-1/2-U	3/8	1/2	7/8
190751	QSKL-1/2-1/2-U	1/2	1/2	7/8

Push-in Elbow Fitting, NPT, with External Hex

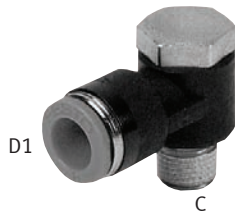

Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153682*	QSLV-1/8-5/32-U	1/8	5/32	9/16
153683*	QSLV-1/8-3/16-U	1/8	3/16	9/16
153685*	QSLV-1/8-1/4-U	1/8	1/4	9/16
153687*	QSLV-1/8-5/16-U	1/8	5/16	9/16
153684*	QSLV-1/4-3/16-U	1/4	3/16	11/16
153686*	QSLV-1/4-1/4-U	1/4	1/4	11/16
153688*	QSLV-1/4-5/16-U	1/4	5/16	11/16
153690*	QSLV-1/4-3/8-U	1/4	3/8	11/16
153689*	QSLV-3/8-5/16-U	3/8	5/16	7/8
153691*	QSLV-3/8-3/8-U	3/8	3/8	7/8
153692*	QSLV-3/8-1/2-U	3/8	1/2	7/8
153693	QSLV-1/2-1/2-U	1/2	1/2	1
190752	QSLV-1/2-5/8-U	1/2	5/8	1

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

1
1.1

Quick Star Push-in Fittings – Inch Series

1

1.1

Push-in Elbow Fitting, NPT, with Internal Hex



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190753*	QSLV-1/8-5/32-I-U	1/8	5/32	5/32
190754*	QSLV-1/8-3/16-I-U	1/8	3/16	3/16
190755*	QSLV-1/8-1/4-I-U	1/8	1/4	3/16
190756*	QSLV-1/8-5/16-I-U	1/8	5/16	5/16
190757*	QSLV-1/4-1/4-I-U	1/4	1/4	5/16
190758*	QSLV-1/4-5/16-I-U	1/4	5/16	5/16
190759*	QSLV-1/4-3/8-I-U	1/4	3/8	5/16
190760*	QSLV-3/8-5/16-I-U	3/8	5/16	5/16
190761*	QSLV-3/8-3/8-I-U	3/8	3/8	5/16
190762*	QSLV-3/8-1/2-I-U	3/8	1/2	1/2
190763*	QSLV-1/2-1/2-I-U	1/2	1/2	1/2
190764*	QSLV-1/2-5/8-I-U	1/2	5/8	9/16

Push-in Double Elbow Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190765	QSLV2-1/8-5/32-U	1/8	5/32	9/16
190766	QSLV2-1/8-3/16-U	1/8	3/16	9/16
190767	QSLV2-1/8-1/4-U	1/8	1/4	9/16
190768	QSLV2-1/8-5/16-U	1/8	5/16	11/16
190769	QSLV2-1/4-1/4-U	1/4	1/4	9/16
190770	QSLV2-1/4-5/16-U	1/4	5/16	11/16
190771	QSLV2-1/4-3/8-U	1/4	3/8	7/8
190772	QSLV2-3/8-5/16-U	3/8	5/16	11/16
190773	QSLV2-3/8-3/8-U	3/8	3/8	7/8
190774	QSLV2-3/8-1/2-U	3/8	1/2	1 1/8
190775	QSLV2-1/2-1/2-U	1/2	1/2	1 1/8
190776	QSLV2-1/2-5/8-U	1/2	5/8	1 1/8

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
 Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series

Push-in Triple Elbow Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190777	QSLV3-1/8-5/32-U	1/8	5/32	9/16
190778	QSLV3-1/8-3/16-U	1/8	3/16	9/16
190779	QSLV3-1/8-1/4-U	1/8	1/4	9/16
190780	QSLV3-1/8-5/16-U	1/8	5/16	11/16
190781	QSLV3-1/4-1/4-U	1/4	1/4	9/16
190782	QSLV3-1/4-5/16-U	1/4	5/16	11/16
190783	QSLV3-1/4-3/8-U	1/4	3/8	7/8
190784	QSLV3-3/8-5/16-U	3/8	5/16	11/16
190785	QSLV3-3/8-3/8-U	3/8	3/8	7/8
190786	QSLV3-3/8-1/2-U	3/8	1/2	1 1/8
190787	QSLV3-1/2-1/2-U	1/2	1/2	1 1/8
190788	QSLV3-1/2-5/8-U	1/2	5/8	1 1/8

Push-in Y Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190838*	QSMY-1/8-1/8-U	1/8	1/8	7/16
190839*	QSMY-1/4-1/8-U	1/4	1/8	9/16
153735*	QSY-1/8-5/32-U	1/8	5/32	7/16
153737*	QSY-1/8-3/16-U	1/8	3/16	1/2
153739*	QSY-1/8-1/4-U	1/8	1/4	1/2
153742*	QSY-1/8-5/16-U	1/8	5/16	9/16
153736*	QSY-1/4-5/32-U	1/4	5/32	9/16
153738*	QSY-1/4-3/16-U	1/4	3/16	9/16
153740*	QSY-1/4-1/4-U	1/4	1/4	9/16
153743*	QSY-1/4-5/16-U	1/4	5/16	9/16
153745*	QSY-1/4-3/8-U	1/4	3/8	11/16
153741*	QSY-3/8-1/4-U	3/8	1/4	11/16
153744*	QSY-3/8-5/16-U	3/8	5/16	11/16
153746*	QSY-3/8-3/8-U	3/8	3/8	11/16
153748*	QSY-3/8-1/2-U	3/8	1/2	7/8
153747*	QSY-1/2-3/8-U	1/2	3/8	7/8
153749	QSY-1/2-1/2-U	1/2	1/2	7/8

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
 Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

1
1.1

Quick Star Push-in Fittings – Inch Series

1
1.1

Push-in Elbow Y Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153779	QSYL-1/8-5/32-U	1/8	5/32	7/16
153781	QSYL-1/8-3/16-U	1/8	3/16	1/2
153783	QSYL-1/8-1/4-U	1/8	1/4	1/2
153786	QSYL-1/8-5/16-U	1/8	5/16	9/16
153780	QSYL-1/4-5/32-U	1/4	5/32	9/16
153782	QSYL-1/4-3/16-U	1/4	3/16	9/16
153784	QSYL-1/4-1/4-U	1/4	1/4	9/16
153787	QSYL-1/4-5/16-U	1/4	5/16	9/16
153789	QSYL-1/4-3/8-U	1/4	3/8	11/16
153785	QSYL-3/8-1/4-U	3/8	1/4	11/16
153788	QSYL-3/8-5/16-U	3/8	5/16	11/16
153790	QSYL-3/8-3/8-U	3/8	3/8	11/16
153792	QSYL-3/8-1/2-U	3/8	1/2	7/8
153791	QSYL-1/2-3/8-U	1/2	3/8	7/8
153793	QSYL-1/2-1/2-U	1/2	1/2	7/8

Push-in Elbow Y Fitting, NPT, with External Hex



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153794	QSYLV-1/8-3/16-U	1/8	3/16	9/16
153795	QSYLV-1/8-1/4-U	1/8	1/4	9/16
153796	QSYLV-1/4-5/16-U	1/4	5/16	11/16
153797	QSYLV-3/8-3/8-U	3/8	3/8	7/8
153798	QSYLV-1/2-1/2-U	1/2	1/2	1

Push-in Elbow Y Fitting, NPT, with Male and Female Thread



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190834*	QSYTF-1/8-1/4-U	1/8	1/4	9/16
190835*	QSYTF-1/4-5/16-U	1/4	5/16	11/16
190836*	QSYTF-3/8-3/8-U	3/8	3/8	7/8
190837*	QSYTF-1/2-1/2-U	1/2	1/2	1

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series

Push-in Double Y Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153810	QSQ-1/8-5/32-U	1/8	5/32	7/16
153812	QSQ-1/8-3/16-U	1/8	3/16	1/2
153813	QSQ-1/8-1/4-U	1/8	1/4	1/2
153811	QSQ-1/4-5/32-U	1/4	5/32	9/16

Push-in Elbow Double Y Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190789	QSLV4-1/8-5/32-U	1/8	5/32	9/16
190790	QSLV4-1/8-3/16-U	1/8	3/16	9/16
190791	QSLV4-1/8-1/4-U	1/8	1/4	9/16
190792	QSLV4-1/8-5/16-U	1/8	5/16	11/16
190793	QSLV4-1/4-1/4-U	1/4	1/4	9/16
190794	QSLV4-1/4-5/16-U	1/4	5/16	11/16
190795	QSLV4-1/4-3/8-U	1/4	3/8	7/8
190796	QSLV4-3/8-5/16-U	3/8	5/16	11/16
190797	QSLV4-3/8-3/8-U	3/8	3/8	1 1/8
190798	QSLV4-3/8-1/2-U	3/8	1/2	1 1/8
190799	QSLV4-1/2-1/2-U	1/2	1/2	1 1/8
190800	QSLV4-1/2-5/8-U	1/2	5/8	1 1/8

Push-in Elbow Triple Y Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190801	QSLV6-1/8-5/32-U	1/8	5/32	9/16
190802	QSLV6-1/8-3/16-U	1/8	3/16	9/16
190803	QSLV6-1/8-1/4-U	1/8	1/4	9/16
190804	QSLV6-1/8-5/16-U	1/8	5/16	11/16
190805	QSLV6-1/4-1/4-U	1/4	1/4	9/16
190806	QSLV6-1/4-5/16-U	1/4	5/16	11/16
190807	QSLV6-1/4-3/8-U	1/4	3/8	7/8
190808	QSLV6-3/8-5/16-U	3/8	5/16	11/16
190809	QSLV6-3/8-3/8-U	3/8	3/8	7/8
190810	QSLV6-3/8-1/2-U	3/8	1/2	1 1/8
190811	QSLV6-1/2-1/2-U	1/2	1/2	1 1/8
190812	QSLV6-1/2-5/8-U	1/2	5/8	1 1/8

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.



Quick Star Push-in Fittings – Inch Series

1

1.1

Push-in T Fitting, UNF



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153914*	QSMT-10-32-UNF-1/8-U	10-32	1/8	5/16
190813*	QSMT-10-32-UNF-5/32-U	10-32	5/32	5/16
190815*	QST-10-32-UNF-3/16-U	10-32	3/16	1/2
190816*	QST-10-32-UNF-1/4-U	10-32	1/4	1/2

Push-in T Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153915*	QSMT-1/16-1/8-U	1/16	1/8	7/16
190814*	QSMT-1/16-5/32-U	1/16	5/32	7/16
153916*	QSMT-1/8-1/8-U	1/8	1/8	7/16
190817*	QSMT-1/4-1/8-U	1/4	1/8	9/16
153694*	QST-1/8-5/32-U	1/8	5/32	7/16
153696*	QST-1/8-3/16-U	1/8	3/16	1/2
153698*	QST-1/8-1/4-U	1/8	1/4	1/2
153701*	QST-1/8-5/16-U	1/8	5/16	9/16
153695*	QST-1/4-5/32-U	1/4	5/32	9/16
153697*	QST-1/4-3/16-U	1/4	3/16	9/16
153699*	QST-1/4-1/4-U	1/4	1/4	9/16
153702*	QST-1/4-5/16-U	1/4	5/16	9/16
153704*	QST-1/4-3/8-U	1/4	3/8	11/16
153700*	QST-3/8-1/4-U	3/8	1/4	11/16
153703*	QST-3/8-5/16-U	3/8	5/16	11/16
153705*	QST-3/8-3/8-U	3/8	3/8	11/16
153707*	QST-3/8-1/2-U	3/8	1/2	7/8
153706*	QST-1/2-3/8-U	1/2	3/8	7/8
153708	QST-1/2-1/2-U	1/2	1/2	7/8

Push-in Branch T Fitting, UNF



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153917*	QSMTL-10-32-UNF-1/8-U	10-32	1/8	5/16
190818*	QSMTL-10-32-UNF-5/32-U	10-32	5/32	5/16
190820*	QSTL-10-32-UNF-3/16-U	10-32	3/16	1/2
190821*	QSTL-10-32-UNF-1/4-U	10-32	1/4	1/2

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
 Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series

Push-in Branch T Fitting, NPT



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
153918*	QSMTL-1/16-1/8-U	1/16	1/8	7/16
190819*	QSMTL-1/16-5/32-U	1/16	5/32	7/16
153919*	QSMTL-1/8-1/8-U	1/8	1/8	7/16
190822*	QSMTL-1/4-1/8-U	1/4	1/8	9/16
153709*	QSTL-1/8-5/32-U	1/8	5/32	7/16
153711*	QSTL-1/8-3/16-U	1/8	3/16	1/2
153713*	QSTL-1/8-1/4-U	1/8	1/4	1/2
153716*	QSTL-1/8-5/16-U	1/8	5/16	9/16
153710*	QSTL-1/4-5/32-U	1/4	5/32	9/16
153712*	QSTL-1/4-3/16-U	1/4	3/16	9/16
153714*	QSTL-1/4-1/4-U	1/4	1/4	9/16
153717*	QSTL-1/4-5/16-U	1/4	5/16	9/16
153719*	QSTL-1/4-3/8-U	1/4	3/8	11/16
153715	QSTL-3/8-1/4-U	3/8	1/4	11/16
153718	QSTL-3/8-5/16-U	3/8	5/16	11/16
153720*	QSTL-3/8-3/8-U	3/8	3/8	11/16
153722	QSTL-3/8-1/2-U	3/8	1/2	7/8
153721	QSTL-1/2-3/8-U	1/2	3/8	7/8
153723	QSTL-1/2-1/2-U	1/2	1/2	7/8

Push-in T Fitting, NPT, with Male and Female Thread



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190823*	QSTF-1/8-5/32-U	1/8	5/32	9/16
190824*	QSTF-1/8-3/16-U	1/8	3/16	9/16
190825*	QSTF-1/8-1/4-U	1/8	1/4	9/16
190826*	QSTF-1/8-5/16-U	1/8	5/16	9/16
190827*	QSTF-1/4-1/4-U	1/4	1/4	11/16
190828*	QSTF-1/4-5/16-U	1/4	5/16	11/16
190829*	QSTF-1/4-3/8-U	1/4	3/8	11/16
190830*	QSTF-3/8-5/16-U	3/8	5/16	7/8
190831*	QSTF-3/8-3/8-U	3/8	1/8	7/8
190832*	QSTF-3/8-1/2-U	3/8	1/2	7/8
190833*	QSTF-1/2-1/2-U	3/8	1/2	1

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series

1

1.1

Push-in Triple Branch Reducing T Fitting, NPT



Ordering Data					
Part No.	Type	Thread C	For Tubing O.D.		Wrench Size
			D1	D2	
			[inch]	[inch]	[inch]
153799	QST3-1/8-3/16-5/32-U	1/8	3/16	5/32	1/2
153800	QST3-1/4-5/16-5/32-U	1/4	5/16	5/32	9/16
153801	QST3-1/4-5/16-3/16-U	1/4	5/16	3/16	9/16
153802	QST3-1/4-5/16-1/4-U	1/4	5/16	1/4	9/16
153803	QST3-3/8-3/8-5/16-U	3/8	3/8	5/16	11/16

Push-in Bulkhead Fitting, with Female NPT Thread



Ordering Data					
Part No.	Type	Thread C1	Thread C2	For Tubing O.D.	Wrench Size
		[NPT]	[UNF]	D1	
				[inch]	[inch]
153767*	QSSF-1/8-5/32-U	1/8	1/2-20	5/32	9/16
153768*	QSSF-1/8-3/16-U	1/8	9/16-18	3/16	11/16
153770*	QSSF-1/8-1/4-U	1/8	9/16-18	1/4	11/16
153772*	QSSF-1/8-5/16-U	1/8	5/8-18	5/16	3/4
190719*	QSSF-1/8-3/8-U	1/8	7/8-14	3/8	1
190720*	QSSF-1/4-5/32-U	1/4	1/2-20	5/32	11/16
153769*	QSSF-1/4-3/16-U	1/4	9/16-18	3/16	11/16
153771*	QSSF-1/4-1/4-U	1/4	9/16-18	1/4	11/16
153773*	QSSF-1/4-5/16-U	1/4	5/8-18	5/16	3/4
153775*	QSSF-1/4-3/8-U	1/4	7/8-14	3/8	1
153774*	QSSF-3/8-5/16-U	3/8	5/8-18	5/16	3/4
153776*	QSSF-3/8-3/8-U	3/8	7/8-14	3/8	1
153777*	QSSF-3/8-1/2-U	3/8	7/8-14	1/2	1
153778*	QSSF-1/2-1/2-U	1/2	7/8-14	1/3	1

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

Quick Star Push-in Fittings – Inch Series – QS Rotary

Push-in Straight Fitting, NPT with Ball Bearing



Ordering Data					
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Max. RPM	Wrench Size [inch]
153951	QSR-1/8-5/32-U	1/8	5/32	500	1/2
153952	QSR-1/8-3/16-U	1/8	3/16	500	9/16
153954	QSR-1/8-1/4-U	1/8	1/4	500	9/16
153956	QSR-1/8-5/16-U	1/8	5/16	400	11/16
153953	QSR-1/4-3/16-U	1/4	3/16	500	9/16
153955	QSR-1/4-1/4-U	1/4	1/4	500	11/16
153957	QSR-1/4-5/16-U	1/4	5/16	400	11/16
153958	QSR-3/8-5/16-U	3/8	5/16	400	11/16
153959	QSR-3/8-3/8-U	3/8	3/8	300	7/8
153961	QSR-3/8-1/2-U	3/8	1/2	250	1
153960	QSR-1/2-3/8-U	1/2	3/8	300	7/8
153962	QSR-1/2-1/2-U	1/2	1/2	250	1

Push-in Elbow Fitting, NPT with Ball Bearing



Ordering Data					
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Max. RPM	Wrench Size [inch]
153963	QSL-1/8-5/32-U	1/8	5/32	500	1/2
153964	QSL-1/8-3/16-U	1/8	3/16	500	9/16
153966	QSL-1/8-1/4-U	1/8	1/4	500	9/16
153968	QSL-1/8-5/16-U	1/8	5/16	400	11/16
153965	QSL-1/4-3/16-U	1/4	3/16	500	9/16
153967	QSL-1/4-1/4-U	1/4	1/4	500	9/16
153969	QSL-1/4-5/16-U	1/4	5/16	400	11/16
153970	QSL-3/8-5/16-U	3/8	5/16	400	11/16
153971	QSL-3/8-3/8-U	3/8	3/8	300	7/8
153973	QSL-3/8-1/2-U	3/8	1/2	250	1
153972	QSL-1/2-3/8-U	1/2	3/8	300	7/8
153974	QSL-1/2-1/2-U	1/2	1/2	250	1

* Packaged in quantities of 10. (No asterisk = items sold by the unit.)
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

1
1.1

Product Range and Company Overview

A Complete Suite of Automation Services

Our experienced engineers provide complete support at every stage of your development process, including: conceptualization, analysis, engineering, design, assembly, documentation, validation, and production.



Custom Automation Components
Complete custom engineered solutions



Custom Control Cabinets
Comprehensive engineering support and on-site services



Complete Systems
Shipment, stocking and storage services

The Broadest Range of Automation Components

With a comprehensive line of more than 30,000 automation components, Festo is capable of solving the most complex automation requirements.



Electromechanical
Electromechanical actuators, motors, controllers & drives



Pneumatics
Pneumatic linear and rotary actuators, valves, and air supply



PLCs and I/O Devices
PLC's, operator interfaces, sensors and I/O devices

Supporting Advanced Automation... As No One Else Can!

Festo is a leading global manufacturer of pneumatic and electromechanical systems, components and controls for industrial automation, with more than 12,000 employees in 56 national headquarters serving more than 180 countries. For more than 80 years, Festo has continuously elevated the state of manufacturing with innovations and optimized motion control solutions that deliver higher performing, more profitable automated manufacturing and processing equipment. Our dedication to the advancement of automation extends beyond technology to the education and development of current and future automation and robotics designers with simulation tools, teaching programs, and on-site services.

Quality Assurance, ISO 9001 and ISO 14001 Certifications

Festo Corporation is committed to supply all Festo products and services that will meet or exceed our customers' requirements in product quality, delivery, customer service and satisfaction.

To meet this commitment, we strive to ensure a consistent, integrated, and systematic approach to management that will meet or exceed the requirements of the ISO 9001 standard for Quality Management and the ISO 14001 standard for Environmental Management.



© Copyright 2008, Festo Corporation. While every effort is made to ensure that all dimensions and specifications are correct, Festo cannot guarantee that publications are completely free of any error, in particular typing or printing errors. Accordingly, Festo cannot be held responsible for the same. For Liability and Warranty conditions, refer to our "Terms and Conditions of Sale", available from your local Festo office. All rights reserved. No part of this publication may be reproduced, distributed, or transmitted in any form or by any means, electronic, mechanical, photocopying or otherwise, without the prior written permission of Festo. All technical data subject to change according to technical update.



Printed on recycled paper at New Horizon Graphic, Inc., FSC certified as an environmentally friendly printing plant.

Festo North America

United States

Customer Resource Center
502 Earth City Expy., Suite 125
Earth City, MO 63045

For ordering assistance, or to find
your nearest Festo Distributor,

Call: 1.800.99.FESTO

Fax: 1.800.96.FESTO

Email: customer.service@us.festo.com

For technical support,

Call: 1.866.GO.FESTO

Fax: 1.800.96.FESTO

Email: product.support@us.festo.com

Headquarters

Festo Corporation
395 Moreland Road
P.O. Box 18023
Hauppauge, NY 11788
www.festo.com/us

Sales Offices

Appleton

N. 922 Tower View Drive, Suite N
Greenville, WI 54942

Boston

120 Presidential Way, Suite 330
Woburn, MA 01801

Chicago

1441 East Business Center Drive
Mt. Prospect, IL 60056

Dallas

1825 Lakeway Drive, Suite 600
Lewisville, TX 75057

Detroit - Automotive Engineering Center

2601 Cambridge Court, Suite 320
Auburn Hills, MI 48326

New York

395 Moreland Road
Hauppauge, NY 11788

Silicon Valley

4935 Southfront Road, Suite F
Livermore, CA 94550

Design and Manufacturing Operations



East: 395 Moreland Road, Hauppauge, NY 11788



Central: 1441 East Business Center Drive, Mt. Prospect, IL 60056



West: 4935 Southfront Road, Suite F, Livermore, CA 94550

Mexico

Headquarters

Festo Pneumatic, S.A.
Av. Ceylán 3, Col. Tequesquahuac
54020 Tlalnepantla, Edo. de México
Call: 011 52 [55] 53 21 66 00
Fax: 011 52 [55] 53 21 66 65
Email: festo.mexico@mx.festo.com
www.festo.com/mx



Canada

Headquarters

Festo Inc.
5300 Explorer Drive
Mississauga, Ontario L4W 5G4
Call: 1.905.624.9000
Fax: 1.905.624.9001
Email: info.ca@ca.festo.com
www.festo.com/ca



Festo Worldwide

Argentina Australia Austria Belarus Belgium Brazil Bulgaria Canada Chile China Colombia Croatia Czech Republic Denmark
Estonia Finland France Germany Great Britain Greece Hong Kong Hungary India Indonesia Iran Ireland Israel Italy Japan
Latvia Lithuania Malaysia Mexico Netherlands New Zealand Norway Peru Philippines Poland Romania Russia Serbia Singapore
Slovakia Slovenia South Africa South Korea Spain Sweden Switzerland Taiwan Thailand Turkey Ukraine United States Venezuela

www.festo.com