

Plugs, Sub-D, 9-pin

Technical data

Plug
FBS-SUB-9

- Fieldbus plug with 9-pin Sub-D connection
- Variants for different fieldbus systems
- Position of DIL switches can be read externally
- Easy assembly



General technical data				
Type	FBS-SUB-9-GS-DP-B	FBS-SUB-9-GS-IB-B	FBS-SUB-9-GS-2X4POL-B	FBS-SUB-9-GS-1X9POL-B
Electrical connection	Plug, 9-pin, Sub-D			
Control elements	DIL switches	-	-	-
Note for fieldbus interface	-	-	BUS In - BUS Out looped through	-
Additional functions	Switching off of outgoing fieldbus segment	Integrated RBST bridge	-	-
Permissible cable diameter [mm]	5 ... 10			
Degree of protection to EN 60529	IP65, IP67 (assembled)			
Height/length/width [mm]	62/61/20			

General technical data	
Type	FBS-SUB-9-WS-...
Electrical connection	Plug, 9-pin, Sub-D
Permissible cable diameter [mm]	4.5 ... 8
Degree of protection to EN 60529	IP40

Materials			
Type	FBS-SUB-9-GS-...	FBS-SUB-9-GS-1X9POL-B	FBS-SUB-9-WS-...
Housing	PA reinforced	PA reinforced	Thermoplastic
Seals	NBR	NBR	-
Screws	Steel	Steel	-
Union nut	Brass	Brass	-
Note on materials	RoHS-compliant	-	-

Operating and environmental conditions			
Type	FBS-SUB-9-GS-...	FBS-SUB-9-GS-1X9POL-B	FBS-SUB-9-WS-...
Ambient temperature [°C]	0 ... +50	0 ... +50	-20 ... +70
Storage temperature [°C]	-20 ... +70	-20 ... +70	-
Relative air humidity [%]	95, non-condensing	95, non-condensing	-
CE marking (see declaration of conformity)	-	To EU EMC Directive ¹⁾	-
	-	To EU Low Voltage Directive	-

1) For information about the applicability of the component see the manufacturer's EC declaration of conformity at: www.festo.com/sp → User documentation.
If the component is subject to restrictions on usage in residential, office or commercial environments or small businesses, further measures to reduce the emitted interference may be necessary.

Plugs, Sub-D, 9-pin


Technical data

FESTO

Dimensions


Download CAD data → www.festo.com

FBS-SUB-9-GS-...

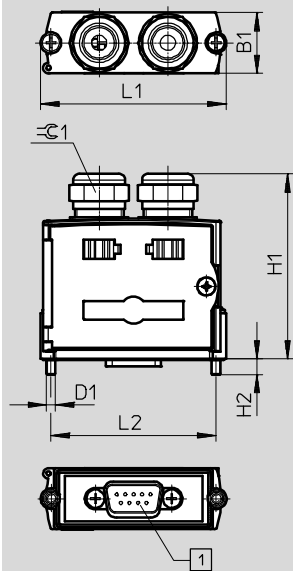

1 Sub-D plug, 9-pin


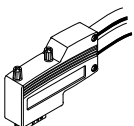
FBS-SUB-9-WS-...

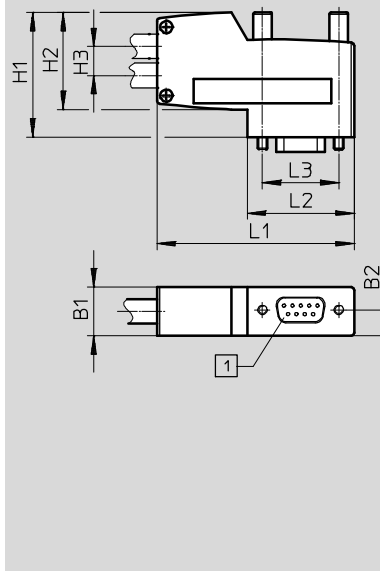

1 Sub-D plug, 9-pin

Type	B1	B2	D1	H1	H2	H3	L1	L2	L3	⌀C1
FBS-SUB-9-GS-...	20	–	M3x20	60.5	5	–	60.9	54.1	–	17
FBS-SUB-9-WS-...	16	8.5	–	40.8	31.8	9.5	64.6	35	25	–

Ordering data

	Electrical connection	Protocol	Fieldbus interface	Product weight [g]	Part No.	Type
	Straight plug	PROFIBUS	2x 2 spring-loaded terminals	60	532216	FBS-SUB-9-GS-DP-B
		INTERBUS	1x 5 spring-loaded terminals	60	532217	FBS-SUB-9-GS-IB-B
		CC-Link	2x 4 spring-loaded terminals	60	532220	FBS-SUB-9-GS-2x4POL-B
		RS232	1x 9 spring-loaded terminals	60	534497	FBS-SUB-9-GS-1x9POL-B
	Angled plug	PROFIBUS	–	43	533780	FBS-SUB-9-WS-PB-K
		CANopen	–	45.9	533783	FBS-SUB-9-WS-CO-K

Festo - Your Partner in Automation



1 Festo Inc.
5300 Explorer Drive
Mississauga, ON L4W 5G4
Canada

Festo Customer Interaction Center
Tel: 1 877 463 3786
Fax: 1 877 393 3786
Email: customer.service.ca@festo.com



2 Festo Pneumatic
Av. Ceylán 3,
Col. Tequesquináhuac
54020 Tlalnepantla,
Estado de México

Multinational Contact Center
01 800 337 8669
ventas.mexico@festo.com



3 Festo Corporation
1377 Motor Parkway
Suite 310
Islandia, NY 11749

Festo Customer Interaction Center
1 800 993 3786
1 800 963 3786
customer.service.us@festo.com



4 Regional Service Center
7777 Columbia Road
Mason, OH 45040

Connect with us



www.festo.com/socialmedia



www.festo.com

Subject to change