


Plug connectors for self-assembly, Sub-D socket

FESTO

Technical data

Plug connector SD-SUB-...-BU

- Socket for multi-pin plug connection
- Can be assembled with any cable lengths
- 9-pin, 15-pin or 25-pin
- Sub-D

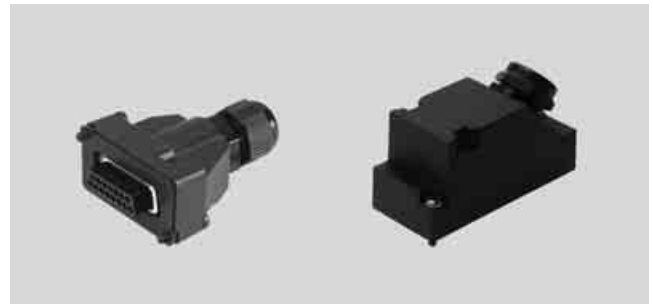


General technical data	
Type of mounting	Two M3x16 screws
Mounting position	Any
Nominal operating voltage [V DC]	24
Acceptable current load [A]	5
Protection class to EN 60529	IP65 (assembled)

Materials			
Type	SD-SUB-D-BU9	SD-SUB-D-BU25	SD-SUB-D-BU15
Housing	PA		
Pin contact	Nickel-plated and gold-plated copper base alloy		
Seals	NBR	NBR	CR

Dimensions Download CAD data → www.festo.com

SD-SUB-D-BU-...

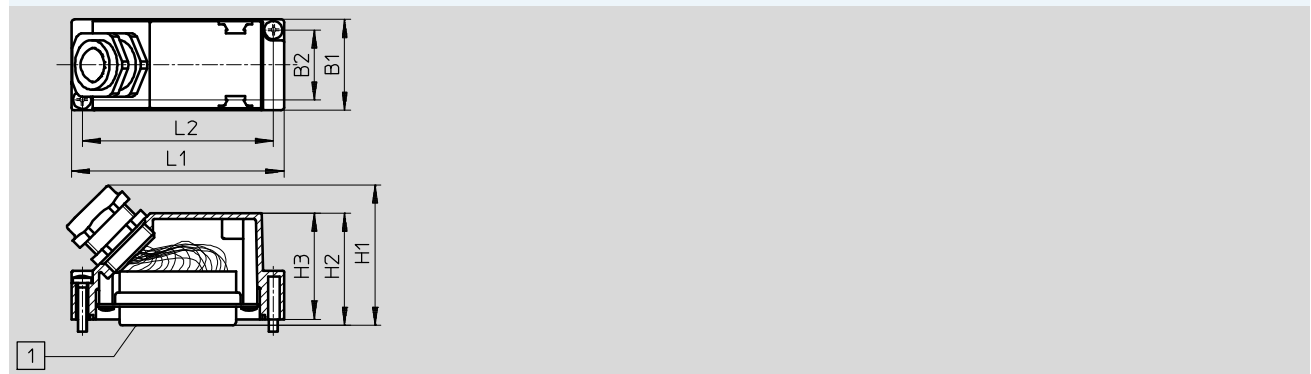

Type	1	B1	B2	H1	H2	H3	L1	L2
SD-SUB-D-BU9	Sub-D socket, 9-pin	30	23	43	37	35	50	43
SD-SUB-D-BU25	Sub-D socket, 25-pin	30	23	47	37	35	70	63

Plug connectors for self-assembly, Sub-D socket


Technical data

FESTO

Dimensions

SD-SUB-D-BU15

Download CAD data → www.festo.com

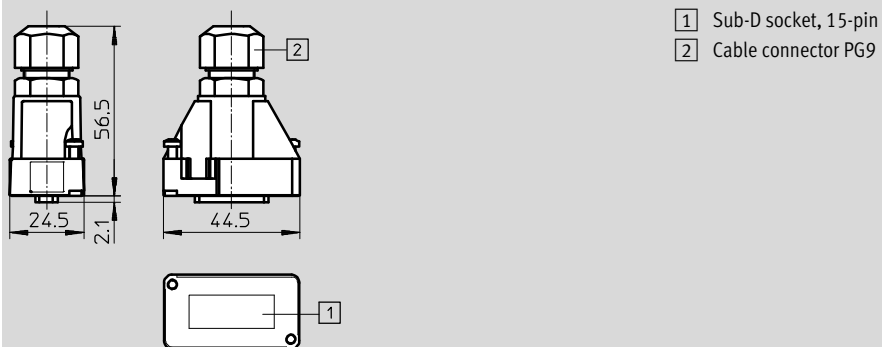

Ordering data

	Electrical connection	Cable connector	Perm. cable Ø [mm]	Product weight [g]	Part No.	Type
	Socket, 9-pin, Sub-D	Pg9	6 ... 9	38	18708	SD-SUB-D-BU9
	Socket, 25-pin, Sub-D	Pg11	7 ... 12	53	18709	SD-SUB-D-BU25
	Socket, 15-pin, Sub-D	Pg9	3 ... 8	33	177675	SD-SUB-D-BU15

Festo - Your Partner in Automation



1 Festo Inc.
5300 Explorer Drive
Mississauga, ON L4W 5G4
Canada

Festo Customer Interaction Center
Tel: 1 877 463 3786
Fax: 1 877 393 3786
Email: customer.service.ca@festo.com



2 Festo Pneumatic
Av. Ceylán 3,
Col. Tequesquináhuac
54020 Tlalnepantla,
Estado de México

Multinational Contact Center
01 800 337 8669
ventas.mexico@festo.com



3 Festo Corporation
1377 Motor Parkway
Suite 310
Islandia, NY 11749

Festo Customer Interaction Center
1 800 993 3786
1 800 963 3786
customer.service.us@festo.com



4 Regional Service Center
7777 Columbia Road
Mason, OH 45040

Connect with us

www.festo.com/socialmedia



www.festo.com

Subject to change