

# Midi-Pneumatic Sub-bases/Manifolds



Single Sub-bases, INCH and Metric Series

## Sub-base

For solenoid valves with 0.16 in / 4 mm orifice or 0.20 in / 5 mm orifice

Side connections

Type AS-ME-1/8  
AS-ME-1/8-NPT

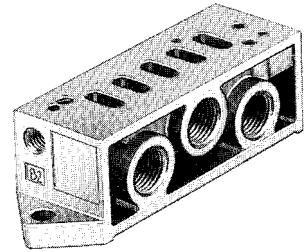
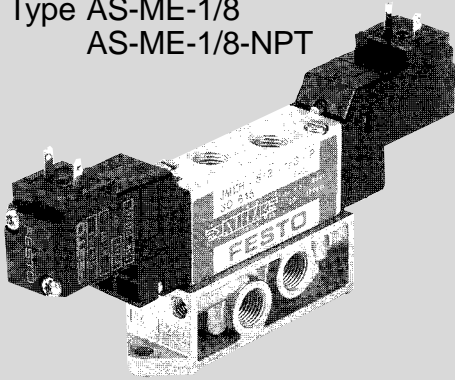


## Sub-base

For valves Type ...-1/8-P

Bottom connections

Type AU-ME-1/8

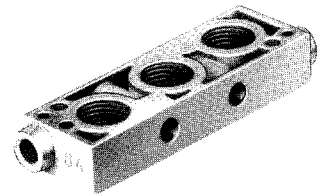
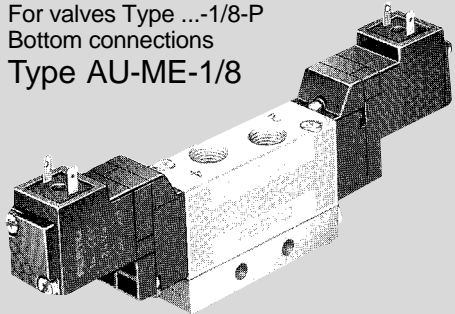


## Sub-base

For pneumatically-actuated valves with 0.16 in / 4 mm orifice or 0.20 in / 5 mm orifice.

Side connections

Type AS-VL-1/8\*  
AS-VL-1/8-NPT\*

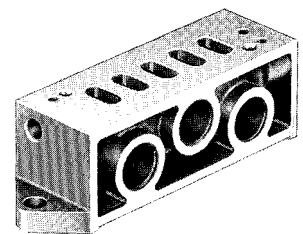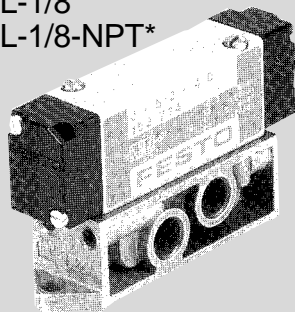

Order Number		33405 AS-ME-1/8	151659 AS-ME-1/8-NPT	32797 AU-ME-1/8
		152803 AS-VL-1/8	152804 AS-VL-1/8-NPT	
Mounting		Through-holes		
Connection	Working Port	G 1/8 ISO	1/8 NPT	G 1/8 ISO
	Pilot Port	M5	10-32 UNF	M5
Material		Diecast aluminum		
Weight		0.110 lb / 0.050 kg		0.033 lb / 0.015 kg


\*For use with Midi-Pneumatic valves, Type VL-/J-...-5.0

# Midi-Pneumatic Sub-bases/Manifolds

## Single Sub-bases, Dimensions

**FESTO**

Type AS-ME-...

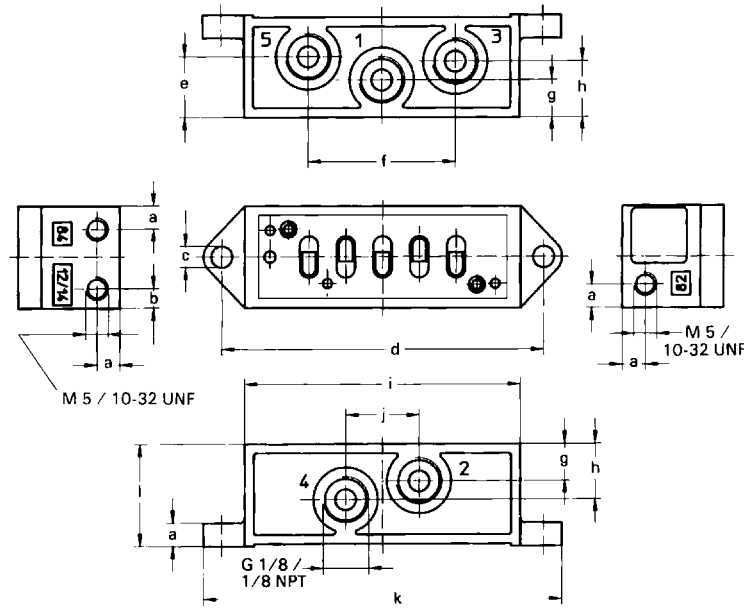


- 1 (P) = Supply port
- 4, 2 (A, B) = Working or outlet port
- 5, 3 (R, S) = Exhaust port
- 12, 14 = External pilot
- 82, 84 = Pilot exhaust


### Dimensions

- a 0.20 in / 5 mm
- b 0.17 in / 4.2 mm
- c 0.18 in / 4.6 mm
- d 2.76 in / 70 mm
- e 0.51 in / 13 mm
- f 1.26 in / 32 mm
- g 0.31 in / 8 mm
- h 0.47 in / 12 mm
- i 2.36 in / 60 mm
- j 0.63 in / 16 mm
- k 3.07 in / 78 mm
- l 0.87 in / 22 mm
- m 0.18 in / 4.5 mm
- n 0.71 in / 18 mm
- o 0.67 in / 17 mm
- p 1.34 in / 34 mm
- q 0.12 in / 3 mm
- r 0.39 in / 10 mm

Type AU-ME-1/8

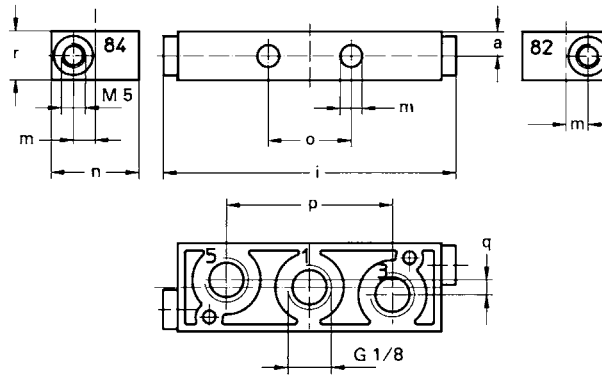

Type AS-VL-...

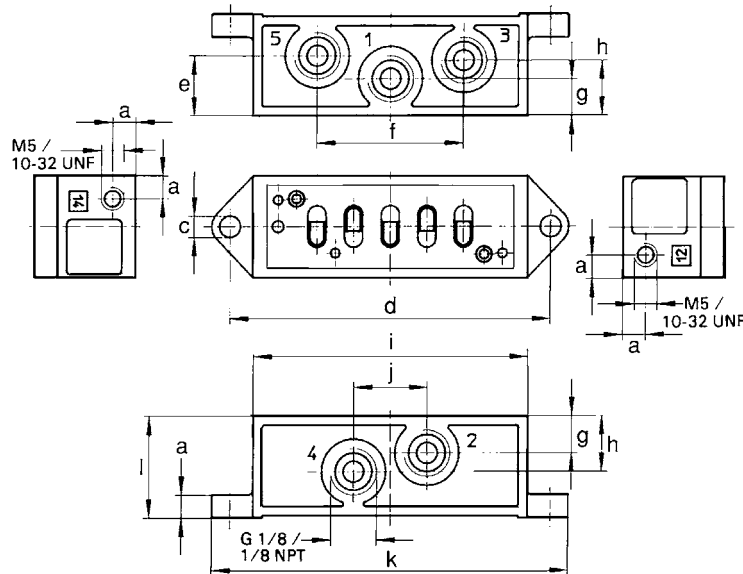

# Festo - Your Partner in Automation



**1 Festo Inc.**  
5300 Explorer Drive  
Mississauga, ON L4W 5G4  
Canada

**Festo Customer Interaction Center**  
Tel: 1 877 463 3786  
Fax: 1 877 393 3786  
Email: [customer.service.ca@festo.com](mailto:customer.service.ca@festo.com)



**2 Festo Pneumatic**  
Av. Ceylán 3,  
Col. Tequesquináhuac  
54020 Tlalnepantla,  
Estado de México

**Multinational Contact Center**  
01 800 337 8669  
[ventas.mexico@festo.com](mailto:ventas.mexico@festo.com)



**3 Festo Corporation**  
1377 Motor Parkway  
Suite 310  
Islandia, NY 11749

**Festo Customer Interaction Center**  
1 800 993 3786  
1 800 963 3786  
[customer.service.us@festo.com](mailto:customer.service.us@festo.com)



**4 Regional Service Center**  
7777 Columbia Road  
Mason, OH 45040

Connect with us



[www.festo.com/socialmedia](http://www.festo.com/socialmedia)



[www.festo.com](http://www.festo.com)

Subject to change