

Electrical adapters NEFV, for valves

Technical data

FESTO

Plug socket MSSD-EB



- Plug socket for connecting individual valves
- M12 plug connector for pre-assembled cable
- Socket, 2-pin
- With LED



General technical data		
Electrical connection	1	Socket, to EN 175301-803 type C
	2	Straight plug, M12, 2-pin, A-coded
Based on standard	EN 61984, EN 175301-803, EN 61076-2-101	
Type of mounting	M2.5 central screw	
Operating voltage range	[V DC]	12 ... 24
	[V AC]	12 ... 24
Surge strength	[kV]	2.5
Acceptable current load	[A]	0.12
Signal status display	LED	
Max. tightening torque	[Nm]	0.4
Protection class to EN 60529	IP65 (assembled)	

Materials	
Housing	PA
Contacts	Brass
Seal	Nitrile rubber

Operating and environmental conditions		
Ambient temperature	[°C]	-10 ... +50
Degree of contamination		3

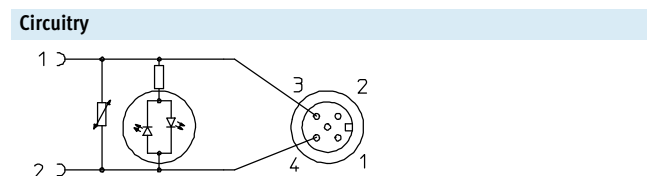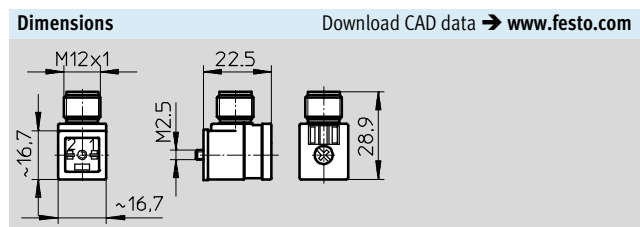

Ordering data		
Electrical connection	Part No.	Type
Angled socket, 2-pin; straight plug, 2-pin, M12	188024	MSSD-EB-M12-MONO

Ordering data – Accessories			
	Description	Part No.	Type
	Inscription labels 6x10 mm, 64 pieces, in frames	18576	IBS-6x10

Festo - Your Partner in Automation



1 Festo Inc.
5300 Explorer Drive
Mississauga, ON L4W 5G4
Canada

Festo Customer Interaction Center
Tel: 1 877 463 3786
Fax: 1 877 393 3786
Email: customer.service.ca@festo.com



2 Festo Pneumatic
Av. Ceylán 3,
Col. Tequesquináhuac
54020 Tlalnepantla,
Estado de México

Multinational Contact Center
01 800 337 8669
ventas.mexico@festo.com



3 Festo Corporation
1377 Motor Parkway
Suite 310
Islandia, NY 11749

Festo Customer Interaction Center
1 800 993 3786
1 800 963 3786
customer.service.us@festo.com



4 Regional Service Center
7777 Columbia Road
Mason, OH 45040

Connect with us

www.festo.com/socialmedia



www.festo.com

Subject to change