


# Pressure Regulators

Quick Star Flow/Pressure Controls

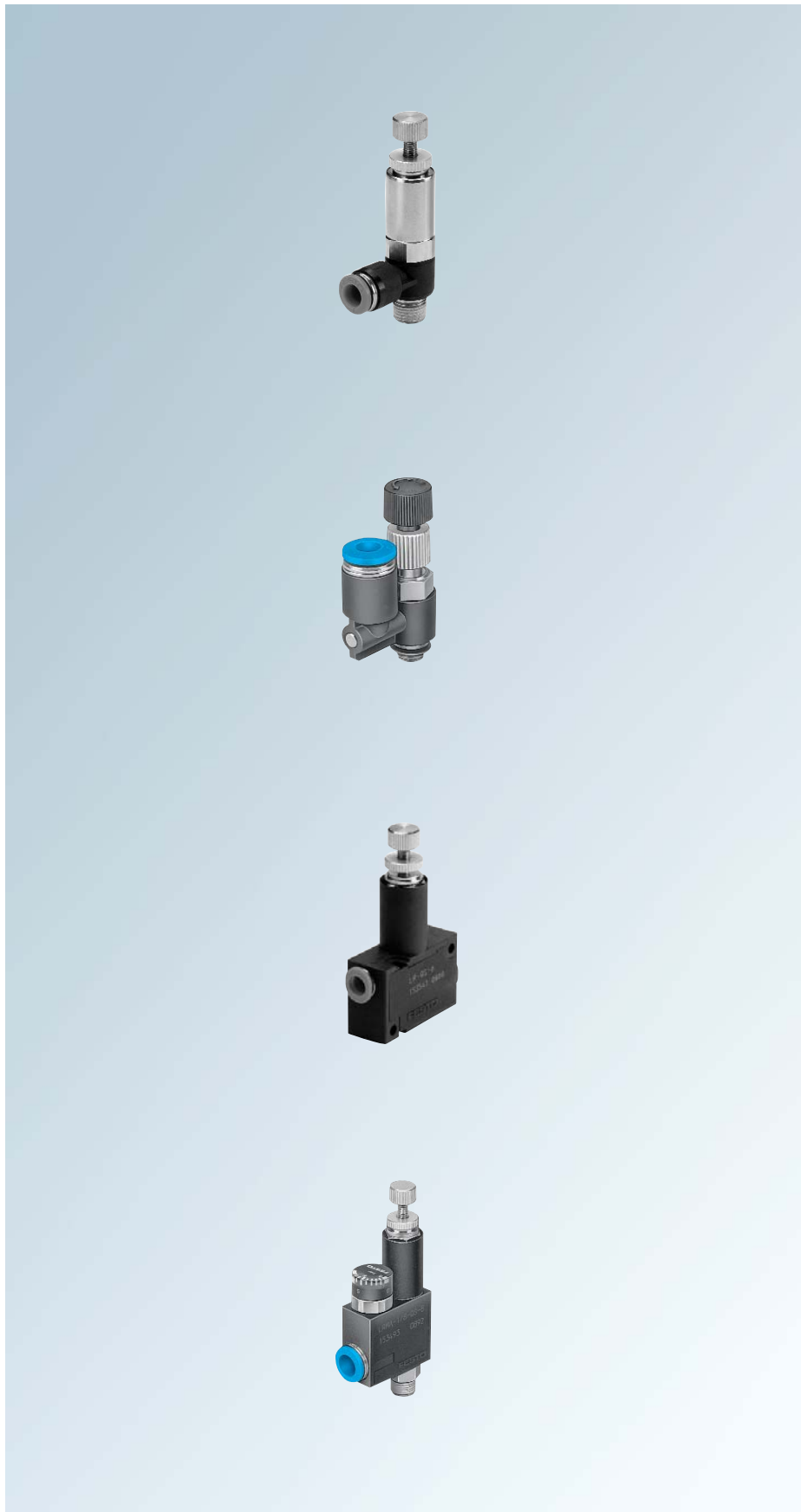

Inch Series

ISO/R Thread Series

With or without gauge

Elbow Connector and Fitting

Parallel Connector and Fitting

Two connectors

Differential pressure regulators

For complete dimensional and technical information, visit: [www.festo.com/us](http://www.festo.com/us) and view our online catalog, or contact your Product Support team via:  
Phone: 1.800.99.FESTO (1.800.993.3786)  
Email: [product.support@us.festo.com](mailto:product.support@us.festo.com)

# Pressure Regulators – Inch Series

Quick Star Flow/Pressure Controls

**Pressure Regulator, UNF, without Gauge, with Elbow Connector Housing: Polymer**




Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190924	LR-10-32-UFN-QS-5/32-U	10-32	5/32	7/16
190925	LR-10-32-UFN-QS-3/16-U	10-32	3/16	7/16
190926	LR-10-32-UFN-QS-1/4-U	10-32	1/4	7/16

**Pressure Regulator, NPT, without Gauge, with Elbow Connector Housing: Polymer**



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190927	LR-1/8-NPT-QS-5/32-U	1/8	5/32	9/16
190928	LR-1/8-NPT-QS-3/16-U	1/8	3/16	9/16
190929	LR-1/8-NPT-QS-1/4-U	1/8	1/4	9/16
190930	LR-1/8-NPT-QS-5/16-U	1/8	5/16	9/16
190931	LR-1/4-NPT-QS-3/16-U	1/4	3/16	11/16
190932	LR-1/4-NPT-QS-1/4-U	1/4	1/4	11/16
190933	LR-1/4-NPT-QS-5/16-U	1/4	5/16	11/16

**Pressure Regulator, without Gauge, with 2 Connectors Housing: Polymer**

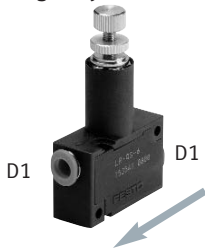

Ordering Data		
Part No.	Type	For Tubing O.D. D1 [inch]
190918	LR-QS-1/4-U	1/4

**Pressure Regulator, NPT, with Gauge and Elbow Connector Housing: Polymer**




Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
192751	LRMA-1/16-NPT-QS-3/16-U	1/16	3/16	1/2
192752	LRMA-1/16-NPT-QS-1/4-U	1/16	1/4	1/2
190920	LRMA-1/8-NPT-QS-1/4-U	1/8	1/4	1/2
190921	LRMA-1/8-NPT-QS-5/16-U	1/8	5/16	1/2
190922	LRMA-1/4-NPT-QS-1/4-U	1/4	1/4	11/16
190923	LRMA-1/4-NPT-QS-5/16-U	1/4	5/16	11/16

\* Packaged in quantities of 10. (No asterisk = items sold by the unit.)  
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

# Pressure Regulators – Inch Series

Quick Star Flow/Pressure Controls

**Pressure Regulator, with Gauge and 2 Connectors**  
Housing: Polymer

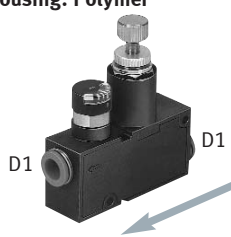

Ordering Data		
Part No.	Type	For Tubing O.D. D1 [inch]
190916	LRMA-QS-1/4-U	1/4

**Differential Pressure Regulator, UNF, with Parallel Connector**  
Housing: Polymer



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190890	LRL-10-32-UFN-QS-5/32-U	10-32	5/32	5/16

**Differential Pressure Regulator, NPT, with Parallel Connector**  
Housing: Polymer



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190891	LRL-1/8-NPT-QS-5/32-U	1/8	5/32	7/16
190892	LRL-1/8-NPT-QS-3/16-U	1/8	3/16	7/16
190893	LRL-1/8-NPT-QS-1/4-U	1/8	1/4	7/16
190894	LRL-1/8-NPT-QS-5/16-U	1/8	5/16	7/16
190895	LRL-1/4-NPT-QS-3/16-U	1/4	3/16	9/16
190896	LRL-1/4-NPT-QS-1/4-U	1/4	1/4	9/16
190897	LRL-1/4-NPT-QS-5/16-U	1/4	5/16	9/16
190898	LRL-1/4-NPT-QS-3/8-U	1/4	3/8	9/16
190899	LRL-3/8-NPT-QS-5/16-U	3/8	5/16	3/4
190900	LRL-3/8-NPT-QS-3/8-U	3/8	3/8	3/4
190901	LRL-3/8-NPT-QS-1/2-U	3/8	1/2	3/4
190902	LRL-1/2-NPT-QS-1/2-U	1/2	1/2	1

\* Packaged in quantities of 10. (No asterisk = items sold by the unit.)  
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

# Pressure Regulators – Inch Series

Quick Star Flow/Pressure Controls

**Differential Pressure Regulator,  
UNF, with Elbow Connector  
Housing: Polymer**



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
190903	LRLL-10-32-UNF-QS-5/32-U	10-32	5-32	5/16

**Differential Pressure Regulator,  
NPT, with Elbow Connector  
Housing: Polymer**



Ordering Data				
Part No.	Type	Thread C	For Tubing O.D. D1 [inch]	Wrench Size [inch]
192828	LRLLM-1/16-NPT-QS-1/8-U	1/16	1/8	7/16
192829	LRLLM-1/16-NPT-QS-5/32-U	1/16	5/32	7/16
190904	LRLL-1/8-NPT-QS-5/32-U	1/8	5/32	7/16
190905	LRLL-1/8-NPT-QS-3/16-U	1/8	3/16	7/16
190906	LRLL-1/8-NPT-QS-1/4-U	1/8	1/4	7/16
190907	LRLL-1/8-NPT-QS-5/16-U	1/8	5/16	7/16
190908	LRLL-1/4-NPT-QS-3/16-U	1/4	3/16	9/16
190909	LRLL-1/4-NPT-QS-1/4-U	1/4	1/4	9/16
190910	LRLL-1/4-NPT-QS-5/16-U	1/4	5/16	9/16
190911	LRLL-1/4-NPT-QS-3/8-U	1/4	3/8	9/16
190912	LRLL-3/8-NPT-QS-5/16-U	3/8	5/16	3/4
190913	LRLL-3/8-NPT-QS-3/8-U	3/8	3/8	3/4
190914	LRLL-3/8-NPT-QS-1/2-U	3/8	1/2	3/4
190915	LRLL-1/2-NPT-QS-1/2-U	1/2	1/2	1

\* Packaged in quantities of 10. (No asterisk = items sold by the unit.)  
Ask Festo or your authorized Festo distributor about part numbers of items offered in bulk package sizes.

# Festo - Your Partner in Automation



**1 Festo Inc.**  
5300 Explorer Drive  
Mississauga, ON L4W 5G4  
Canada

**Festo Customer Interaction Center**  
Tel: 1 877 463 3786  
Fax: 1 877 393 3786  
Email: [customer.service.ca@festo.com](mailto:customer.service.ca@festo.com)

**2 Festo Pneumatic**  
Av. Ceylán 3,  
Col. Tequesquináhuac  
54020 Tlalnepantla,  
Estado de México

**Multinational Contact Center**  
01 800 337 8669  
[ventas.mexico@festo.com](mailto:ventas.mexico@festo.com)

**3 Festo Corporation**  
1377 Motor Parkway  
Suite 310  
Islandia, NY 11749

**Festo Customer Interaction Center**  
1 800 993 3786  
1 800 963 3786  
[customer.service.us@festo.com](mailto:customer.service.us@festo.com)

**4 Regional Service Center**  
7777 Columbia Road  
Mason, OH 45040

Connect with us



[www.festo.com/socialmedia](http://www.festo.com/socialmedia)



[www.festo.com](http://www.festo.com)

Subject to change