

Cartridge fittings QSP

FESTO



Cartridge fittings QSP

Technical data

FESTO

General technical data	
Size	Mini Standard
Design	Push-pull principle
Mounting position	Any
Type of seal on threaded plug	O-ring

Operating and environmental conditions					
Cartridge fitting	QSP10	QSP...10	QSP...14	QSP...18	QSP...20
Operating pressure [bar]	-0.95 ... +10				
complete temperature range					
Operating medium	Compressed air in accordance with ISO 8573-1:2010 [7:-:-]				
Note on operating/pilot medium	Operation with lubricated medium possible				
Ambient temperature [°C]	0 ... +60	-5 ... +60	-5 ... +60	-5 ... +60	-5 ... +60
Corrosion resistance class CRC ¹⁾	1				
Maritime classification	See certificate ²⁾				

- 1) Corrosion resistance class CRC 1 to Festo standard FN 940070
Low corrosion stress. For dry indoor applications or transport and storage protection. Also applies to parts behind covers, in the non-visible interior area, and parts which are covered in the application (e.g. drive trunnions).
- 2) Additional information www.festo.com/sp → Certificates.


Materials					
Cartridge fitting	QSP10	QSP...10	QSP...14	QSP...18	QSP...20
Housing	Nickel-plated brass	Reinforced PA	Reinforced PA	Reinforced PA	Reinforced PA
Releasing ring	POM (colour: blue)				
Tube retaining claw	High-alloy stainless steel				
Tubing seal	NBR				
Note on materials	Conforms to RoHS				

Cartridge fittings QSP

Technical data

FESTO


Cartridge fittings QSP10

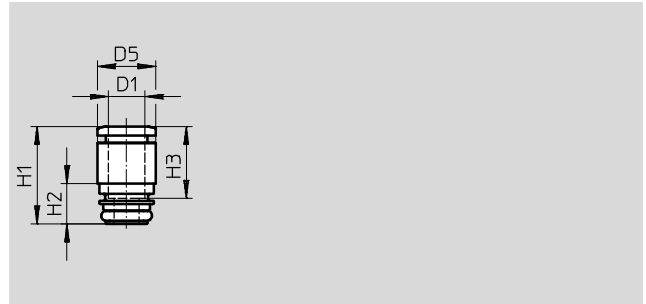

Dimensions and ordering data								
Pneumatic connection		D5	H1	H2	H3	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]	Ø						
10	4	9.8	16.2	6.7	11.6	172972	QSP10-4	10
	6	9.8	16.2	6.7	11.9	172973	QSP10-6	10

1) Packaging unit quantity.

Cartridge fittings QSPKG10

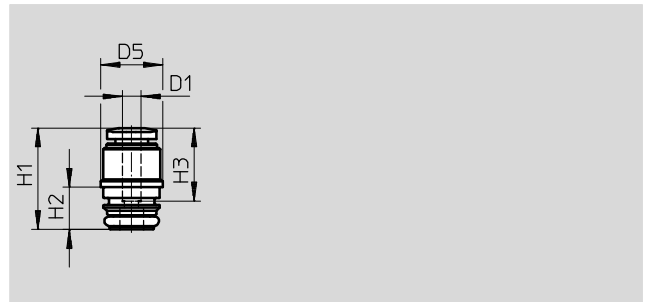

Dimensions and ordering data										
Pneumatic connection		Nominal size	D5	H1	H2	H3	Weight/piece	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]	[mm]	Ø				[g]			
10	3	1.6	9.75	16.1	6.7	11.6	1.5	132621	QSPKG10-3	10
	4	2.3	9.75	16.1	6.7	11.6	1.4	132622	QSPKG10-4	10
	6	3.7	10.55	18.1	6.7	11.9	1.8	132623	QSPKG10-6	10


1) Packaging unit quantity.

Cartridge fittings QSP

Technical data

FESTO


Cartridge fittings QSPLKG10

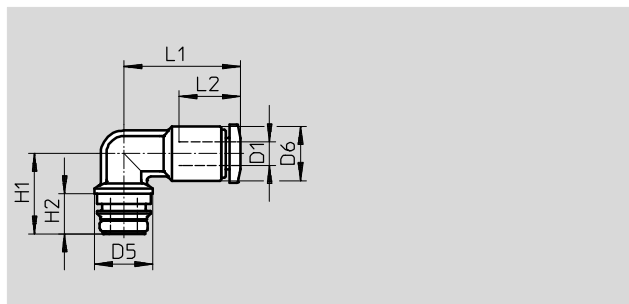

Dimensions and ordering data												
Pneumatic connection		Nominal size	D5	D6	H1	H2	L1	L2	Weight/piece	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]	[mm]	Ø	Ø					[g]			
10	3	1.8	9.75	9.4	13.4	6.7	18.2	11.6	2.1	132853	QSPLKG10-3	10
	4	2.3	9.75	9.4	13.4	6.7	18.2	11.6	2	132920	QSPLKG10-4	10
	6	3.3	9.75	10.55	14.4	6.7	19.8	11.9	2.7	132921	QSPLKG10-6	10

1) Packaging unit quantity.

Cartridge fittings QSPLLKG10

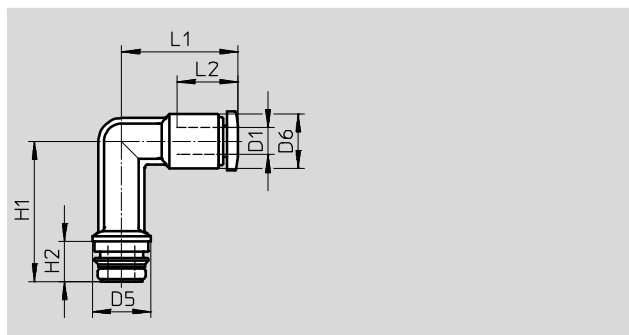

Dimensions and ordering data												
Pneumatic connection		Nominal size	D5	D6	H1	H2	L1	L2	Weight/piece	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]	[mm]	Ø	Ø					[g]			
10	3	1.8	9.75	9.4	23.4	6.7	18.2	11.6	2.5	132861	QSPLLKG10-3	10
	4	2.3	9.75	9.4	23.4	6.7	18.2	11.6	2.4	132925	QSPLLKG10-4	10
	6	3.3	9.75	10.55	26.4	6.7	19.8	11.9	3.2	132926	QSPLLKG10-6	10


1) Packaging unit quantity.

Cartridge fittings QSP

Technical data

FESTO


Cartridge fittings QSPK10

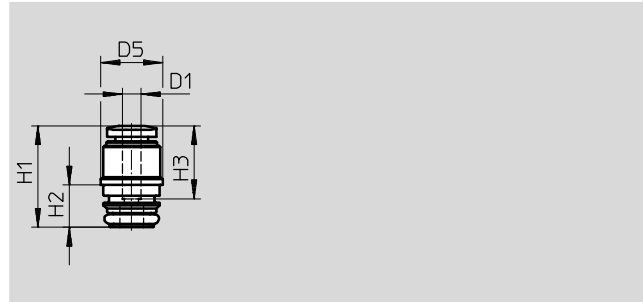

Dimensions and ordering data										
Pneumatic connection		Nominal size [mm]	D5 Ø	H1	H2	H3	Weight/piece [g]	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]									
10	3	1.6	9.75	16.1	6.7	11.6	1.5	132978	QSPK10-3	10
	4	2.3	9.75	16.1	6.7	11.6	1.4	132979	QSPK10-4	10
	6	3.7	10.55	18.1	6.7	11.9	1.8	132980	QSPK10-6	10

1) Packaging unit quantity.

Cartridge fittings QSPLK10

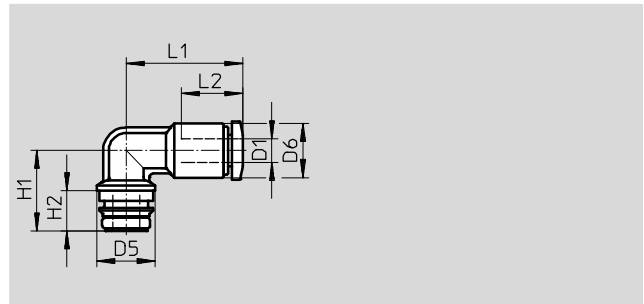

Dimensions and ordering data												
Pneumatic connection		Nominal size [mm]	D5 Ø	D6 Ø	H1	H2	L1	L2	Weight/piece [g]	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]											
10	4	2.3	9.75	9,4	13.4	6.7	19.4	19.4	2.1	132601	QSPLK10-4	10
	6	3.5	9.75	11	14.4	6.7	20.3	11.9	2.8	132602	QSPLK10-6	10


1) Packaging unit quantity.

Cartridge fittings QSP

Technical data

FESTO

Cartridge fittings QSPLLK10

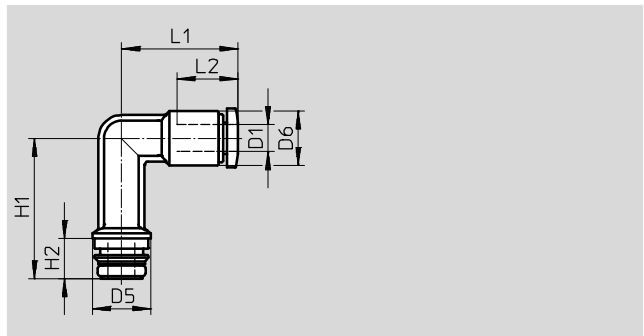

Dimensions and ordering data												
Pneumatic connection		Nominal size	D5	D6	H1	H2	L1	L2	Weight/piece	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]	[mm]	Ø	Ø					[g]			
10	4	2.3	9.75	9,4	23.4	6.7	19.4	11.6	2.4	132603	QSPLLK10-4	10
	6	3.5	9.75	11	26.4	6.7	20.3	11.9	3.3	132604	QSPLLK10-6	10


1) Packaging unit quantity.

Cartridge fittings QSP

Technical data

FESTO


Cartridge fittings QSPKG14

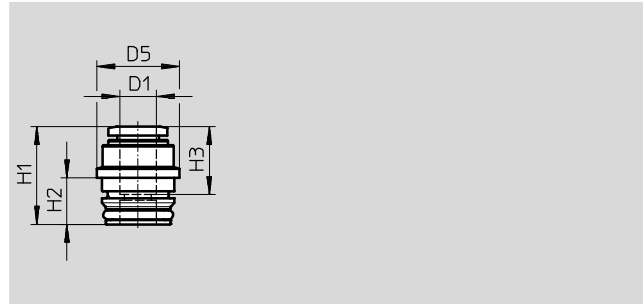

Dimensions and ordering data										
Pneumatic connection		Nominal size [mm]	D5 Ø	H1	H2	H3	Weight/piece [g]	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]									
14	6	3.5	13.7	16.5	7.75	11.9	2.4	132930	QSPKG14-6	10
	8	5.2	14.6	25.2	7.75	18.1	5.3	132931	QSPKG14-8	10

1) Packaging unit quantity.

Cartridge fittings QSPLKG14

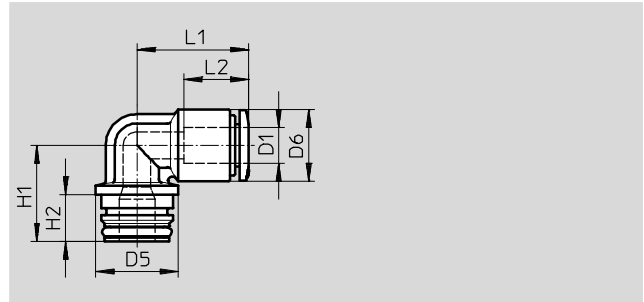

Dimensions and ordering data												
Pneumatic connection		Nominal size [mm]	D5 Ø	D6 Ø	H1	H2	L1	L2	Weight/piece [g]	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]											
14	6	3.3	13.7	11.9	16	7.75	18.8	11.9	3.5	132938	QSPLKG14-6	10
	8	4.8	13.7	14.6	17.8	7.75	28.2	18.1	7.1	132939	QSPLKG14-8	10


1) Packaging unit quantity.

Cartridge fittings QSP

Technical data

FESTO

Cartridge fittings QSPLLKG14

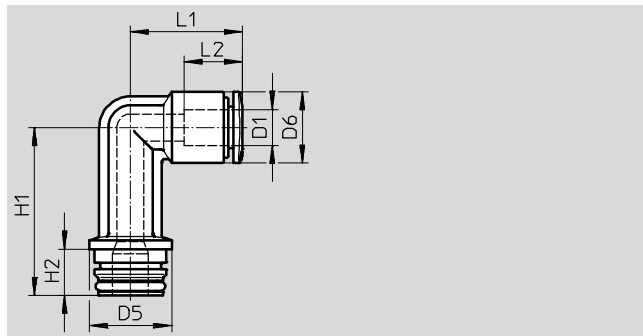

Dimensions and ordering data												
Pneumatic connection		Nominal size	D5	D6	H1	H2	L1	L2	Weight/piece	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]	[mm]	Ø	Ø					[g]			
14	6	3.4	13.7	11.9	28.0	7.75	18.8	11.9	4.0	132942	QSPLLKG14-6	10
	8	4.7	13.7	14.6	33.3	7.75	28.2	18.1	8.1	132943	QSPLLKG14-8	10




1) Packaging unit quantity.

Cartridge fittings QSP

Technical data

FESTO

Cartridge fittings QSPK18

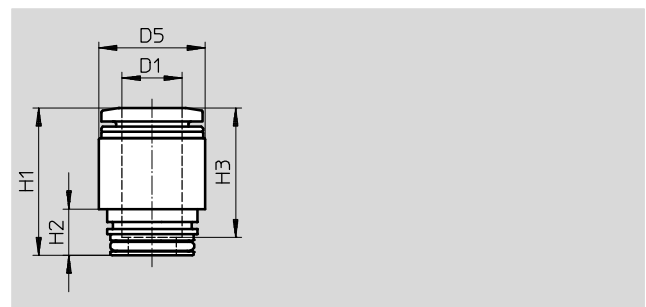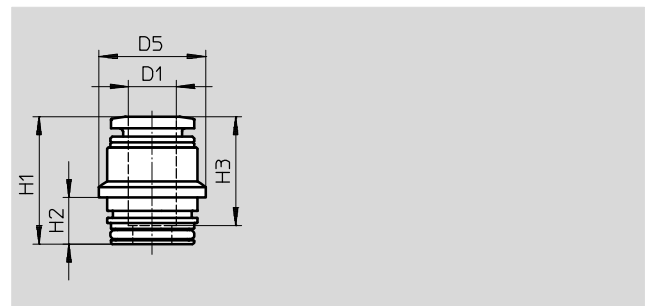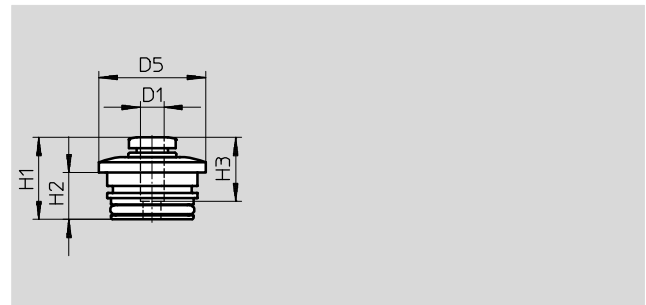

Dimensions and ordering data										
Pneumatic connection		Nominal size [mm]	D5 Ø	H1	H2	H3	Weight/piece [g]	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]									
18	4	2.3	17.7	13.6	7.75	11.6	2.8	130839	QSPK18-4	10
	6	3.8	17.7	13.7	7.75	11.9	3	130840	QSPK18-6	10
	8	5.5	17.7	20.7	7.75	18.2	5.4	130841	QSPK18-8	10
	10	6.7	17.7	24.5	7.75	20.2	8.1	130842	QSPK18-10	10


1) Packaging unit quantity.

Cartridge fittings QSP

Technical data

FESTO


Cartridge fittings QSPLK18

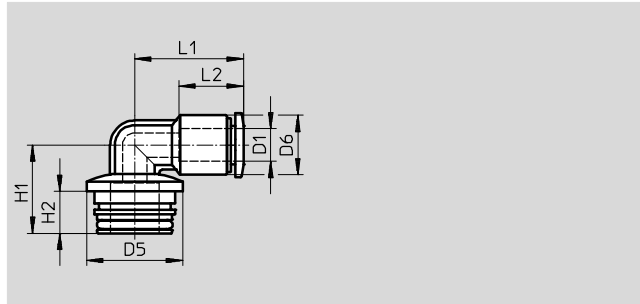

Dimensions and ordering data												
Pneumatic connection		Nominal size [mm]	D5 Ø	D6 Ø	H1	H2	L1	L2	Weight/piece [g]	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]											
18	4	2.3	17.7	9	15.3	7.75	19.4	11.6	3.2	130843	QSPLK18-4	10
	6	3.6	17.7	11	16.3	7.75	20.3	11.9	3.9	130844	QSPLK18-6	10
	8	5.2	17.7	15	18.3	7.75	27.2	18.2	7.5	130845	QSPLK18-8	10
	10	6.7	17.7	17.7	19.6	7.75	29.5	20.2	10.8	132639	QSPLK18-10	10

1) Packaging unit quantity.

Cartridge fittings QSPLK18

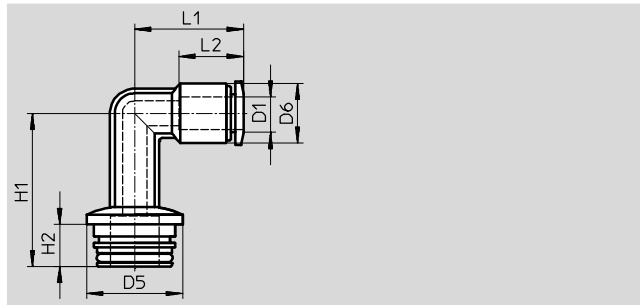

Dimensions and ordering data												
Pneumatic connection		Nominal size [mm]	D5 Ø	D6 Ø	H1	H2	L1	L2	Weight/piece [g]	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]											
18	4	2.3	17.7	9	25.3	7.75	19.4	11.6	3.5	130846	QSPLK18-4	10
	6	3.6	17.7	11	28.3	7.75	20.3	11.9	4.3	130847	QSPLK18-6	10
	8	5.2	17.7	15	34.3	7.75	27.2	18.2	8.1	130848	QSPLK18-8	10
	10	6.4	17.7	17.7	38.3	7.75	29.5	20.2	12	132640	QSPLK18-10	10


1) Packaging unit quantity.

Cartridge fittings QSP

Technical data

FESTO


Cartridge fittings QSPKG18

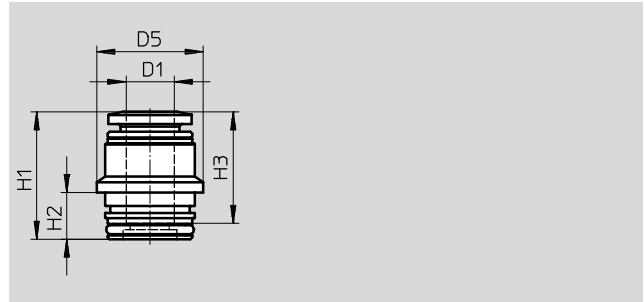

Dimensions and ordering data										
Pneumatic connection		Nominal size [mm]	D5 Ø	H1	H2	H3	Weight/piece [g]	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]									
18	8	5.5	17.7	20.7	7.75	18.2	5.4	132649	QSPKG18-8	10
	10	6.7	17.7	24.5	7.75	20.2	8.1	132650	QSPKG18-10	10

1) Packaging unit quantity.

Cartridge fittings QSPLKG18

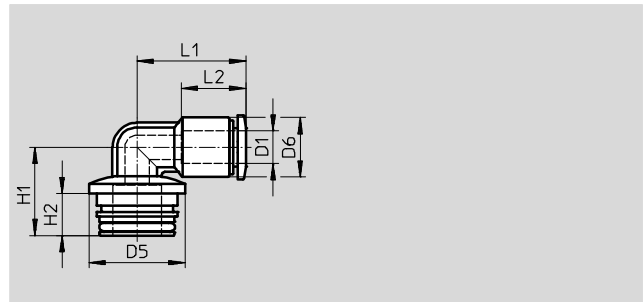

Dimensions and ordering data											
Pneumatic connection		Nominal size [mm]	D5 Ø	D6 Ø	H1	H2	L1	L2	Weight/piece [g]	Part No.	Type
Cartridge [mm]	For tubing O.D. D1 [mm]										
18	8	5.2	17.7	15	18.3	7.75	27.2	18.2	7.5	132946	QSPLKG18-8
	10	6.7	17.7	17.7	19.6	7.75	29.5	20.2	10.8	132947	QSPLKG18-10


1) Packaging unit quantity.

Cartridge fittings QSP

Technical data

FESTO

Cartridge fittings QSPLLKG18

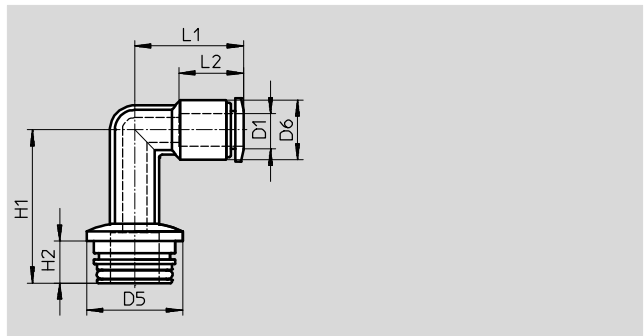

Dimensions and ordering data												
Pneumatic connection		Nominal size [mm]	D5 Ø	D6 Ø	H1	H2	L1	L2	Weight/piece [g]	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]											
18	8	5.2	17.7	15	18.3	7.75	27.2	18.2	8.1	132950	QSPLLKG18-8	10
	10	6.4	17.7	17.7	19.6	7.75	29.5	20.2	12	132951	QSPLLKG18-10	10


1) Packaging unit quantity.

Cartridge fittings QSP

Technical data

FESTO


Cartridge fittings QSPKG20

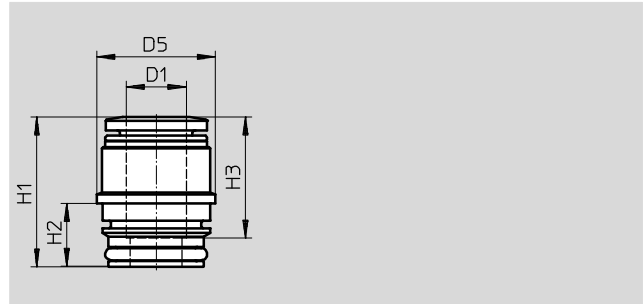

Dimensions and ordering data										
Pneumatic connection		Nominal size [mm]	D5 Ø	H1	H2	H3	Weight/piece [g]	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]									
20	8	5.4	19.75	19.1	10.6	18.1	6	132633	QSPKG20-8	10
	10	6.4	19.75	25	10.6	20.2	9	132634	QSPKG20-10	10
	12	8.3	21.1	32.7	10.6	23.4	13	132635	QSPKG20-12	10

1) Packaging unit quantity.

Cartridge fittings QSPLKG20

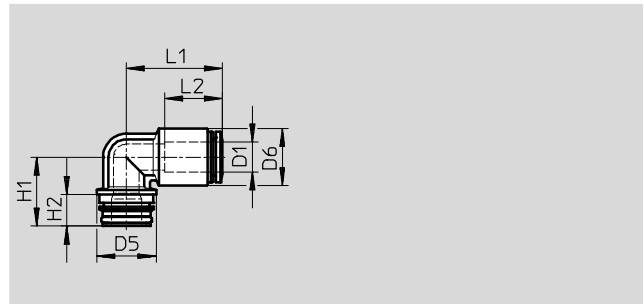

Dimensions and ordering data												
Pneumatic connection		Nominal size [mm]	D5 Ø	D6 Ø	H1	H2	L1	L2	Weight/piece [g]	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]											
20	8	4.8	19.75	16.0	21.5	10.6	29.7	18.1	10	132855	QSPLKG20-8	10
	10	6.1	19.75	19.0	23.0	10.6	32.0	20.2	14	132856	QSPLKG20-10	10
	12	7.7	19.75	21.1	24.0	10.6	36.2	23.4	17	132857	QSPLKG20-12	10


1) Packaging unit quantity.

Cartridge fittings QSP

Technical data

FESTO

Cartridge fittings QSPLLKG20

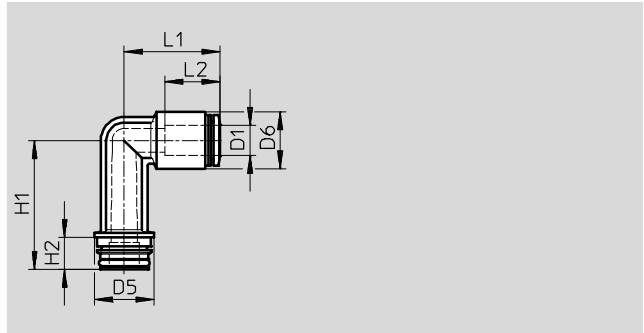

Dimensions and ordering data												
Pneumatic connection		Nominal size [mm]	D5 Ø	D6 Ø	H1	H2	L1	L2	Weight/piece [g]	Part No.	Type	PU ¹⁾
Cartridge [mm]	For tubing O.D. D1 [mm]											
20	8	4.8	19.75	16.0	38.5	10.6	29.7	18.1	11	132863	QSPLLKG20-8	10
	10	6	19.75	19.0	43.0	10.6	32.0	20.2	15	132864	QSPLLKG20-10	10
	12	7.3	19.75	21.1	45.9	10.6	36.2	23.4	20	132865	QSPLLKG20-12	10


1) Packaging unit quantity.

Cartridge fittings QSP

Technical data

FESTO

Blanking plug QSPC10

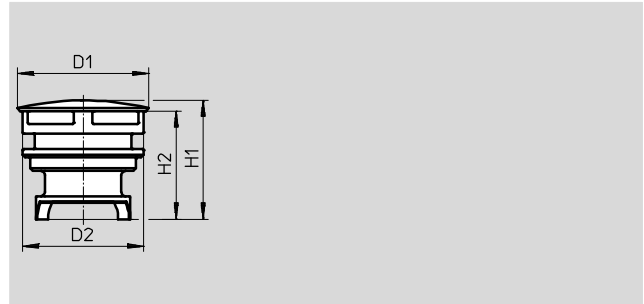

Operating and environmental conditions		
Operating pressure [bar]	0 ... +8	
complete temperature range		
Ambient temperature [°C]	−5 ... +60	
Corrosion resistance class CRC ¹⁾	0	

- 1) Corrosion resistance class CRC 0 to Festo standard FN 940070
No corrosion stress. Applies to small, optically irrelevant standard parts such as threaded pins, circlips and clamping sleeves which are usually only available in a phosphated or burnished version (and possibly oiled) as well as to ball bearings (for components < CRC 3) and plain bearings.

Materials	
Blanking plug	POM
O-ring	NBR
Note on materials	Conforms to RoHS
	Free of copper and PTFE

Dimensions and ordering data							
D1	D2	H1	H2	Weight/piece [g]	Part No.	Type	PU ¹⁾
Ø 9.8	9	8.8	8.0	0.4	562243	QSPC10	10



- 1) Packaging unit quantity.

Cartridge fittings QSP

Technical data

FESTO

Blanking plug QSP...-PTB

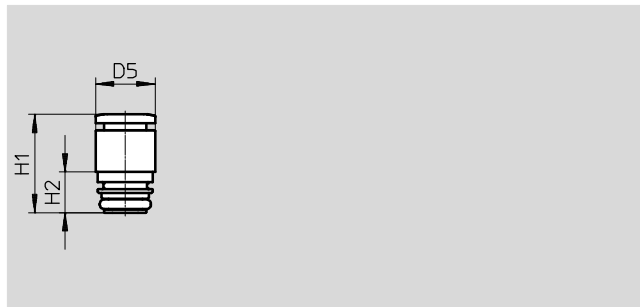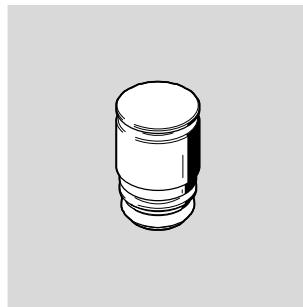

General technical data	
Mounting position	Any
Operating and environmental conditions	
Operating pressure [bar]	-0.95 ... +10
complete temperature range	
Operating medium	Compressed air in accordance with ISO 8573-1:2010 [7:-:-]
Note on operating/pilot medium	Operation with lubricated medium possible
Ambient temperature [°C]	-10 ... +60
Maritime classification	See certificate ¹⁾

1) Additional information www.festo.com/sp → Certificates.

Materials	
Housing	PA
Tubing seal	NBR
Note on materials	Conforms to RoHS

Dimensions and ordering data						
D5 Ø	H1	H2	Weight/piece [g]	Part No.	Type	PU ¹⁾
9.7 ±0.1	16.2	6.7	1.1	172976	QSP10-PTB	1
13.8	22	7.8 -0.1	2.7	172987	QSP14-PTB	1
16.8	24.5	7.8 -0.1	4.7	172996	QSP17-PTB	1

1) Packaging unit quantity.

Festo - Your Partner in Automation



1 Festo Inc.
5300 Explorer Drive
Mississauga, ON L4W 5G4
Canada

Festo Customer Interaction Center

Tel: 1 877 463 3786
Fax: 1 877 393 3786
Email: customer.service.ca@festo.com



2 Festo Pneumatic
Av. Ceylán 3,
Col. Tequesquináhuac
54020 Tlalneantla,
Estado de México

Multinational Contact Center

01 800 337 8669
ventas.mexico@festo.com



3 Festo Corporation
1377 Motor Parkway
Suite 310
Islandia, NY 11749

Festo Customer Interaction Center

1 800 993 3786
1 800 963 3786
customer.service.us@festo.com



4 Regional Service Center
7777 Columbia Road
Mason, OH 45040

Connect with us



www.festo.com/socialmedia



www.festo.com

Subject to change