


Plug connectors SD-SUB-D-ST for valves, for self-assembly

FESTO

Technical data

Plug connector SD-SUB-D-ST

- Plug for inputs/outputs
- Can be assembled with any cable lengths
- 15-pin or 25-pin
- Sub-D

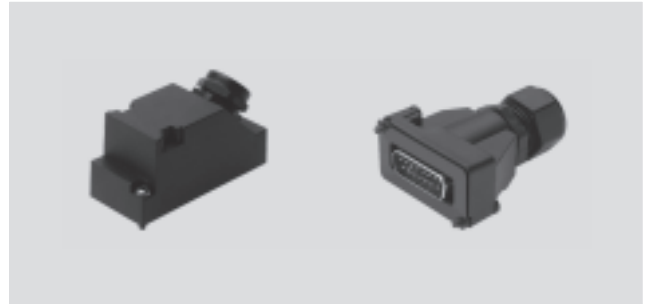

General technical data		
Type	SD-SUB-D-ST	
Type of mounting	2x M3x16 screws	
Mounting position	Any	
Operating voltage range	[V AC]	Max. 250
	[V DC]	Max. 250
Acceptable current load	[A]	5
Protection class to EN 60529	IP65 (assembled)	

Materials		
Type	SD-SUB-D-ST-15	SD-SUB-D-ST-25
Housing	PA	
Seals	Neoprene	NBR
Note on materials	RoHS-compliant	
Pin contact	Gold-plated copper base alloy	

Operating and environmental conditions		
Ambient temperature	[°C]	−20 ... +80

Plug connectors SD-SUB-D-ST for valves, for self-assembly


Technical data

FESTO

Dimensions


Download CAD Data → www.festo.com/us/cad

SD-SUB-D-ST-15

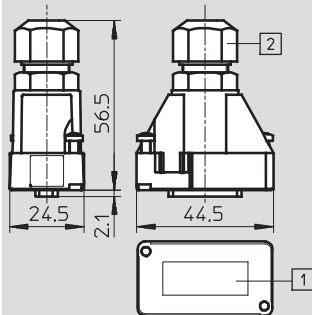

- 1 Plug, 15-pin, Sub-D
- 2 Cable connector Pg9

SD-SUB-D-ST-25

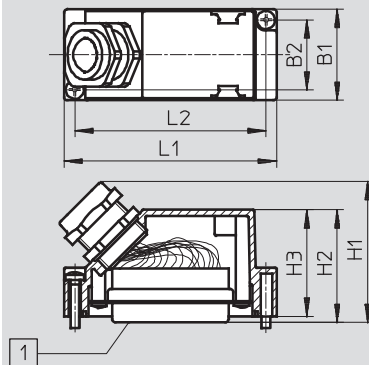

Type	1	B1	B2	H1	H2	H3	L1	L2
SD-SUB-D-ST25	Plug, 25-pin, Sub-D	30	23	47	37	35	70	63

Ordering data

	Electrical connection	Cable connector	Perm. cable Ø [mm]	Weight [g]	Part No.	Type
	Plug, 15-pin, Sub-D	Pg9	6 ... 9	37	192768	SD-SUB-D-ST15
	Plug, 25-pin, Sub-D	Pg11	7 ... 12	51	527522	SD-SUB-D-ST25

Festo - Your Partner in Automation



1 Festo Inc.
5300 Explorer Drive
Mississauga, ON L4W 5G4
Canada

Festo Customer Interaction Center
Tel: 1 877 463 3786
Fax: 1 877 393 3786
Email: customer.service.ca@festo.com



2 Festo Pneumatic
Av. Ceylán 3,
Col. Tequesquináhuac
54020 Tlalnepantla,
Estado de México

Multinational Contact Center
01 800 337 8669
ventas.mexico@festo.com



3 Festo Corporation
1377 Motor Parkway
Suite 310
Islandia, NY 11749

Festo Customer Interaction Center
1 800 993 3786
1 800 963 3786
customer.service.us@festo.com



4 Regional Service Center
7777 Columbia Road
Mason, OH 45040

Connect with us

www.festo.com/socialmedia



www.festo.com

Subject to change