


Connecting cables NEBC, for controllers

Technical data

Connecting cable KDI

- Connecting cable (programming cable) for different applications
- Pre-assembled at both ends
- Cable lengths: 3 m

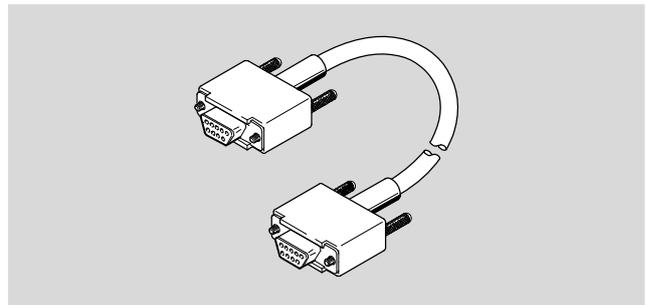

General technical data	
Type of mounting	Screws 4-40 UNC
Mounting position	Any

Materials	
Housing	PBT
Contacts	Gold-plated copper base alloy
Union nut	Nickel-plated brass
Cable sheath	PVC

Operating and environmental conditions		
Ambient temperature	[°C]	-30 ... +80
Ambient temperature for flexible cable installation	[°C]	-10 ... +80

Dimensions Download CAD data → www.festo.com

1 Straight socket, 9-pin, Sub-D
2 Straight plug, 9-pin, Sub-D

Ordering data						
	Electrical connection	Cable composition [mm ²]	Cable length [m]	Weight [g]	Part No.	Type
	Straight socket, 9-pin, Sub-D – straight plug, 9-pin, Sub-D	9x0.22	3	156	151915	KDI-PPA-3-BU9