

Data sheet

Plug PS1-SAC

- Power supply plug, 30-pin
- Simple cable connection using clamping technology


General technical data

Electrical connection		10-pin socket, 30-pin terminal strip
Operating voltage range	[V AC]	Max. 50
Type of mounting		2x M2x7 screws With through-hole
Connection cross section	[mm ²]	0.08 ... 0.75

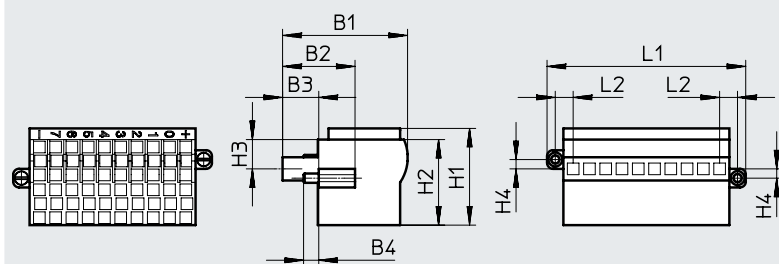
Materials

Housing	PBT
---------	-----

Operating and environmental conditions

 
Ambient temperature	[°C]	-20 ... +100
---------------------	------	--------------

Dimensions

 Download CAD data → www.festo.com


	B1	B2	B3	B4	H1	H2	H3	H4	L1	L2
PS1-SAC31	26.9	15.6	7.6	3.3 ... 3.9	20.8	18.4	6.3	2	42.7	3.9

Ordering data

	Electrical connection	Current rating [A]	Weight [g]	Part no.	Type
	10-pin socket, 30-pin terminal strip	0.5	25	197162	PS1-SAC31-30POL+LED