


Magnetically-Coupled Rodless Cylinders, Type DGO

Yoke Mounting Bracket, Type FKG-...-B

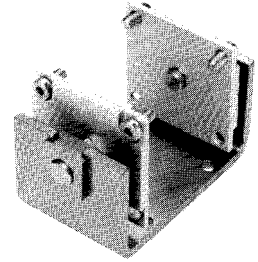

Yoke Mounting Bracket Type FKG-...-B

The yoke mounting bracket prevents moment arm torque on the yoke by transferring the torque force to the centerline of the yoke. This greatly reduces the force lost to bearing friction and compensates for non-parallel alignment.


Order Numbers

Inch Series:

13000110	FKG-5/8-B
546541	FKG-3/4-B
546542	FKG-1-B
546543	FKG-1-1/4-B
546544	FKG-1-5/8-B

Metric Series:

15233	FKG-16-B
33339	FKG-20-B
15234	FKG-25-B
33340	FKG-32-B
15235	FKG-40-B

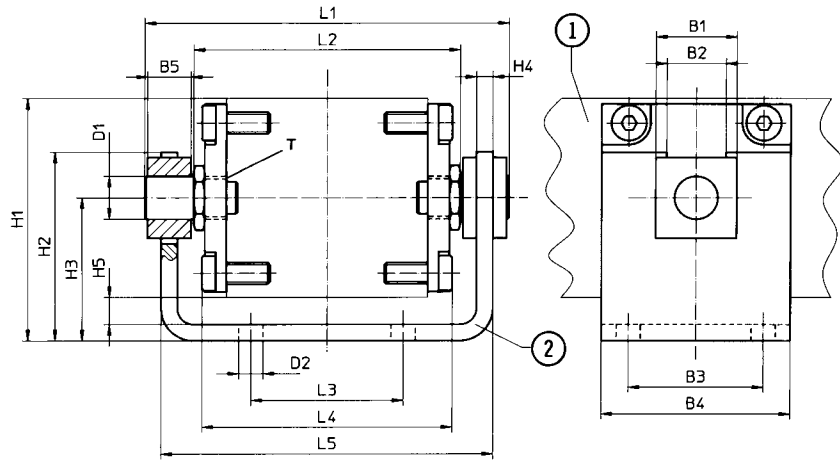

Maximum permissible alignment error on longitudinal axis of cylinder (± 0.039 in / 1 mm).

- ① Rodless cylinder yoke
- ② Can be repositioned by 180° from mounting surface

Type FKG-...- in		B1 in / mm	B2 in / mm	B3 in / mm	B4 in / mm	B5 in / mm	D1 dia. in / mm	D2 in / mm	H1 in / mm	H2 in / mm
5/8	16	0.71 / 18	0.55 / 14	1.02 / 26	1.57 / 40	0.31 / 8	0.39 / 10	0.22 / 5.5	1.85 / 47	1.57 / 40
3/4	20	0.71 / 18	0.55 / 14	1.26 / 32	1.65 / 42	0.32 / 8	0.39 / 10	0.22 / 5.5	2.09 / 53	1.69 / 43
1	25	0.87 / 22	0.63 / 16	1.42 / 36	1.97 / 50	0.47 / 12	0.47 / 12	0.26 / 6.6	2.48 / 63	1.97 / 50
1-1/4	32	0.87 / 22	0.63 / 16	1.89 / 48	2.36 / 60	0.47 / 12	0.47 / 12	0.26 / 6.6	2.87 / 73	2.17 / 55
1-5/8	40	1.18 / 30	0.87 / 22	1.97 / 50	2.76 / 70	0.63 / 16	0.63 / 16	0.35 / 9	3.54 / 90	2.76 / 70
Type FKG-...- in		H3 in / mm	H4 in / mm	H5 in / mm	L1 in / mm	L2 in / mm	L3 in / mm	L4 in / mm	L5 in / mm	T
5/8	16	1.14 / 29	0.16 / 4	0.28 / 7	2.91 / 74	2.13 / 54	1.02 / 26	1.93 / 49	2.68 / 68	M10 x 1
3/4	20	1.26 / 32	0.16 / 4	0.28 / 7	3.23 / 82	2.44 / 62	1.26 / 32	2.24 / 57	2.99 / 76	M10 x 1
1	25	1.50 / 38	0.20 / 5	0.31 / 8	3.86 / 98	2.76 / 70	1.42 / 36	2.52 / 64	3.50 / 89	M12 x 1
1-1/4	32	1.69 / 43	0.30 / 5	0.32 / 8	4.25 / 108	3.15 / 80	1.89 / 48	2.91 / 74	3.90 / 99	M12 x 1
1-5/8	40	2.09 / 53	0.24 / 6	0.39 / 10	5.28 / 134	3.86 / 98	2.20 / 56	3.62 / 92	4.80 / 122	M16 x 1

Festo - Your Partner in Automation



1 Festo Inc.
5300 Explorer Drive
Mississauga, ON L4W 5G4
Canada

Festo Customer Interaction Center
Tel: 1 877 463 3786
Fax: 1 877 393 3786
Email: customer.service.ca@festo.com



2 Festo Pneumatic
Av. Ceylán 3,
Col. Tequesquináhuac
54020 Tlalnepantla,
Estado de México

Multinational Contact Center
01 800 337 8669
ventas.mexico@festo.com



3 Festo Corporation
1377 Motor Parkway
Suite 310
Islandia, NY 11749

Festo Customer Interaction Center
1 800 993 3786
1 800 963 3786
customer.service.us@festo.com



4 Regional Service Center
7777 Columbia Road
Mason, OH 45040

Connect with us



www.festo.com/socialmedia



www.festo.com

Subject to change