


Connecting cables NEBC, for controllers

Technical data

Connecting cable KDI

- Connecting cable (programming cable) for different applications
- Pre-assembled at both ends
- Cable lengths: 3 m

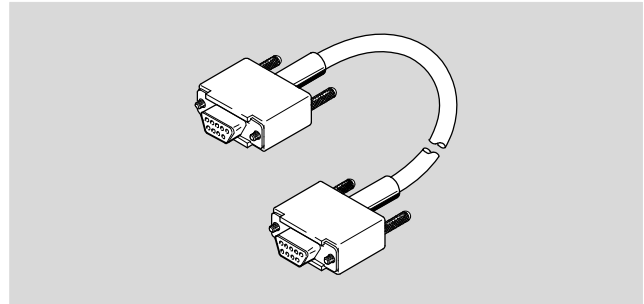

General technical data	
Type of mounting	Screws 4-40 UNC
Mounting position	Any

Materials	
Housing	PBT
Contacts	Gold-plated copper base alloy
Union nut	Nickel-plated brass
Cable sheath	PVC


Operating and environmental conditions		
Ambient temperature	[°C]	-30 ... +80
Ambient temperature for flexible cable installation	[°C]	-10 ... +80

Dimensions Download CAD data → www.festo.com

1 Straight socket, 9-pin, Sub-D
2 Straight plug, 9-pin, Sub-D

Ordering data						
	Electrical connection	Cable composition [mm ²]	Cable length [m]	Weight [g]	Part No.	Type
	Straight socket, 9-pin, Sub-D – straight plug, 9-pin, Sub-D	9x0.22	3	156	151915	KDI-PPA-3-BU9

Festo North America

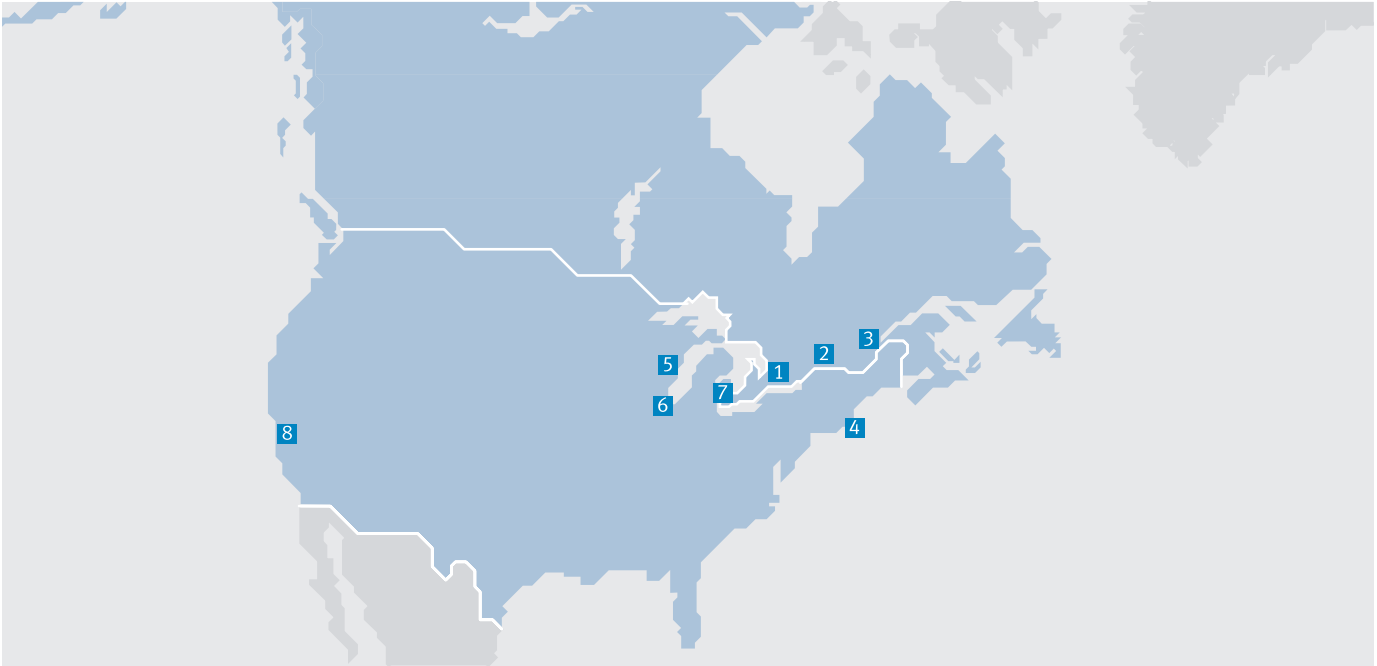

**1 Festo Canada
Headquarters
Festo Inc.**
5300 Explorer Drive
Mississauga, ON
L4W 5G4

2 Montréal
5600, Trans-Canada
Pointe-Claire, QC
H9R 1B6

3 Québec City
2930, rue Watt#117
Québec, QC
G1X 4G3



**4 Festo United States
Headquarters
Festo Corporation**
395 Moreland Road
Hauppauge, NY
11788

5 Appleton
North 922 Tower View Drive, Suite N
Greenville, WI
54942

7 Detroit
1441 West Long Lake Road
Troy, MI
48098

6 Chicago
85 W Algonquin - Suite 340
Arlington Heights, IL
60005

8 Silicon Valley
4935 Southfront Road, Suite F
Livermore, CA
94550

Festo Regional Contact Center

Canadian Customers

Commercial Support:
Tel: 1 877 GO FESTO (1 877 463 3786)
Fax: 1 877 FX FESTO (1 877 393 3786)
Email: festo.canada@ca.festo.com

Technical Support:
Tel: 1 866 GO FESTO (1 866 463 3786)
Fax: 1 877 FX FESTO (1 877 393 3786)
Email: technical.support@ca.festo.com

USA Customers

Commercial Support:
Tel: 1 800 99 FESTO (1 800 993 3786)
Fax: 1 800 96 FESTO (1 800 963 3786)
Email: customer.service@us.festo.com

Technical Support:
Tel: 1 866 GO FESTO (1 866 463 3786)
Fax: 1 800 96 FESTO (1 800 963 3786)
Email: product.support@us.festo.com