

Electrical connection technology, for inputs/outputs

Technical data – KVIA-...

- Plug socket with cable for inputs/ outputs
- Pre-assembled at both ends
- Cable lengths 5 m or 10 m
- 4-pin/5-pin
- Round plug
- Suitable for chain link trunking



General technical data	
Type	KVIA-...
Type of mounting	M16/M12 union nut
Mounting position	Any
Operating voltage range	[V AC] Max. 250
Current-carrying capacity	[A] 1
Protection class to EN 60 529	IP65 (assembled)
Material of housing	PBT
Material of contacts	Silver-plated/gold-plated bronze
Material of cable sheath	PVC
Ambient temperature	[°C] -30 ... +80

Ordering data								
	Suitable for chain link trunking	Electrical connection	Constructional design [mm ²]	Cable diameter [mm]	Product weight [g]	Cable length [m]	Part No.	Type
	■	Straight plug Straight socket	4x0.25	6.2	297	5	161984	KVIA-MPYE-5
	■	Straight plug Straight socket	4x0.25	6.2	530	10	161985	KVIA-MPYE-10
	■	Straight plug Angled socket	6x0.25	8	352	5	163882	KVIA-MPPE-5
	■	Straight plug Angled socket	6x0.25	8	828	10	163883	KVIA-MPPE-10

Electrical connection technology, for inputs/outputs

Technical data – KVIA-...

Dimensions Download CAD data → www.festo.com

Type KVIA-MPPE-...

1 Cable length 5 m or 10 m


Type KVIA-MPYE-...

1 Cable length 5 m or 10 m

Wiring allocation (socket/plug view)

Type KVIA-MPPE-...				
Plug	Pin	Core colour	Pin	Socket
	1	Grey	6	
	2	Pink	8	
	3	Green	4	
	4	Yellow	2	
	5	Brown	7	
	6	White	3	
	Housing	Screen	-	
Type KVIA-MPYE-...				
Plug	Pin	Core colour	Pin	Socket
	1	-	-	
	2	-	-	
	3	Green	3	
	4	Yellow	4	
	5	Brown	1	
	6	White	2	
	Housing	Screen	-	

Festo North America

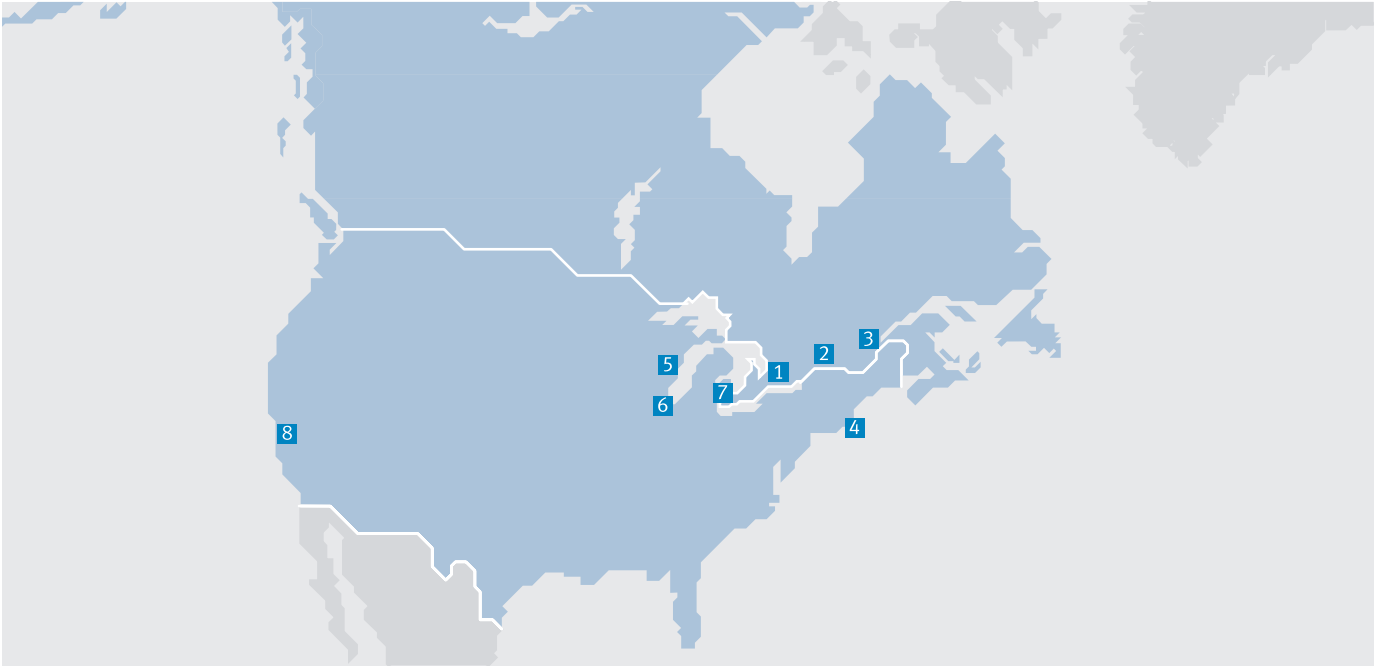

**1 Festo Canada
Headquarters
Festo Inc.**
5300 Explorer Drive
Mississauga, ON
L4W 5G4

2 Montréal
5600, Trans-Canada
Pointe-Claire, QC
H9R 1B6

3 Québec City
2930, rue Watt#117
Québec, QC
G1X 4G3



**4 Festo United States
Headquarters
Festo Corporation**
395 Moreland Road
Hauppauge, NY
11788

5 Appleton
North 922 Tower View Drive, Suite N
Greenville, WI
54942

7 Detroit
1441 West Long Lake Road
Troy, MI
48098

6 Chicago
85 W Algonquin - Suite 340
Arlington Heights, IL
60005

8 Silicon Valley
4935 Southfront Road, Suite F
Livermore, CA
94550

Festo Regional Contact Center

Canadian Customers

Commercial Support:
Tel: 1 877 GO FESTO (1 877 463 3786)
Fax: 1 877 FX FESTO (1 877 393 3786)
Email: festo.canada@ca.festo.com

Technical Support:
Tel: 1 866 GO FESTO (1 866 463 3786)
Fax: 1 877 FX FESTO (1 877 393 3786)
Email: technical.support@ca.festo.com

USA Customers

Commercial Support:
Tel: 1 800 99 FESTO (1 800 993 3786)
Fax: 1 800 96 FESTO (1 800 963 3786)
Email: customer.service@us.festo.com

Technical Support:
Tel: 1 866 GO FESTO (1 866 463 3786)
Fax: 1 800 96 FESTO (1 800 963 3786)
Email: product.support@us.festo.com