

Tools and accessories

FESTO



Datasheet



Tubing cutter PAN-V0S

For flame-retardant PAN-V0 tubing

Note on materials:
RoHS-compliant

LABS (PWIS) conformity:
VDMA24364-B2-L



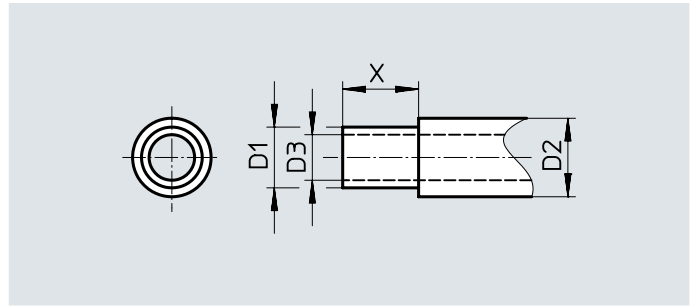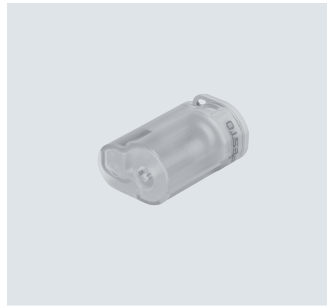


Colour: grey



Before the plastic tubing PAN-V0 can be inserted into the push-in fitting QS-V0, the tubing's PVC sheath must be cut by length X.

The integrated stop in the tubing cutter PAN-V0S ensures that the sheath is always cut to the correct length X. The blade design prevents damage to the inner polyamide tubing.

Dimensions and ordering data

| Push-in connector QS-V0 | D1 ∅ | D2 ∅ | D3 ∅ | X | Weight [g] | Part no. | Type | |
|-------------------------|---------|---------|---------|--------|---------------|----------|------------|---|
| I.D. 4 mm | 4 | 6 | 2.5 | 14.7±1 | 20 | 133180 | PAN-V0S-4 | -  - |
| I.D. 6 mm | 6 | 8 | 4 | 15.7±1 | 20 | 133181 | PAN-V0S-6 | -  - |
| I.D. 8 mm | 8 | 10 | 6 | 16.7±1 | 21 | 133182 | PAN-V0S-8 | -  - |
| I.D. 10 mm | 10 | 12 | 7.5 | 19.2±1 | 21 | 133183 | PAN-V0S-10 | -  - |
| I.D. 12 mm | 12 | 14 | 9 | 22.7±1 | 21 | 133184 | PAN-V0S-12 | -  - |

Datasheet

Connecting pliers ZMS-PK-3/4

With blade for connecting plastic tubing with outside diameters of 4 to 6 mm to barbed fittings.

Note on materials:
RoHS-compliant

LABS (PWIS) conformity:
VDMA24364-B2-L



| Ordering data | Weight [g] | Part no. | Type |
|-------------------|------------|----------|------------|
| Connecting pliers | 189 | 9341 | ZMS-PK-3/4 |

Pipe cutter ZR

For cutting plastic pipes PQ-PA with outside diameters of 12 to 28 mm to length. Not suitable for tubing with metal casing.

Note on materials:
RoHS-compliant

LABS (PWIS) conformity:
VDMA24364-B2-L



| Ordering data | Weight [g] | Part no. | Type |
|---------------|------------|----------|------|
| Pipe cutter | 361 | 194592 | ZR |

Pipe and tubing cutter ZRS

The pipe and tubing cutter ZRS is used for cutting to length plastic and nitrile rubber tubing with outside diameters of 2 to 20 mm, with or without textile insert. It is not suitable for tubing with metal sheath. It also has an integrated retaining clip to prevent unauthorised opening.

Note on materials:
RoHS-compliant

LABS (PWIS) conformity:
VDMA24364-B2-L



| Ordering data | Weight [g] | Part no. | Type | PS ¹⁾ |
|--|------------|----------|------------|------------------|
| Pipe and tubing cutter with 2 spare blades | 134 | 7658 | ZRS | 1 |
| 10 spare blades for pipe and tubing cutter | – | 218606 | ZRS 10PACK | 10 |

1) Pack size

Festo - Your Partner in Automation



1 Festo Inc.
5300 Explorer Drive
Mississauga, ON L4W 5G4
Canada

Festo Customer Interaction Center
Tel: 1 877 463 3786
Fax: 1 877 393 3786
Email: customer.service.ca@festo.com

2 Festo Pneumatic
Av. Ceylán 3,
Col. Tequesquináhuac
54020 Tlalnepantla,
Estado de México

Multinational Contact Center
01 800 337 8669
ventas.mexico@festo.com

3 Festo Corporation
1377 Motor Parkway
Suite 310
Islandia, NY 11749

Festo Customer Interaction Center
1 800 993 3786
1 800 963 3786
customer.service.us@festo.com

4 Regional Service Center
7777 Columbia Road
Mason, OH 45040

Connect with us



www.festo.com/socialmedia



www.festo.com

Subject to change