


 
Silencer AMTC

FESTO

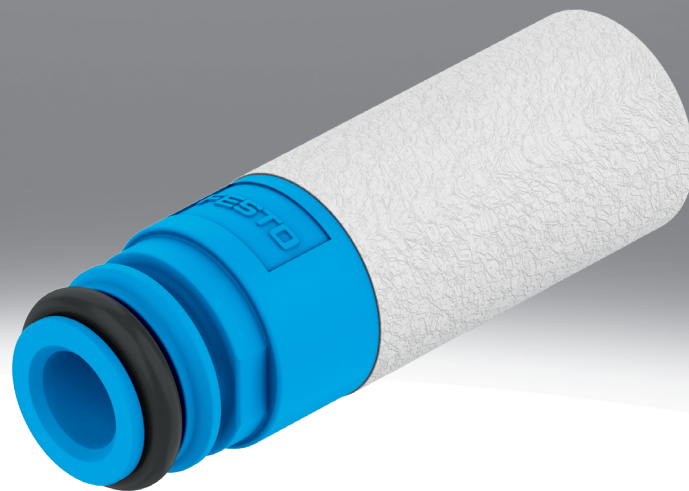

Characteristics

At a glance



Cartridge for solenoid valves VUVB-ST12 and valve terminals type 23 VTUB-12.

- Attached via pin (spring clip, included in the scope of delivery of the valve)
- Polymer version
- Operating medium: compressed air

Note: Clean silencers with paraffin (not with petrol or trichloroethylene).

Type code

001	Series	
AMTC	Silencer	

003	Additional features	
	None	

002	Product version	
P	Mainly polymer	

004	Pneumatic connection	
PC10	Cartridge 10 mm	

Datasheet

General technical data

Pneumatic connection	Cartridge 10 mm
Mounting position	optional
Sound pressure level ¹⁾	58 dB(A)

1) Measured at 6 bar against atmosphere at 1 m distance

Operating and environmental conditions


Operating pressure	0 ... 1 MPa
Operating pressure	0 ... 10 bar
Operating pressure	0 ... 145 psi
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:]
Note on operating and pilot medium	Lubricated operation possible
Ambient temperature	-5 ... 60°C

Materials

Material screwed plug	PE
Material shock absorber insert	PE
Note on materials	RoHS-compliant
LABS (PWIS) conformity	VDMA24364-B1/B2-L


Dimensions

Dimensions – Cartridge 10 mm

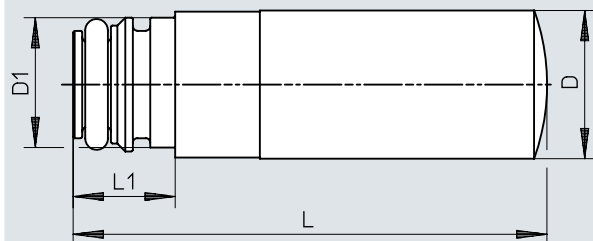Download CAD data → www.festo.com

	D ∅	D1 ∅	L	L1
AMTC-P-PC10	9,8	8,9	31,4	6,8

Ordering data

Ordering data					
	Pneumatic connection	Sound pressure level	Product weight	Part no.	Type
	Cartridge 10 mm	58 dB(A)	2 g	1224460	AMTC-P-PC10