


Silencer AMTX

**FESTO**

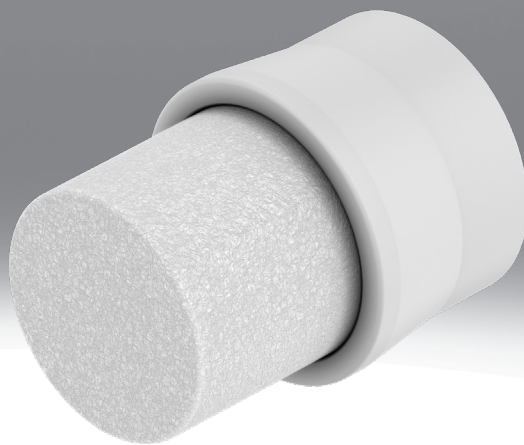

Type code

001	Series
AMTX	Silencer

002	Additional features
P	Cartridge

003	Pneumatic connection
PC12	Cartridge 12 mm

## Datasheet

### General technical data

Pneumatic connection	Cartridge 12 mm
Type of mounting	Via retaining clamp

### Operating and environmental conditions

Operating pressure	-0.1 ... 0.7 MPa
Operating pressure	-1 ... 7 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Ambient temperature	-5 ... 50°C
Corrosion resistance class CRC <sup>1)</sup>	2 - Moderate corrosion stress

<sup>1)</sup> Corrosion resistance class CRC 2 to Festo standard FN 940070. Moderate corrosion stress. Indoor application where condensation can occur. External visible parts with primarily decorative surface requirements that are in direct contact with the surrounding industrial environment.


### Materials

Material silencer	PE
Note on materials	RoHS-compliant
LABS (PWIS) conformity	VDMA24364-B1/B2-L

## Dimensions


Dimensions – AMTX

Download CAD data → [www.festo.com](http://www.festo.com)

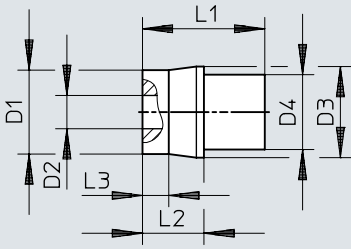

	D1 ∅ ± 0,2	D2 ∅ ± 0,1	D3 ∅ ± 0,15	D4 ∅ ± 0,2	L1 ± 0,2	L2 ± 0,2	L3 ± 0,1
AMTX-P-PC12	11,1	4,4	12,1	9,9	16,2	8,2	3,5

## Ordering data

Short version					
	Pneumatic connection	Size of pack <sup>1)</sup>	Product weight	Part no.	Type
	Cartridge 12 mm	1	0.7 g	<b>8191740</b>	<b>AMTX-P-PC12</b>

1) Quantity