

Datasheet

Terminating resistor CACR-B12G5

- Terminating resistor for PROFIBUS



General technical data

Electrical connection	Straight plug
	4-pin
	M12x1
Plug coding	B (for PROFIBUS)
Operating voltage range [V DC]	0 ... 5
Pollution degree	3
Degree of protection to EN 60529	IP67
Product weight [g]	11.6

Materials


Housing	TPE-U(PU)
Pin contact	Gold-plated brass
Note on materials	RoHS-compliant

Operating and environmental conditions

Ambient temperature [°C]	-25 ... +80
--------------------------	-------------

Dimensions

Download CAD data → www.festo.com

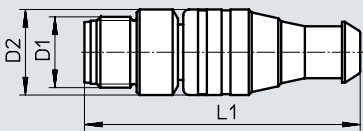

Type	D1	D2	L1
CACR-S-B12G5	M12	15	42

Ordering data

	Part no.	Type
Terminating resistor for PROFIBUS	1072128	CACR-S-B12G5-220-PB

Festo - Your Partner in Automation



1 Festo Inc.
5300 Explorer Drive
Mississauga, ON L4W 5G4
Canada

Festo Customer Interaction Center
Tel: 1 877 463 3786
Fax: 1 877 393 3786
Email: customer.service.ca@festo.com



2 Festo Pneumatic
Av. Ceylán 3,
Col. Tequesquináhuac
54020 Tlalnepantla,
Estado de México

Multinational Contact Center
01 800 337 8669
ventas.mexico@festo.com



3 Festo Corporation
1377 Motor Parkway
Suite 310
Islandia, NY 11749

Festo Customer Interaction Center
1 800 993 3786
1 800 963 3786
customer.service.us@festo.com



4 Regional Service Center
7777 Columbia Road
Mason, OH 45040

Connect with us



www.festo.com/socialmedia



www.festo.com

Subject to change