


Electrical adapter NEFF with additional function

Technical data

Plug socket NEFF-S1G44LB

- Plug socket for operating an interlock-capable valve terminal interface in I-Port operation only

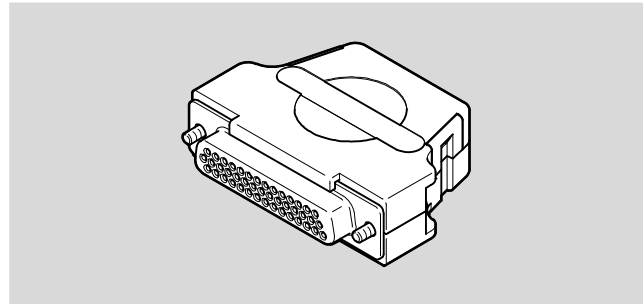

General technical data		
Max. tightening torque	[Nm]	0.24
Degree of protection EN 60529		IP40 (assembled)

Materials	
Note on materials	RoHS-compliant

Operating and environmental conditions		
Ambient temperature	[°C]	-5 ... +50

Dimensions Download CAD data → www.festo.com

Type	B1	H1	H2	L1
NEFF-S1G44LB	16	42.5	38	53.7

Ordering data		
	Part No.	Type
Plug socket	1589339	NEFF-S1G44LB

Festo - Your Partner in Automation



1 Festo Inc.
5300 Explorer Drive
Mississauga, ON L4W 5G4
Canada

Festo Customer Interaction Center
Tel: 1 877 463 3786
Fax: 1 877 393 3786
Email: customer.service.ca@festo.com

2 Festo Pneumatic
Av. Ceylán 3,
Col. Tequesquináhuac
54020 Tlalnepantla,
Estado de México

Multinational Contact Center
01 800 337 8669
ventas.mexico@festo.com

3 Festo Corporation
1377 Motor Parkway
Suite 310
Islandia, NY 11749

Festo Customer Interaction Center
1 800 993 3786
1 800 963 3786
customer.service.us@festo.com

4 Regional Service Center
7777 Columbia Road
Mason, OH 45040

Connect with us



www.festo.com/socialmedia



www.festo.com

Subject to change