

## Datasheet

### Terminating resistor CACR-B12G5

- Terminating resistor for PROFIBUS



#### General technical data

Electrical connection	Straight plug
	4-pin
	M12x1
Plug coding	B (for PROFIBUS)
Operating voltage range [V DC]	0 ... 5
Pollution degree	3
Degree of protection to EN 60529	IP67
Product weight [g]	11.6

#### Materials


Housing	TPE-U(PU)
Pin contact	Gold-plated brass
Note on materials	RoHS-compliant

#### Operating and environmental conditions

Ambient temperature [°C]	-25 ... +80
--------------------------	-------------

#### Dimensions

Download CAD data → [www.festo.com](http://www.festo.com)

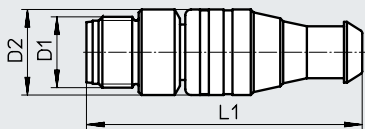

Type	D1	D2	L1
CACR-S-B12G5	M12	15	42

#### Ordering data

	Part no.	Type
Terminating resistor for PROFIBUS	<b>1072128</b>	<b>CACR-S-B12G5-220-PB</b>